

PRODUCT SPECIFICATIONS

MODEL NO.	MAX SPEED	MAX. PRESS.		HP	kW	NET WT.	
		bar	PSI			lbs.	kg
4AM-70C-CB60	50 RPM	7.0	100	.85	0.63	60	27.2

NOTES:

- CONFORMS TO EUROPEAN STANDARD EN13463-1 NON-ELECTRICAL EQUIPMENT FOR EXPLOSIVE ATMOSPHERES GROUP II CAT 2 (GAS & DUST), PROTECTED BY CONSTRUCTION T4 (TEMP RATED 135°C).
- TECHNICAL DATA SUBJECT TO CHANGE WITHOUT NOTICE. DIMENSIONS ARE FOR REFERENCE ONLY UNLESS OTHERWISE TOLERANCED. GEAR REDUCTION 60:1.







SOUND LEVEL: 87 dba MAX.

NORMAL AMBIENT: 1°C - 40°C

RELATIVE HUMIDITY: 0% - 100%

ENVIRONMENT: HAZARDOUS AMBIENT COMBUSTIBLE GAS

PRODUCT PERFORMANCE:

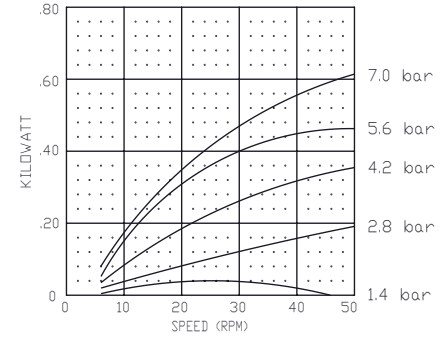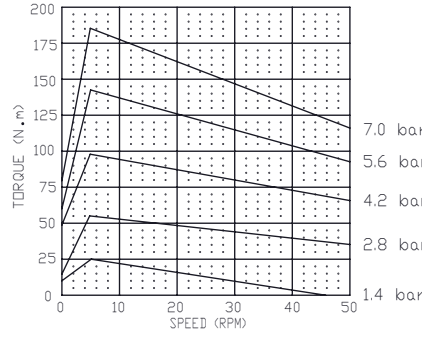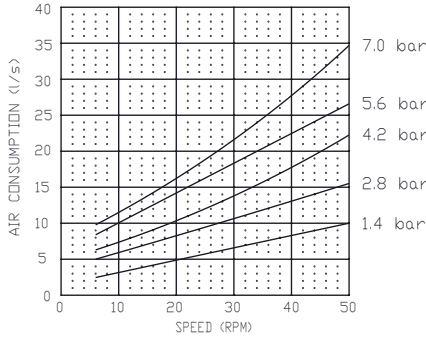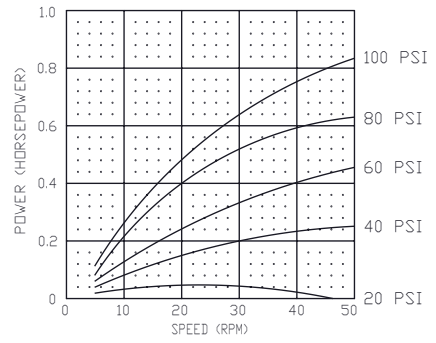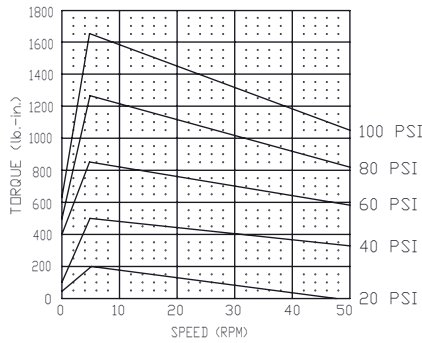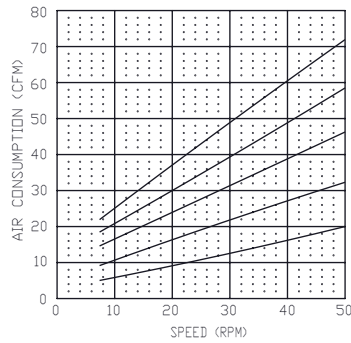

PRODUCT DIMENSIONS:

