



**MCR
SAFETY**

6414

Memphis PVC

**Supported / Dipped gloves
Specification Sheet**

PRODUCT DESCRIPTION:

These MCR Safety Premium PVC gloves are specially formulated to hold up in petrochemical applications. Two layers of sandy textured green PVC reinforced by nitrile offer toughness and abrasion resistance you'll need on the job. Glove lengths in this premium series range from knit wrist options to 18 inch gauntlet cuff options. The 6414 is double dipped in green PVC, has a sandy finish, jersey lining, and is treated with ActiFresh® to help prevent odors and eliminate bacteria caused by perspiration. Measures 14 inches in length. Looking for the best PVC coated work gloves? Don't settle for the rest, but get the best with MCR Safety!

FEATURES:

- Double dipped premium PVC coated gloves
- Nitrile reinforced
- Sandy textured finish
- Soft jersey lining
- 14 Inch Length
- Treated with ActiFresh®

APPLICATIONS:

Construction, Farming, Janitorial , Landscaping, Material Handling, Petrochemical industries, Sanitation



TECHNICAL DATA FOR: 6414

Series	Memphis PVC
Material Group	Supported
Product Type	Supported / Dipped gloves
Glove Size	Large
Material	PVC
Grade	Premium
Features	Nitrile Reinforced
Lining	Jersey
Thumb Style	Wing

Overall Length	14 in.
EN 388: CE Score - Abrasion	4
EN 388 : CE Score - Cut	1
EN 388 : CE Score - Tear	2
EN 388 : CE Score - Puncture	1

Made In Bangladesh

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2021 MCR Safety - All Rights Reserved




MCR
SAFETY

6414

Memphis PVC

Supported / Dipped gloves

Specification Sheet

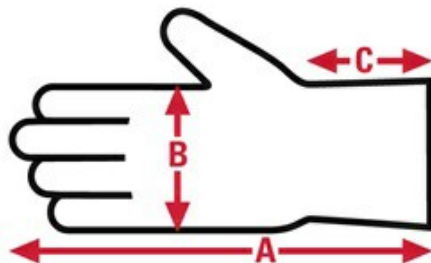

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
6414	Large	14.000	5	N/A	41.148 lb.	6.858

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2021 MCR Safety - All Rights Reserved