
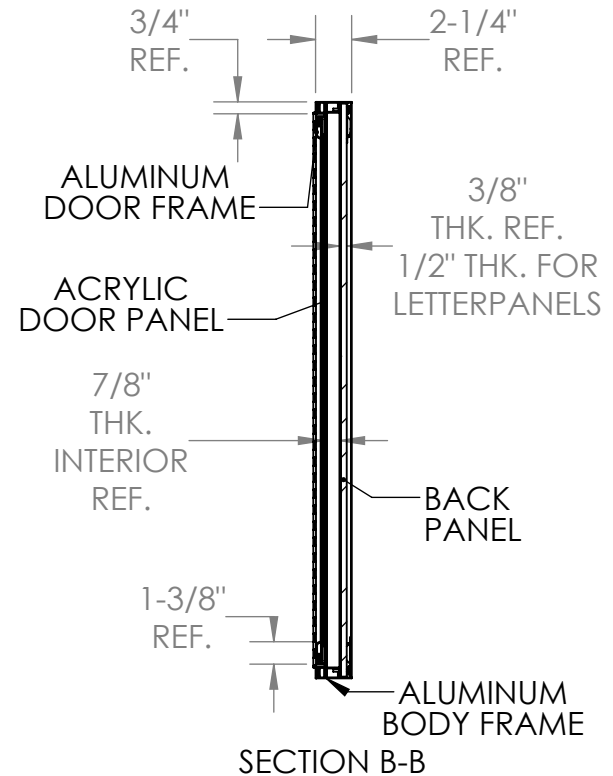


Series PA2 & PB2

Two Door Enclosed Bulletin,
Letter, Tack, & Whiteboards

ghent®

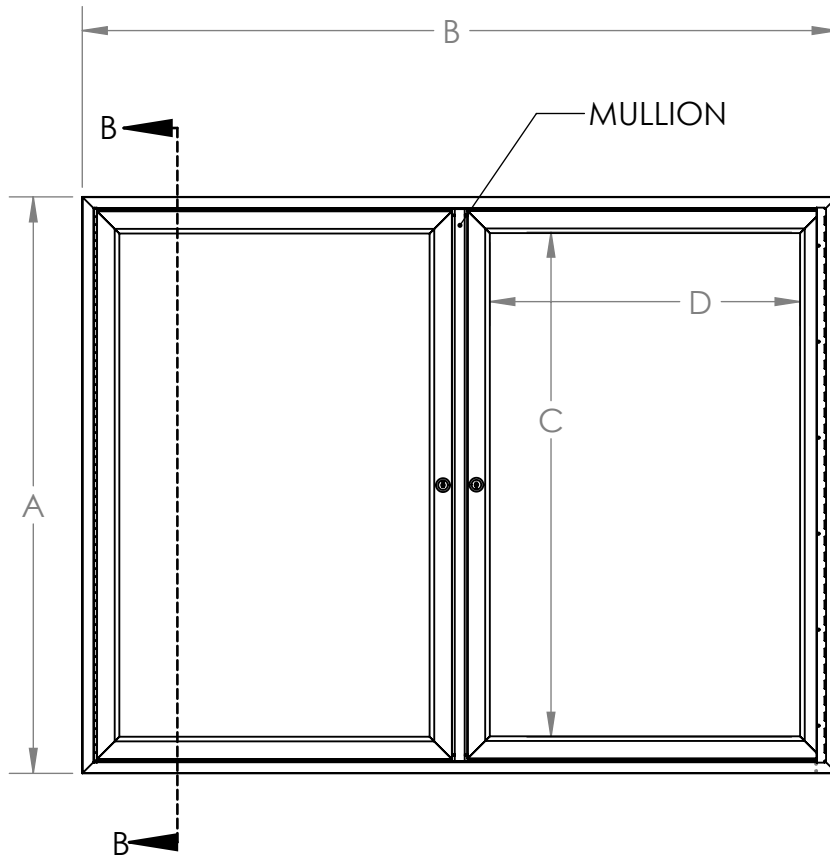

Specifications

All exposed metal is to be satin (PA) or bronze (PB) anodized extruded aluminum. Body frame and doors are constructed with mitered corners. Doors have 1/8" thick acrylic panes, continuous hinges and tumble locks with keys. Door frames are self supporting and do not depend on the acrylic panes for strength. The interior panel of the unit can be one of the following: fabric, cork tackboard, porcelain, or felt changeable letter panels (for interior use), or vinyl changeable letter panels (for exterior use). Panels for exterior units have foil backing and silicone caulking.

Sizes available:

ITEM #	A	B	C	D
PA23648, PB23648	36"	47-1/8"	31-7/16"	19-7/16"
PA23660, PB23660	36"	59-1/4"	31-7/16"	25-7/16"
PA24860, PB24860	47-1/8"	59-1/4"	42-9/16"	25-7/16"