


KS29, Split Bolt Connector, Run/Tap: #1 AWG Str-250 kcmil

By Burndy
Catalog # [KS29](#)

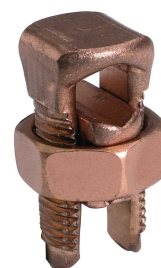

Copper Split Bolt, Cu: 1 AWG (Str)-250 kcmil (Run & Tap)

Features

- UL467 Listed for Direct Burial applications in earth or concrete
- Compact, high-strength, copper alloy with free-running threads and easy to grip wrench flats
- Highly resistant to cracking and corrosion

Application

For Direct Burial Cables

Specifications

Certification - UL Recognized	No
Buy American Compliant	Yes
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	<ul style="list-style-type: none"> • Buy America Compliant (All status valid till December 2026) • Buy American Act Compliant (All status valid till December 2026) • BABA Compliant (All status valid till December 2026)
Industry Standard(s)	<ul style="list-style-type: none"> • UL 486A • UL486B
Certification - ETL	No
Standards - Industry Standards Met	<ul style="list-style-type: none"> • UL 486A • UL486B
Standards - RoHS Compliance Status	EX
Certification - UL Listed Direct Burial	Yes
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Rebar Size	4
Conductor - Rebar Size Range	4
Conductor - Copper Str Run Range	1 STR - 250 KCMIL
Conductor - Copper Str Run	<ul style="list-style-type: none"> • 1 AWG • 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG

	<ul style="list-style-type: none"> • 250 kcmil
Conductor - Copper Solid Run Range	1 AWG-250 kcmil
Conductor - Copper Solid Run	4/0 AWG
Conductor - Copper Solid Tap Range	8 AWG-250 kcmil
Conductor - Copper Solid Tap	4/0 AWG
Conductor - CopperWeld Solid Tap Range	4/0
Conductor - CopperWeld Solid Tap	4/0
Conductor - CopperWeld Solid Run Range	4/0
Conductor - CopperWeld Solid Run	4/0
Conductor - CopperWeld Str Tap Range	7 #5
Conductor - CopperWeld Str Tap	7 #5
Conductor - CopperWeld Str Run Range	7 #5
Conductor - CopperWeld Str Run	7 #5
Conductor Type	<ul style="list-style-type: none"> • CU C Solid-Run • CU C Str-Run • CU Weld C Solid-Run • CU Weld C Str-Run • CU C Str-Tap • CU Weld C Solid-Tap • CU Weld C Str-Tap • CU C Solid-Tap
Conductor - Copper Str Tap Range	1 STR - 250 KCMIL
Conductor - Copper Str Tap	<ul style="list-style-type: none"> • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil

Configuration

Connector Type Split Bolt

Dimensions

Package Height 0.000 in
Package Weight 0.000 lb.
Package Length 0.000 in
Package Width 0.000 in
Dimension - L Length Overall
mm 53 mm
Width 1 in
Dimension - Width fraction 1-17/100 in
Dimension - Width mm 30 mm
Dimension - Width inch 1.17 in
Dimension - B Length inch 1.00 in
Dimension - Cross Flats inch 1.36 in
Dimension - Length Overall
inch 2.25

Force Related

Installation Torque Recommended in-lb 650 in

General

Trade Name SERVIT®
Plated N
Sub Brand SERVIT
UPC 781810013809
Type KS
Material Copper
Plating Type Unplated
UPC 12 Digit 781810013809
UPC 14 Digit GTIN 00781810013809

Logistics

Minimum Pack Quantity 25
Pallet Quantity 4625
Carton Quantity 25

Product Assets

[Catalog \[English\]](#)



A Hubbell brand

© 2026 Hubbell Incorporated. All rights reserved
BRDY-KS29-SPEC-EN | REV 5/2026