

8 AWG

GBC003



COMPACT, YET POWERFUL. BOOST BATTERY CLAMPS.

DESIGNED FOR
NOCO BOOST®
ULTRASAFE® LITHIUM JUMP STARTERS.

COMPATIBLE WITH:

GB20

GB40

GB50

GBX45




NOCO

30339 Diamond Parkway, #102
Glenwillow, OH 44139 | USA
1.800.456.6626

no.co

BETTER PERFORMANCE.
A FRACTION OF THE SIZE.

HD PRECISION CLAMPS vs. PREVIOUS HD CLAMPS

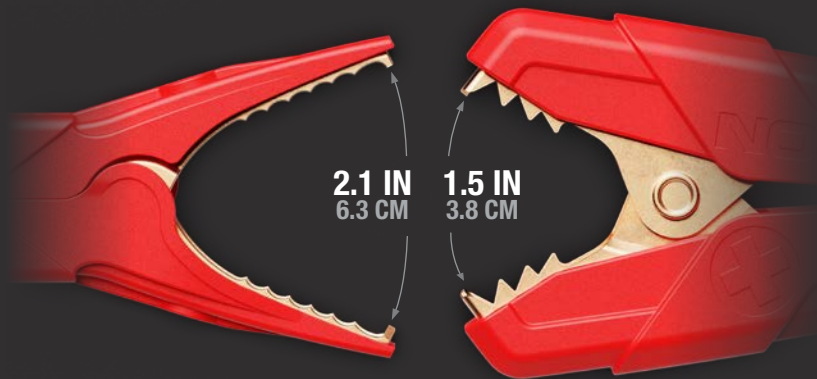

40% WIDER

Optimized to fit a wider range of applications more securely, to maximize conductivity during jump starts.

IMPROVED DESIGN.

Besides fitting most battery terminals, the HD Precision Clamps were engineered for improved clamping range with optimal clamping force.

REACH AND CONNECT.


12-inches of cable length and connect to most battery applications, while balancing performance and current delivery.



FOR EXTREME ENVIRONMENTS.

The GBC003 accessory is no-melt and smoke-free, has a high transferability and is reinforced with all metal construction. It is made from durable, heat stabilized 8 AWG silicone wire that maintains its flexibility in cold weather environments.

DIMENSIONS

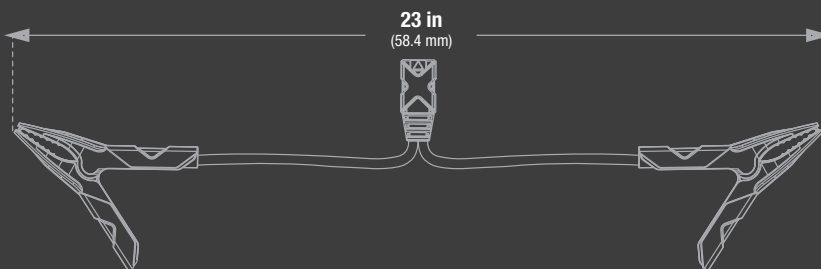

TECHNICAL SPECIFICATIONS

COMPATIBILITY:	GB20, GB40, GB50, GBX45	
WEIGHT:	0.80 lbs (0.49kg)	
INPUT:	Boost female connector	
WIRE SIZE:	8 AWG	
VOLUMETRICS:	Inner Carton: Dimensions: 7.28"x2.63"x3.78" Weight: 0.90 lbs UPC: 0-46221-19014-4	Master Carton: Dimensions: 7.87"x8.66"x8.46" Weight: 6.00 lbs UCC: 20046221190148
	Units Per Pallet: NA - 840 Units International - 720 Units	

NOCO

30339 Diamond Parkway, #102
Glenwillow, OH 44139 | USA
1.800.456.6626

no.co