




Hubbell iSTATION Multi-Service Frame

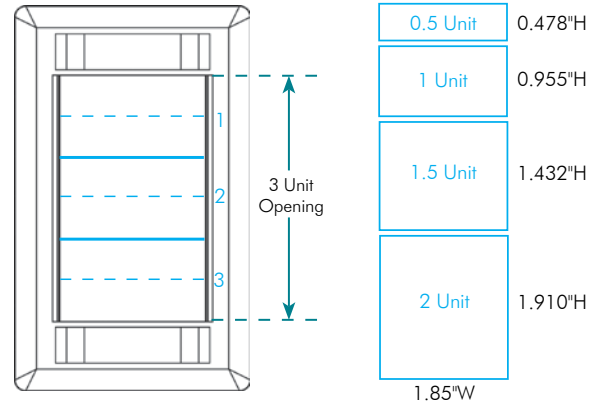

Hubbell iSTATION Frames accept three units of module combinations in a single-gang opening.



Specifications



- Decorator versions: UL Rated for power
- One to four gang
- Compatible with all Hubbell iSTATION modules and keystone connections
- Supplied with paper labels, clear covers and color-matched screw covers

Gangable AV Wallbox



Gangable

Design allows for an infinite number of options



Multi-Service

Ideal for delivering power, data and AV in the same box

Specifications



- 2- and 3-gang options
- Knockouts from 1/2 inch up to 2 inch
- NEMA spaced device mounting accepts industry standard wallplates
- Raised ground provisions in each gang
- 4 inches deep to accept practically any device



Capacity

4-inch depth accommodates large cables and bend radii



Angled Module
IMBDSA15OW



Blank Frame
ISFB215EI



Keystone Module
IM2K1OW



SC Angled Module
IM2SCA2OW

Blank HD15/9-Pin or HDMI Modules

| | 1 Unit | 1.5 Unit | | 2 Unit |
|--------------|--------------------|----------------------------|--|--|
| Color | HD15/9-Pin or HDMI | Angled, HD15/9-Pin or HDMI | HD15/9-Pin or HDMI with 3.5mm Stereo Jack* | HD15/9-Pin or HDMI with 3.5mm SJ+AV Conn |
| Black | IMBDS1BK | IMBDSA15BK | IMB15315BK | IMB153X2BK |
| Ivory | IMBDS1EI | IMBDSA15EI | IMB15315EI | IMB153X2EI |
| Gray | IMBDS1GY | IMBDSA15GY | IMB15315GY | IMB153X2GY |
| Office White | IMBDS1OW | IMBDSA15OW | IMB15315OW | IMB153X2OW |
| White | IMBDS1W | IMBDSA15W | IMB15315W | IMB153X2W |

*Screw termination or solder

Blank HD15/9-Pin or HDMI Frames

| Color | 1-Port | Recessed, 1-Port | 2-Port |
|--------------|-----------------|------------------|------------------|
| Black | ISFB15BK | ISFBR15BK | ISFB215BK |
| Ivory | ISFB15EI | ISFBR15EI | ISFB215EI |
| Gray | ISFB15GY | ISFBR15GY | ISFB215GY |
| Office White | ISFB15OW | ISFBR15OW | ISFB215OW |
| White | ISFB15W | ISFBR15W | ISFB215W |

Keystone Modules, Unloaded

| Color | 1 Unit | | 1.5 Unit | | Recessed, Angled, 1-Port | Recessed, Angled, 2-Port |
|--------------|----------------|----------------|------------------|------------------|--------------------------|--------------------------|
| | Flat, 1-Port | Flat, 2-Port | Angled, 1-Port | Angled, 2-Port | | |
| Black | IM1K1BK | IM2K1BK | IM1KA15BK | IM2KA15BK | IM1IA15BK | IM2IA15BK |
| Ivory | IM1K1EI | IM2K1EI | IM1KA15EI | IM2KA15EI | IM1IA15EI | IM2IA15EI |
| Gray | IM1K1GY | IM2K1GY | IM1KA15GY | IM2KA15GY | IM1IA15GY | IM2IA15GY |
| Office White | IM1K1OW | IM2K1OW | IM1KA15OW | IM2KA15OW | IM1IA15OW | IM2IA15OW |
| White | IM1K1W | IM2K1W | IM1KA15W | IM2KA15W | IM1IA15W | IM2IA15W |

Blank Modules

| Color | 0.5 Unit | 1 Unit | 1.5 Unit |
|--------------|----------------|---------------|----------------|
| Black | IMB05BK | IMB1BK | IMB15BK |
| Ivory | IMB05EI | IMB1EI | IMB15EI |
| Gray | IMB05GY | IMB1GY | IMB15GY |
| Office White | IMB05OW | IMB1OW | IMB15OW |
| White | IMB05W | IMB1W | IMB15W |

SC Angled Modules

| Color | 1.5 Unit, 1 Duplex | 2 Unit, 2 Duplex |
|--------------|--------------------|------------------|
| Black | IM1SCA15BK | IM2SCA2BK |
| Ivory | IM1SCA15EI | IM2SCA2EI |
| Gray | IM1SCA15GY | IM2SCA2GY |
| Office White | IM1SCA15OW | IM2SCA2OW |
| White | IM1SCA15W | IM2SCA2W |

Light Almond is the same color as Office White. See color chart on page V12.



HI-Impact Surface Mount Box

- Provides an easy way to mount and protect connectivity in punishing environments, supporting all HI-Impact media types
- For applications requiring stainless steel, NEMA Type 4/12 or NEMA Type 4X in different port configurations, a HI-Impact surface mount box suits environmental needs



2-Port Thermoplastic
HI24XGY



2-Port Powder Coat Steel
HI2CB2G



1-Port Stainless Steel
HI1CBSS

HI-Impact Surface Mount Boxes

Thermoplastic, Gray

| NEMA Type Rating | Ports | Catalog No. |
|------------------|-------|----------------|
| 4X | 1 | HI14XGY |
| | 2 | HI24XGY |
| | 4 | HI44XGY |
| | 6 | HI64XGY |

Steel, powder coated, Gray

| | | |
|---------|---|----------------|
| 4/12/13 | 1 | HI1CB2G |
| | 2 | HI2CB2G |

Stainless steel, brushed

| | | |
|----|---|----------------|
| 4X | 1 | HI1CBSS |
| | 2 | HI2CBSS |



DIN Rail Utility Box

- Offers a labor-saving method for providing utility power and/or communications to any control cabinet
- Installation is as easy as snapping the box vertically onto a 35mm DIN Rail and connecting the line, neutral and ground wires to the terminal block for power, or punching down Hubbell jacks for communications

DIN Rail Utility Box

| Description | Catalog No. |
|--|--------------------|
| Communications DIN rail utility box kit (unloaded) | HI DRUBCKIT |

See page B9 for decorator and duplex frames.