



Reeves LED Flush Mount RVEF Series

Features

Ornamental metal accents with a white linen fabric side diffuser.
White bottom acrylic diffuser. Ideal use in kitchens, hallways, and anywhere general lighting is needed. Provides lighting in residential, commercial and hospitality applications. Fixture mounts to standard junction box (not included).

Construction

The canopy is made of 22-gauge cold rolled steel. The LED pan is white painted. Standard mounting holes and hardware included. The canopy fits over a standard junction box. Power supply connections must be made inside a junction box (not included).

Finish

Satin nickel metal accents.

Diffuser

White linen fabric side diffuser.
White acrylic bottom diffuser.

Electrical

Input 120-277 VAC 60 HZ.
Compatible with residential (TRIAC/ELV) and commercial (0-10V) dimmers.
TRIAC and ELV dimming only at 120 VAC.

LED

Integrated LED modules capable of producing:
27W = 2000 delivered lumens
40W = 2800 delivered lumens
Adjustable 2700K, 3000K, 3500K, 4000K, 5000K (CCT).
Rated for 50,000 Hrs., 90 CRI.

Options

Emergency Battery Back-Up (add -BB to the end of the model number)
Motion Sensor (add -MS to the end of the model number)
Emergency Battery Back-Up with Motion Sensor (add -MSBB to the end of the model number)

Certification


All fixtures are cETLus listed for indoor damp locations.
Title 24/JA8 Compliant

Warranty

Limited warranty: This fixture is free from defects in materials and workmanship for a period of 5 years from date of purchase.

Specifications and dimensions
subject to change without notice.

LOCATION		DATE
PREPARED BY		QUANTITY
COMMENTS		FIXTURE TYPE
CATALOG NUMBER		

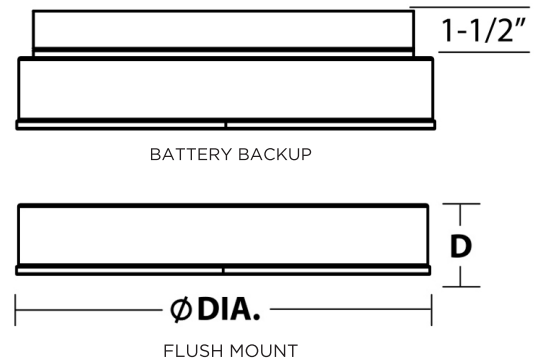

Ordering Information:

Satin Nickel/Linen White	LED	Delivered Lumens	Adjustable CCT	DIA.	D
RVEF16LAJUDSNLW	27W	2000	2700K/3000K/3500K/4000K/5000K	16"	4"
RVEF20LAJUDSNLW	40W	2800	2700K/3000K/3500K/4000K/5000K	20-1/4"	4"