




ITEM NUMBER	CATALOG NUMBER	TENSILE STRENGTH LB / N	MATERIAL	COLOR	FEATURE	BUNDLE DIA. MIN. IN [MM]	BUNDLE DIA. MAX. IN [MM]	L IN [MM]	W IN [MM]	MIN. INSTALL TEMP. °F / °C	MIN. OPER. TEMP. °F / °C	MAX. OPER. TEMP. °F / °C	PKG. QTY.	CTN. QTY.
10023292	CT18075C	18 / 80	NYLON 6/6	NATURAL	STANDARD	.06 [2]	.87 [22]	4.12 [105]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	1000
10023303	CT18075M	18 / 80	NYLON 6/6	NATURAL	STANDARD	.06 [2]	.87 [22]	4.12 [105]	.09 [2]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023304	CT18125C	18 / 80	NYLON 6/6	NATURAL	STANDARD	.06 [2]	1.50 [38]	6.18 [157]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	1000
10023307	CT18125C3	18 / 80	NYLON 6/6	ORANGE	STANDARD	.06 [2]	1.50 [38]	6.18 [157]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	1000
10023308	CT18125C4	18 / 80	NYLON 6/6	YELLOW	STANDARD	.06 [2]	1.50 [38]	6.18 [157]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	1000
10023315	CT18125M	18 / 80	NYLON 6/6	NATURAL	STANDARD	.06 [2]	1.50 [38]	6.18 [157]	.09 [2]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023316	CT18200C	18 / 80	NYLON 6/6	NATURAL	STANDARD	.06 [2]	2.10 [53]	8.18 [208]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	1000
10023317	CT18200C1	18 / 80	NYLON 6/6	BROWN	STANDARD	.06 [2]	2.10 [53]	8.18 [208]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	1000
10023318	CT18200C2	18 / 80	NYLON 6/6	RED	STANDARD	.06 [2]	2.10 [53]	8.18 [208]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	1000
10023321	CT18200C5	18 / 80	NYLON 6/6	GREEN	STANDARD	.06 [2]	2.10 [53]	8.18 [208]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	1000
10023322	CT18200C6	18 / 80	NYLON 6/6	BLUE	STANDARD	.06 [2]	2.10 [53]	8.18 [208]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	1000
10023327	CT18200M	18 / 80	NYLON 6/6	NATURAL	STANDARD	.06 [2]	2.10 [53]	8.18 [208]	.09 [2]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023328	CT18075C00	18 / 80	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	.87 [22]	4.12 [105]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	1000
10023329	CT18075M00	18 / 80	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	.87 [22]	4.12 [105]	.09 [2]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023334	CT18075C0	18 / 80	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	.87 [22]	4.12 [105]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	1000
10023335	CT18075M0	18 / 80	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	.87 [22]	4.12 [105]	.09 [2]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023336	CT18125C0	18 / 80	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	1.50 [38]	6.18 [157]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	1000
10023337	CT18125M0	18 / 80	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	1.50 [38]	6.18 [157]	.09 [2]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023338	CT18200C0	18 / 80	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	2.10 [53]	8.18 [208]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	1000
10023339	CT18200M0	18 / 80	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	2.10 [53]	8.18 [208]	.09 [2]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023669	CT18075MH4C	18 / 80	NYLON 6/6	NATURAL	MTG HOLE	.12 [3]	.75 [19]	4.62 [118]	.09 [2]	32 / 0	32 / 0	185 / 85	100	1000
10023670	CT18075MH4M	18 / 80	NYLON 6/6	NATURAL	MTG HOLE	.12 [3]	.75 [19]	4.62 [118]	.09 [2]	32 / 0	32 / 0	185 / 85	1000	1000
10023689	CT18075IDC	18 / 80	NYLON 6/6	NATURAL	IDENTIFICATION	.21 [6]	.82 [22]	4.03 [103]	.1 [2]	14 / -10	-40 / -40	185 / 85	100	1000
50027390	CTHS18075M	18 / 80	NYLON 6/6 HEAT STABILIZED	HS UV BLK	STANDARD	.06 [2]	.87 [22]	4.12 [105]	.09 [2]	-4 / -20	-40 / -40	257 / [125]	1000	1000

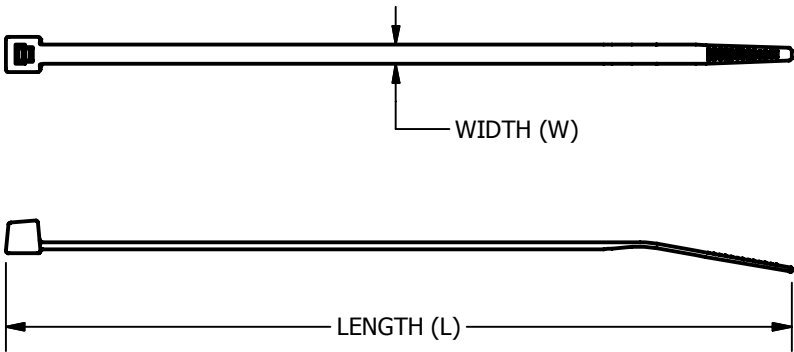

STANDARD

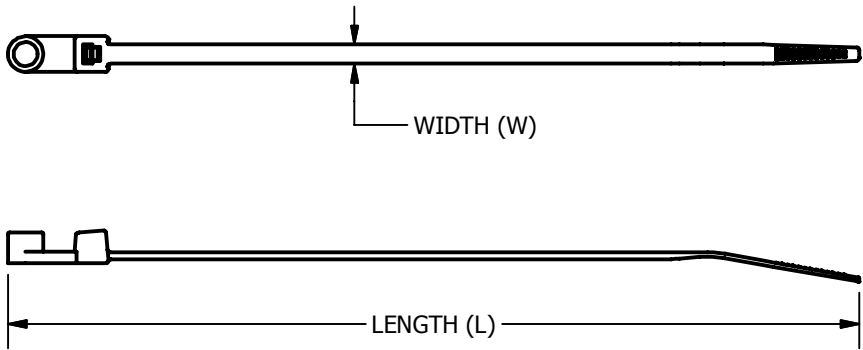

MTG HOLE

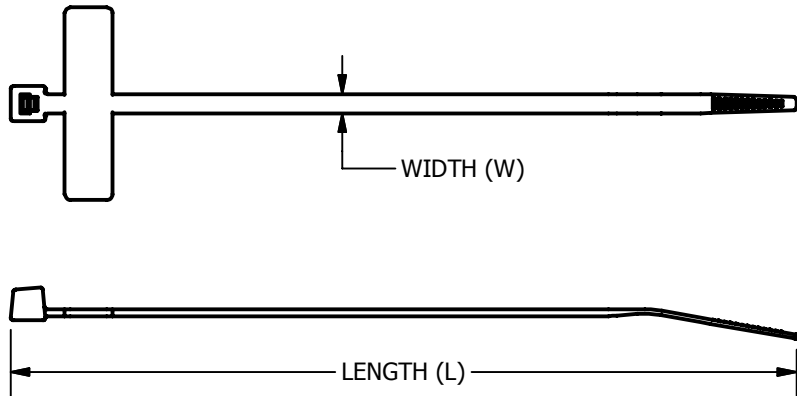

IDENTIFICATION


NOTES:

1. DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE SPECIFIED AND ARE FOR REFERENCE ONLY.


REV	DATE	DESCRIPTION	ECO	BY	C'H'K.
C	12/12/2017	TABLE DETAILS UPDATED	48171	PB	DD

TO ORDER BURNDY® PRODUCTS CALL			UNIRAP™		
UNITED STATES 1-800-346-4175 (LONDONDERRY, NH)			ITEM NO: SEE TABLE		
CANADA: 1-800-361-6975 (QUEBEC) 1-800-387-6487 (ALL OTHER PROVINCES)			CAT. NO: SEE TABLE		
FOR PRODUCT INFO: http://www.burndy.com			DRAWN BY: D DHEENA	3/8/2017	
			CHECKER: K BOUTIN	4/5/2017	
			DSN APRVL: A MONTMINY	3/29/2017	
			MFG APRVL: --		
			QA APRVL: B POST	3/20/2017	
			MKT APRVL: K BOUTIN	4/5/2017	
			PROD FAM: --		
			PROJECT #: --	SIZE	
			DOCUMENT TYPE: SALES		
			REL LEVEL: Released		
			DRAWING NO		REV
			50080813		C
			SHEET 1 OF 5		


ITEM NUMBER	CATALOG NUMBER	TENSILE STRENGTH LB / N	MATERIAL	COLOR	FEATURE	BUNDLE DIA. MIN. IN [MM]	BUNDLE DIA. MAX. IN [MM]	L IN [MM]	W IN [MM]	MIN. INSTALL TEMP. °F / °C	MIN. OPER. TEMP. °F / °C	MAX. OPER. TEMP. °F / °C	PKG. QTY.	CTN. QTY.
10023340	CT30125C	40 / 178	NYLON 6/6	NATURAL	STANDARD	.06 [2]	1.40 [36]	5.84 [148]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	1000
10023351	CT30125M	40 / 178	NYLON 6/6	NATURAL	STANDARD	.06 [2]	1.40 [36]	5.84 [148]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023388	CT30125C00	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	1.40 [36]	5.84 [148]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	1000
10023389	CT30125M00	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	1.40 [36]	5.84 [148]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023673	CT30125MH8C	40 / 180	NYLON 6/6	NATURAL	MTG HOLE	.11 [3]	1.40 [36]	6.12 [155]	.13 [3]	14 / -10	-40 / -40	185 / 85	100	1000
10023674	CT30125MH8M	40 / 180	NYLON 6/6	NATURAL	MTG HOLE	.11 [3]	1.40 [36]	6.12 [155]	.13 [3]	14 / -10	-40 / -40	185 / 85	1000	10000
10023676	CT30125MH8M0	40 / 180	NYLON 6/6	UV BLACK	MTG HOLE	.11 [3]	1.40 [36]	6.12 [155]	.13 [3]	14 / -10	-40 / -40	185 / 85	1000	10000
10023352	CT40200C	40 / 178	NYLON 6/6	NATURAL	STANDARD	.06 [2]	2.37 [60]	8.87 [225]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	1000
10023363	CT40200M	40 / 178	NYLON 6/6	NATURAL	STANDARD	.06 [2]	2.37 [60]	8.87 [225]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023364	CT40300C	40 / 178	NYLON 6/6	NATURAL	STANDARD	.06 [2]	3.37 [86]	10.96 [278]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	1000
10023375	CT40300M	40 / 178	NYLON 6/6	NATURAL	STANDARD	.06 [2]	3.37 [86]	10.96 [278]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023376	CT40400C	40 / 178	NYLON 6/6	NATURAL	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	1000
10023387	CT40400M	40 / 178	NYLON 6/6	NATURAL	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023390	CT30125C0	40 / 178	NYLON 6/6	UVBLACK	STANDARD	.06 [2]	1.40 [36]	5.84 [148]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	1000
10023391	CT30125M0	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	1.40 [36]	5.84 [148]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023392	CT40200C00	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	2.37 [60]	8.87 [225]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	1000
10023393	CT40200M00	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	2.37 [60]	8.87 [225]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023394	CT40300C00	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	3.37 [86]	10.96 [278]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	1000
10023395	CT40300M00	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	3.37 [86]	10.96 [278]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023396	CT40400C00	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	1000
10023397	CT40400M00	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023398	CT40200C0	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	2.37 [60]	8.87 [225]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	1000
10023399	CT40200M0	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	2.37 [60]	8.87 [225]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023400	CT40300C0	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	3.37 [86]	10.96 [278]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	1000
10023401	CT40300M0	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	3.37 [86]	10.96 [278]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023402	CT40400C0	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	1000
10023403	CT40400M0	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
50027391	CTHS40125M	40 / 178	NYLON 6/6 HEAT STABILIZED	HS UV BLACK	STANDARD	.06 [2]	1.40 [36]	5.84 [148]	.14 [4]	-4 / -20	-40 / -40	257 / [125]	1000	1000

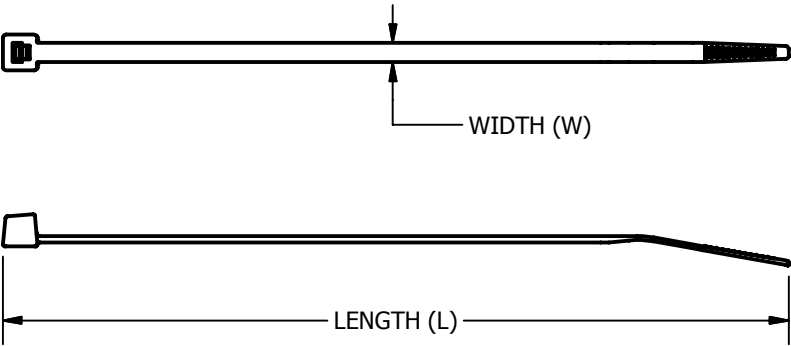

STANDARD

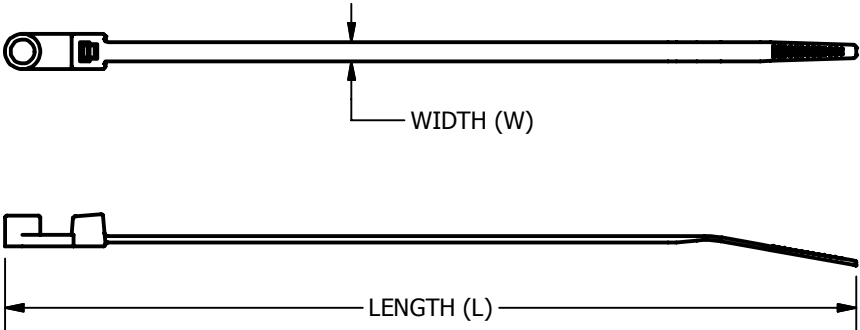

MTG HOLE

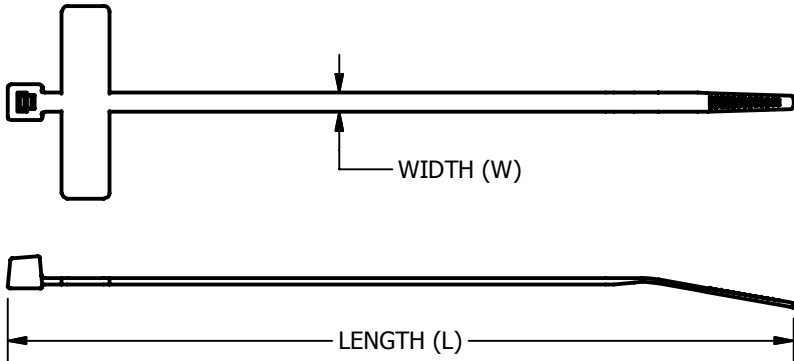

IDENTIFICATION


NOTES:

1. DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE SPECIFIED AND ARE FOR REFERENCE ONLY.


REV	DATE	DESCRIPTION	ECO	BY	C'H'K.
C	12/12/2017	TABLE DETAILS UPDATED	48171	PB	DD

TO ORDER BURNDY® PRODUCTS CALL		UNIRAP™			
UNITED STATES		ITEM NO: SEE TABLE			
1-800-346-4175 (LONDONDERRY, NH)		CAT. NO:SEE TABLE			
CANADA:		DRAWN BY: D DHEENA 3/8/2017			
1-800-361-6975 (QUEBEC)		CHECKER: K BOUTIN 4/5/2017			
1-800-387-6487 (ALL OTHER PROVINCES)		DSN APRVL: A MONTMINY 3/29/2017			
		MFG APRVL: --			
		QA APRVL: B POST 3/20/2017			
FOR PRODUCT INFO: http://www.burndy.com		MKT APRVL: K BOUTIN 4/5/2017			
		PROD FAM: --		DRAWING NO	
		PROJECT #: --		REV	
		SIZE		50080813	
		DOCUMENT TYPE: SALES		C	
		REL LEVEL: Released			
				SHEET 2 OF 5	


ITEM NUMBER	CATALOG NUMBER	TENSILE STRENGTH LB / N	MATERIAL	COLOR	FEATURE	BUNDLE DIA. MIN. IN [MM]	BUNDLE DIA. MAX. IN [MM]	L IN [MM]	W IN [MM]	MIN. INSTALL TEMP. °F / °C	MIN. OPER. TEMP. °F / °C	MAX. OPER. TEMP. °F / °C	PKG. QTY.	CTN. QTY.
10023404	CT50175C	50 / 222	NYLON 6/6	NATURAL	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	10000
10023405	CT50175C1	50 / 222	NYLON 6/6	BROWN	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	1000
10023406	CT50175C2	50 / 222	NYLON 6/6	RED	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	1000
10023407	CT50175C3	50 / 222	NYLON 6/6	ORANGE	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	1000
10023408	CT50175C4	50 / 222	NYLON 6/6	YELLOW	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	1000
10023409	CT50175C5	50 / 222	NYLON 6/6	GREEN	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	1000
10023410	CT50175C6	50 / 222	NYLON 6/6	BLUE	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	1000
10023411	CT50175C7	50 / 222	NYLON 6/6	PURPLE	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	1000
10023412	CT50175C8	50 / 222	NYLON 6/6	GRAY	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	1000
10023413	CT50175C10	50 / 222	NYLON 6/6	WHITE	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	1000
10023415	CT50175M	50 / 222	NYLON 6/6	NATURAL	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023416	CT50300C	50 / 222	NYLON 6/6	NATURAL	STANDARD	.06 [2]	3.00 [76]	11.25 [286]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023418	CT50300C2	50 / 222	NYLON 6/6	RED	STANDARD	.06 [2]	3.00 [76]	11.25 [286]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023427	CT50300M	50 / 222	NYLON 6/6	NATURAL	STANDARD	.06 [2]	3.00 [76]	11.25 [286]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023428	CT50400C	50 / 222	NYLON 6/6	NATURAL	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023430	CT50400C2	50 / 222	NYLON 6/6	RED	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023431	CT50400C3	50 / 222	NYLON 6/6	ORANGE	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023439	CT50400M	50 / 222	NYLON 6/6	NATURAL	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023440	CT50175C00	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	10000
10023441	CT50175M00	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023442	CT50300C00	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	3.00 [76]	11.25 [286]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023443	CT50300M00	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	3.00 [76]	11.25 [286]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023444	CT50400C00	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023445	CT50400M00	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023446	CT50175C0	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	10000
10023447	CT50175M0	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023448	CT50300C0	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	3.00 [76]	11.25 [286]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023449	CT50300M0	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	3.00 [76]	11.25 [286]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023450	CT50400C0	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023451	CT50400M0	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	5000

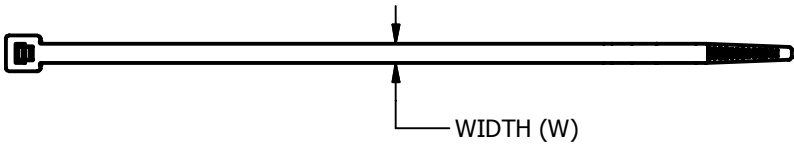

STANDARD

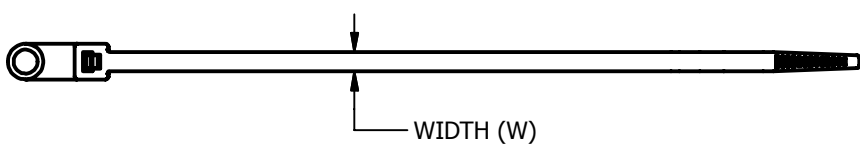

MTG HOLE

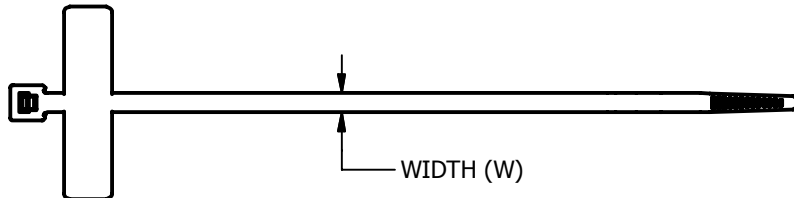

IDENTIFICATION


NOTES:

1. DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE SPECIFIED AND ARE FOR REFERENCE ONLY.


REV	DATE	DESCRIPTION	ECO	BY	C'H'K.
C	12/12/2017	TABLE DETAILS UPDATED	48171	PB	DD

TO ORDER BURNDY® PRODUCTS CALL			UNIRAP™		
UNITED STATES 1-800-346-4175 (LONDONDERRY, NH)			ITEM NO: SEE TABLE		
CANADA: 1-800-361-6975 (QUEBEC) 1-800-387-6487 (ALL OTHER PROVINCES)			CAT. NO: SEE TABLE		
FOR PRODUCT INFO: http://www.burndy.com			DRAWN BY: D DHEENA	3/8/2017	
			CHECKER: K BOUTIN	4/5/2017	
			DSN APRVL: A MONTMINY	3/29/2017	
			MFG APRVL: --		
			QA APRVL: B POST	3/20/2017	
			MKT APRVL: K BOUTIN	4/5/2017	
			PROD FAM: --		
			PROJECT #: --	SIZE	
			DOCUMENT TYPE: SALES		
			REL LEVEL: Released		
			DRAWING NO		REV
			50080813		C
			SHEET 3 OF 5		


ITEM NUMBER	CATALOG NUMBER	TENSILE STRENGTH LB / N	MATERIAL	COLOR	FEATURE	BUNDLE DIA. MIN. IN [MM]	BUNDLE DIA. MAX. IN [MM]	L IN [MM]	W IN [MM]	MIN. INSTALL TEMP. °F / °C	MIN. OPER. TEMP. °F / °C	MAX. OPER. TEMP. °F / °C	PKG. QTY.	CTN. QTY.
10023657	CT50175PMC	49 / 220	NYLON 6/6	NATURAL	PUSH MOUNT	.13 [4]	1.97 [50]	7.99 [202]	.18 [5]	14 / -10	-40 / -40	185 / 85	100	1000
10023661	CT50175PMC0	49 / 220	NYLON 6/6	UV BLACK	PUSH MOUNT	.13 [4]	1.97 [50]	7.99 [202]	.18 [5]	14 / -10	-40 / -40	185 / 85	100	1000
10023677	CT50175MH10C	50 / 222	NYLON 6/6	NATURAL	MTG HOLE	.06 [2]	1.87 [48]	8.00 [203]	.17 [4]	-4 / -20	-40 / -40	185 / 85	100	5000
10023678	CT50175MH10M	50 / 222	NYLON 6/6	NATURAL	MTG HOLE	.06 [2]	1.87 [48]	8.00 [203]	.17 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023679	CT50175MH10C0	50 / 222	NYLON 6/6	UVBLACK	MTG HOLE	.06 [2]	1.87 [48]	8.00 [203]	.17 [4]	-4 / -20	-40 / -40	185 / 85	100	5000
10023680	CT50175MH10M0	50 / 222	NYLON 6/6	UV BLACK	MTG HOLE	.06 [2]	1.87 [48]	8.00 [203]	.17 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023681	CT50400MH10C	50 / 222	NYLON 6/6	NATURAL	MTG HOLE	.06 [2]	4.00 [102]	14.50 [368]	.17 [4]	-4 / -20	-40 / -40	185 / 85	100	1000
10023683	CT50400MH10C0	50 / 222	NYLON 6/6	UVBLACK	MTG HOLE	.06 [2]	4.00 [102]	14.50 [368]	.17 [4]	-4 / -20	-40 / -40	185 / 85	100	1000
10023691	CT50175IDC	49 / 220	NYLON 6/6	NATURAL	IDENTIFICATION	.49 [13]	2.00 [51]	7.50 [191]	.18 [5]	14 / -10	-40 / -40	185 / 85	100	1000
10023692	CT50175ID2L	50 / 222	NYLON 6/6	NATURAL	IDENTIFICATION	.37 [10]	1.75 [45]	7.40 [188]	.18 [5]	32 / 0	32 / 0	185 / 85	50	1000
10023693	CT50175ID3L	50 / 222	NYLON 6/6	NATURAL	IDENTIFICATION	.37 [10]	1.75 [45]	7.40 [188]	.18 [5]	32 / 0	32 / 0	185 / 85	50	1000
10023829	CT50175M02	50 / 222	NYLON 6/6	UV RED	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023830	CT50400M02	50 / 222	NYLON 6/6	UV RED	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	5000
50027392	CTHS50700M	50 / 222	NYLON 6/6 HEAT STABILIZED	HS UV BLACK	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	257 / 125	1000	1000
50027393	CTHS50300M	50 / 222	NYLON 6/6 HEAT STABILIZED	HS UV BLACK	STANDARD	.06 [2]	3.00 [76]	11.25 [286]	.18 [5]	-4 / -20	-40 / -40	257 / 125	1000	1000
50027394	CTHS50400M	50 / 222	NYLON 6/6 HEAT STABILIZED	HS UV BLACK	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.18 [5]	-4 / -20	-40 / -40	257 / 125	1000	1000
10023452	CT120200L	120 / 534	NYLON 6/6	NATURAL	STANDARD	.18 [5]	2.00 [51]	8.70 [221]	.30 [8]	-4 / -20	-40 / -40	185 / 85	50	2500
10023463	CT120200D	120 / 534	NYLON 6/6	NATURAL	STANDARD	.18 [5]	2.00 [51]	8.70 [221]	.30 [8]	-4 / -20	-40 / -40	185 / 85	500	2500
10023464	CT120300L	120 / 534	NYLON 6/6	NATURAL	STANDARD	.18 [5]	3.00 [76]	12.00 [305]	.30 [8]	-4 / -20	-40 / -40	185 / 85	50	2000
10023475	CT120300D	120 / 534	NYLON 6/6	NATURAL	STANDARD	.18 [5]	3.00 [76]	12.00 [305]	.30 [8]	-4 / -20	-40 / -40	185 / 85	500	2000
10023476	CT120400L	120 / 534	NYLON 6/6	NATURAL	STANDARD	.18 [5]	4.00 [102]	15.09 [383]	.30 [8]	-4 / -20	-40 / -40	185 / 85	50	2000
10023487	CT120400D	120 / 534	NYLON 6/6	NATURAL	STANDARD	.18 [5]	4.00 [102]	15.09 [383]	.30 [8]	-4 / -20	-40 / -40	185 / 85	500	2000
50034735	CT120800L	120 / 534	NYLON 6/6	NATURAL	STANDARD	.18 [5]	9.00 [229]	30.87 [784]	.30 [8]	-4 / -20	-40 / -40	185 / 85	50	500
10023500	CT120400L00	120 / 534	NYLON 6/6	UV BLACK	STANDARD	.18 [5]	4.00 [102]	15.09 [383]	.30 [8]	-4 / -20	-40 / -40	185 / 85	50	2000
10023501	CT120400D00	120 / 534	NYLON 6/6	UV BLACK	STANDARD	.18 [5]	4.00 [102]	15.09 [383]	.30 [8]	-4 / -20	-40 / -40	185 / 85	500	2000
50034736	CT120800L00	120 / 534	NYLON 6/6	UV BLACK	STANDARD	.18 [5]	9.00 [229]	30.87 [784]	.30 [8]	-4 / -20	-40 / -40	185 / 85	50	500

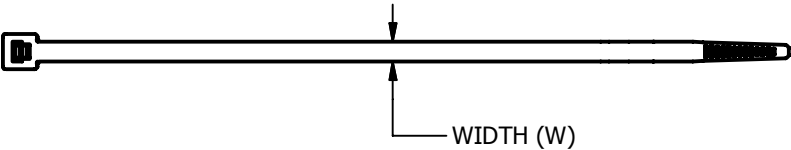

STANDARD

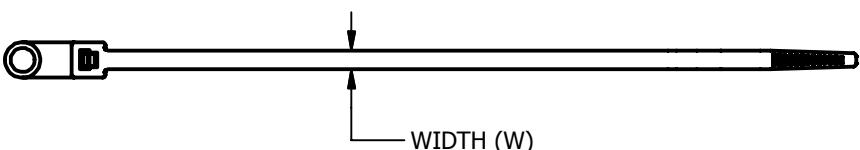

MTG HOLE

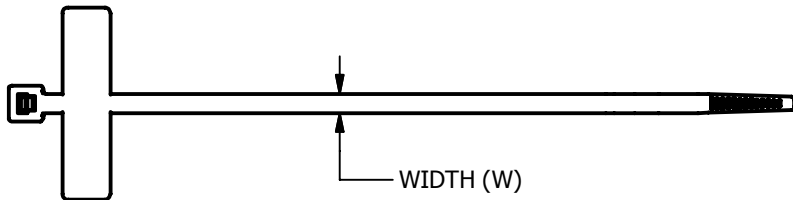

IDENTIFICATION


NOTES:

1. DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE SPECIFIED AND ARE FOR REFERENCE ONLY.


REV	DATE	DESCRIPTION	ECO	BY	C'H'K.
C	12/12/2017	TABLE DETAILS UPDATED	48171	PB	DD

TO ORDER BURNDY® PRODUCTS CALL			UNIRAP™		
UNITED STATES 1-800-346-4175 (LONDONDERRY, NH)			ITEM NO: SEE TABLE		
CANADA: 1-800-361-6975 (QUEBEC) 1-800-387-6487 (ALL OTHER PROVINCES)			CAT. NO: SEE TABLE		
FOR PRODUCT INFO: http://www.burndy.com			DRAWN BY: D DHEENA	3/8/2017	
			CHECKER: K BOUTIN	4/5/2017	
			DSN APRVL: A MONTMINY	3/29/2017	
			MFG APRVL: --		
			QA APRVL: B POST	3/20/2017	
			MKT APRVL: K BOUTIN	4/5/2017	
			PROD FAM: --		
			PROJECT #: --	SIZE	
			DOCUMENT TYPE: SALES		
			REL LEVEL: Released		
			DRAWING NO		REV
			50080813		C
			SHEET 4 OF 5		


ITEM NUMBER	CATALOG NUMBER	TENSILE STRENGTH LB / N	MATERIAL	COLOR	FEATURE	BUNDLE DIA. MIN. IN [MM]	BUNDLE DIA. MAX. IN [MM]	L IN [MM]	W IN [MM]	MIN. INSTALL TEMP. °F / °C	MIN. OPER. TEMP. °F / °C	MAX. OPER. TEMP. °F / °C	PKG. QTY.	CTN. QTY.
10023504	CT120200L0	120 / 534	NYLON 6/6	UV BLACK	STANDARD	.18 [5]	2.00 [51]	8.70 [221]	.30 [8]	-4 / -20	-40 / -40	185 / 85	50	2500
10023505	CT120200D0	120 / 534	NYLON 6/6	UV BLACK	STANDARD	.18 [5]	2.00 [51]	8.70 [221]	.30 [8]	-4 / -20	-40 / -40	185 / 85	500	2500
10023506	CT120300L0	120 / 534	NYLON 6/6	UV BLACK	STANDARD	.18 [5]	3.00 [76]	12.00 [305]	.30 [8]	-4 / -20	-40 / -40	185 / 85	50	2000
10023507	CT120300D0	120 / 534	NYLON 6/6	UV BLACK	STANDARD	.18 [5]	3.00 [76]	12.00 [305]	.30 [8]	-4 / -20	-40 / -40	185 / 85	500	2000
10023508	CT120400L0	120 / 534	NYLON 6/6	UV BLACK	STANDARD	.18 [5]	4.00 [102]	15.09 [383]	.30 [8]	-4 / -20	-40 / -40	185 / 85	50	2000
10023509	CT120400D0	120 / 534	NYLON 6/6	UV BLACK	STANDARD	.18 [5]	4.00 [102]	15.09 [383]	.30 [8]	-4 / -20	-40 / -40	185 / 85	500	2000
50056948	CT120400M0	120 / 534	NYLON 6/6	UV BLACK	STANDARD	.18 [5]	4.00 [102]	15.09 [383]	.30 [8]	-4 / -20	-40 / -40	185 / 85	1000	2000
50081667	CT120400MH14C	120 / 534	NYLON 6/6	NATURAL	MTG HOLE	.18 [5]	4.06 [103]	15.70 [399]	.30 [8]	-4 / -20	-40 / -40	185 / 85	100	1000
10023685	CT120400MH14L	120 / 534	NYLON 6/6	NATURAL	MTG HOLE	.18 [5]	4.06 [103]	15.70 [399]	.30 [8]	-4 / -20	-40 / -40	185 / 85	50	1000
10023686	CT120400MH14D	120 / 534	NYLON 6/6	NATURAL	MTG HOLE	.18 [5]	4.06 [103]	15.70 [399]	.30 [8]	-4 / -20	-40 / -40	185 / 85	500	1000
10023687	CT120400MH14L0	120 / 534	NYLON 6/6	UV BLACK	MTG HOLE	.18 [5]	4.06 [103]	15.70 [399]	.30 [8]	32 / 0	32 / 0	185 / 85	50	1000
50034737	CT175500Q	180 / 800	NYLON 6/6	NATURAL	STANDARD	.35 [9]	6.44 [164]	21.75 [552]	.34 [9]	14 / -10	-40 / -40	185 / 85	25	1000
10023523	CT175600Q	175 / 778	NYLON 6/6	NATURAL	STANDARD	1.50 [38]	7.18 [182]	25.25 [641]	.34 [9]	-4 / -20	-40 / -40	185 / 85	25	500
10023534	CT175900Q	175 / 778	NYLON 6/6	NATURAL	STANDARD	1.50 [38]	9.75 [248]	33.21 [844]	.34 [9]	-4 / -20	-40 / -40	185 / 85	25	500
10023545	CT1751100Q	175 / 778	NYLON 6/6	NATURAL	STANDARD	1.50 [38]	11.00 [279]	37.25 [946]	.34 [9]	-4 / -20	-40 / -40	185 / 85	25	500
50034738	CT1751500Q	175 / 778	NYLON 6/6	NATURAL	STANDARD	1.50 [38]	14.50 [368]	48.56 [1233]	.34 [9]	-4 / -20	-40 / -40	185 / 85	25	500
10023569	CT175900Q00	175 / 778	NYLON 6/6	UV BLACK	STANDARD	1.50 [38]	9.75 [248]	33.21 [844]	.34 [9]	-4 / -20	-40 / -40	185 / 85	25	500
50034739	CT175500Q0	180 / 800	NYLON 6/6	UV BLACK	STANDARD	.35 [9]	6.44 [164]	21.75 [552]	.34 [9]	14 / -10	-40 / -40	185 / 85	25	1000
10023571	CT175600Q0	175 / 778	NYLON 6/6	UV BLACK	STANDARD	1.50 [38]	7.18 [182]	25.25 [641]	.34 [9]	-4 / -20	-40 / -40	185 / 85	25	500
50034740	CT175800Q0	175 / 778	NYLON 6/6	UV BLACK	STANDARD	1.50 [38]	9.75 [248]	33.21 [844]	.34 [9]	-4 / -20	-40 / -40	185 / 85	25	500
10023573	CT1751100Q0	175 / 778	NYLON 6/6	UV BLACK	STANDARD	1.50 [38]	11.00 [279]	37.25 [946]	.34 [9]	-4 / -20	-40 / -40	185 / 85	25	500
10023574	CT1751400Q0	175 / 778	NYLON 6/6	UV BLACK	STANDARD	1.50 [38]	14.50 [368]	48.56 [1233]	.34 [9]	-4 / -20	-40 / -40	185 / 85	25	500
10023575	CT250600Q	270 / 1200	NYLON 6/6	NATURAL	STANDARD	.35 [9]	6.61 [168]	22.80 [581]	.48 [13]	14 / -10	-40 / -40	185 / 85	25	500
10023586	CT250800Q	270 / 1200	NYLON 6/6	NATURAL	STANDARD	.35 [9]	8.50 [216]	29.00 [737]	.47 [12]	14 / -10	-40 / -40	185 / 85	25	500
10023597	CT2501000Q	270 / 1200	NYLON 6/6	NATURAL	STANDARD	.35 [9]	10.35 [263]	34.90 [887]	.47 [12]	14 / -10	-40 / -40	185 / 85	25	500
10023619	CT250600Q0	270 / 1200	NYLON 6/6	UV BLACK	STANDARD	.35 [9]	6.61 [168]	22.80 [581]	.48 [13]	14 / -10	-40 / -40	185 / 85	25	500
10023620	CT250800Q0	270 / 1200	NYLON 6/6	UV BLACK	STANDARD	.35 [9]	8.50 [216]	29.00 [737]	.47 [12]	14 / -10	-40 / -40	185 / 85	25	500
50027395	CTHS120400M	120 / 534	NYLON 6/6 HEAT STABILIZED	HS UV BLACK	STANDARD	.18 [5]	4.00 [102]	15.09 [383]	.30 [8]	-4 / -20	-40 / -40	257 / 125	1000	1000

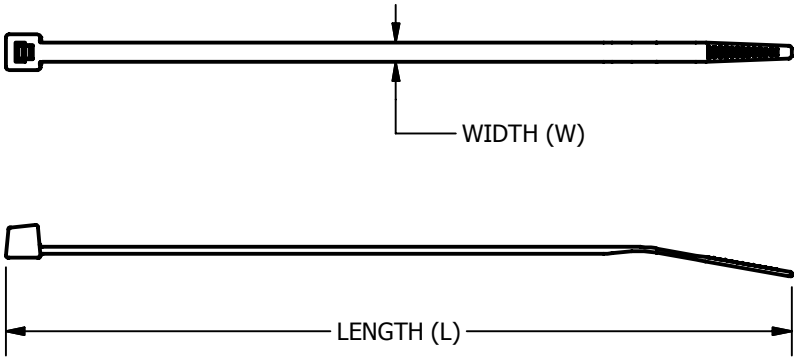

STANDARD

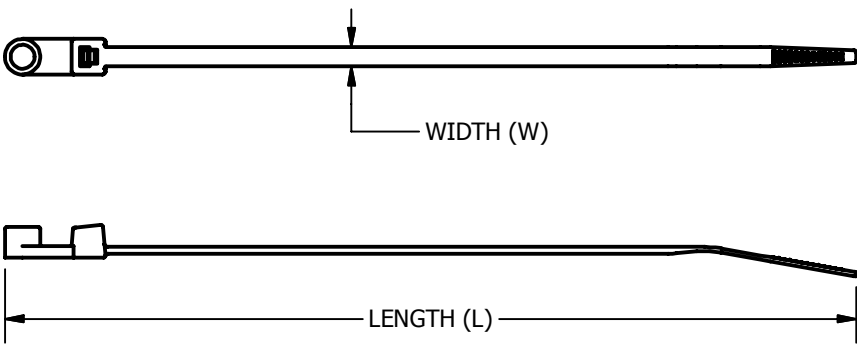

MTG HOLE

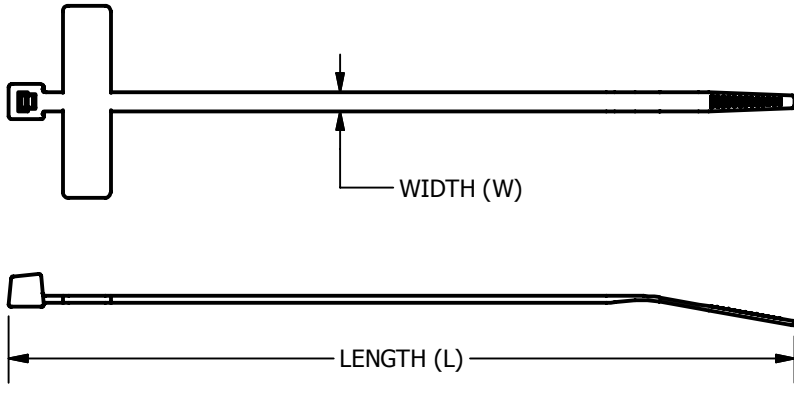

IDENTIFICATION

NOTES:

1. DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE SPECIFIED AND ARE FOR REFERENCE ONLY.

REV	DATE	DESCRIPTION	ECO	BY	C'H'K.
C	12/12/2017	TABLE DETAILS UPDATED	48171	PB	DD

TO ORDER BURNDY® PRODUCTS CALL						UNIRAP™					
UNITED STATES						ITEM NO: SEE TABLE					
1-800-346-4175 (LONDONDERRY, NH)						CAT. NO: SEE TABLE					
CANADA:						DRAWN BY: D DHEENA	3/8/2017				
1-800-361-6975 (QUEBEC)						CHECKER: K BOUTIN	4/5/2017				
1-800-387-6487 (ALL OTHER PROVINCES)						DSN APRVL: A MONTMINY	3/29/2017				
FOR PRODUCT INFO: http://www.burndy.com						MFG APRVL: --					
						QA APRVL: B POST	3/20/2017				
						MKT APRVL: K BOUTIN	4/5/2017				
						PROD FAM: --		DRAWING NO		REV	
						PROJECT #: --		SIZE		50080813	
						DOCUMENT TYPE: SALES		B		C	
						REL LEVEL: Released				SHEET 5 OF 5	