

## PRODUCT SPECIFICATIONS



MODEL NO.	MOTOR	RPM		RUNNING AMPS		STARTING AMPS (0-500 RPM)		HP	kW	NET WT.		CAPACITOR	
		60HZ	50HZ.	60HZ	50HZ.	60HZ	50HZ.			lbs.	kg	mfd.	VOLT
DOA-P701-AA	115V	1575	N/A	4.5	N/A	5.1	N/A	1/8	.09	14.38	6.54	N/A	N/A

**SOUND LEVEL** LESS THAN 70 db(A)  
**NORMAL AMBIENT** +5 °C - +40 °C  
**RELATIVE HUMIDITY** 20% - 80%  
**ENVIRONMENT** CLEAN DUST FREE

**NOTES:**

1. ALL DIMENSIONS ARE FOR REF. USE ONLY.
2. PRODUCT DIMENSIONS: U.S. IMPERIAL (INCHES), METRIC (mm).
3. TECHNICAL DATA SUBJECT TO CHANGE WITHOUT NOTICE.

### PRODUCT PERFORMANCE:

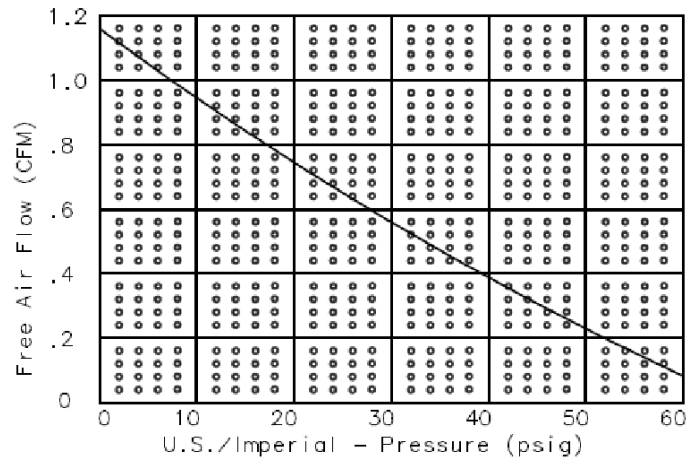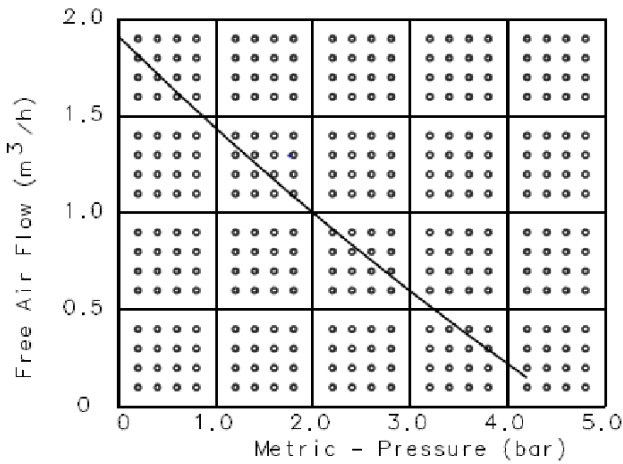

### PRODUCT DIMENSIONS:

