


HIGH PERFORMANCE • OSHA GUARDS • CORROSION RESISTANT

IDEAL FOR ALL AGRICULTURAL APPLICATIONS

FEATURES





- Single speed, totally enclosed, sealed ball bearing, thermally protected, high efficiency, dual voltage, 115/230V.
- High volume, corrosion resistant blades.
- Polyester powder coated, steel wire guard to OSHA specifications.
- Galvanized Steel adjustable three way mount. Mount to wall, ceiling or overhead joist. Fan can pivot down and swivel left and right for pin-point control of air stream.
- Fan head comes pre-assembled to guarantee fan blade is in proper location on motor shaft for max performance and safety within the guard.
- Can operate with Canarm's manual or automatic thermostatic controls (sold separately)
- The fans should move air from the inlets towards the exhaust fans and into all areas to remove dead air pockets. The airstream should be directed across the back of the head and shoulders of the animals.
- Suitable for buildings with low ceilings.

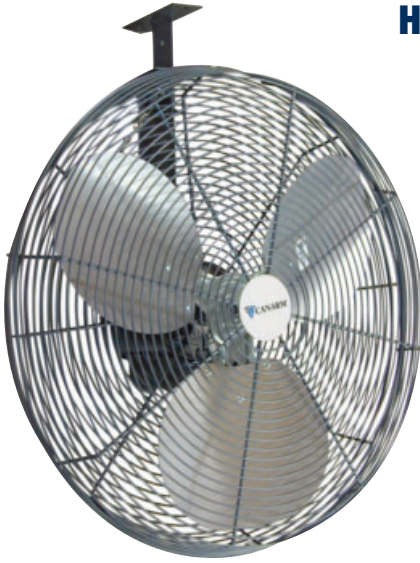

PERFORMANCE DATA & SPECIFICATIONS

Model Number	Size	HP	RPM/Speed	CFM	CFM / W	Voltage	Amps	Weight (lbs.)
CA20AG-FVD	20"	1/3	1625 / Single speed	3,440	-	115/230V	4.2/2.1	37

MOUNTING OPTIONS

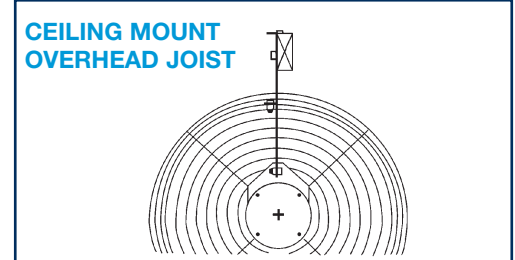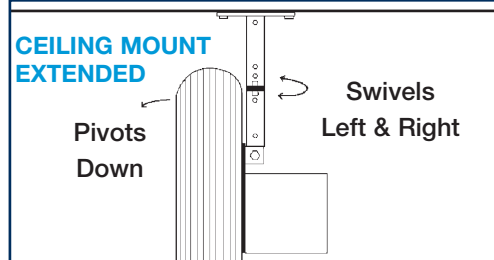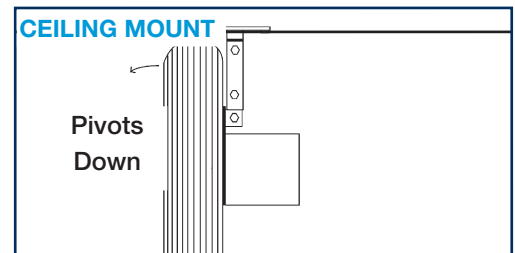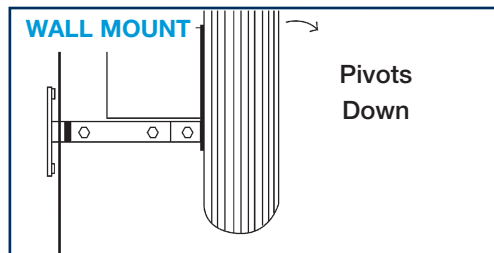

VELOCITY MAPPING CHART

Chart indicates the air distribution pattern. It is a graphic illustration of air velocity in feet per minute.

