


8AWG

GBC007

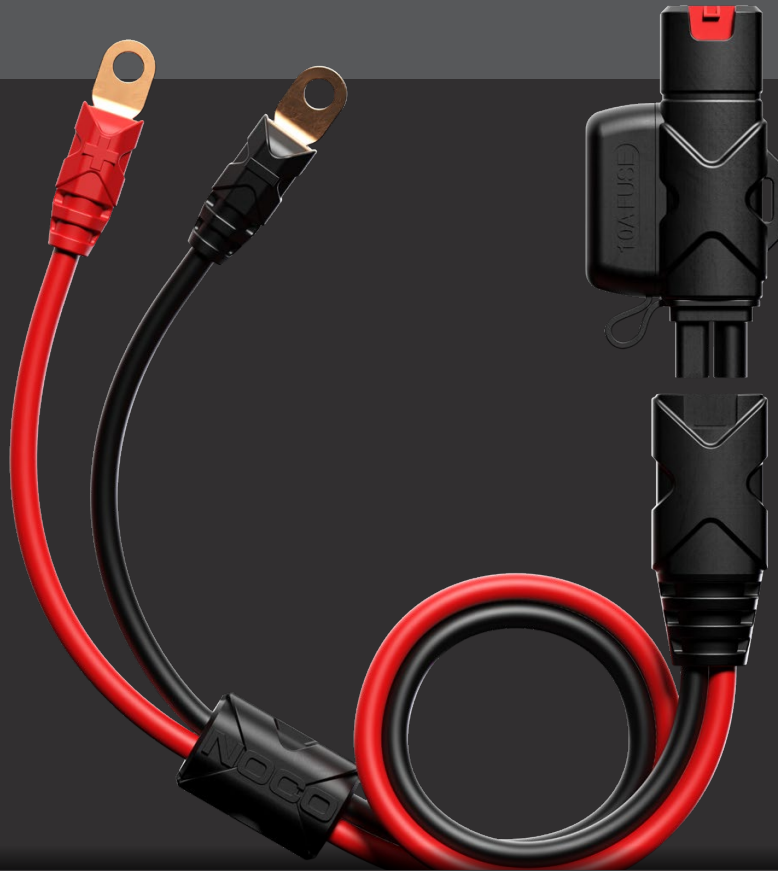

CONNECT BOOST AND GENIUS. EYELET CABLE AND X-CONNECT ADAPTER.

DESIGNED FOR
NOCO BOOST® & **NOCO genius®**

COMPATIBLE BOOST:

GB20 GB50 GB40 GXB45

COMPATIBLE GENIUS:

GENIUS1 GENIUS5 GENIUS2X2

GENIUS2 GENIUS10 GENIUS2X4

+ PREVIOUS G SERIES MODELS.

G750 G3500

G1100 G7200



NOCO®

30339 Diamond Parkway, #102
Glenwillow, OH 44139 | USA
1.800.456.6626

no.co

RUGGED.
FOR EXTREME ENVIRONMENTS.

HEAVY DUTY DESIGN.
Dirt, Water, UV and Impact resistant.

MAXIMUM PERFORMANCE.

Made from durable, heat stabilized 8AWG silicone wire that maintains its flexibility in cold weather environments. The eyelets include a lie-flat design for seamless installations with M6 (1/4-inch) hole size.


QUICK AND EASY TRANSITIONS.
MAXIMUM PERFORMANCE.



MADE FOR BOOST.

Heavy-duty battery eyelet cable with charger adapter designed to be hard-mounted and left for convenience. Compatible with GB20, GB40, GB50, and GBX45 NOCO Boost UltraSafe Lithium Jump Starters.

WHAT'S IN THE BOX

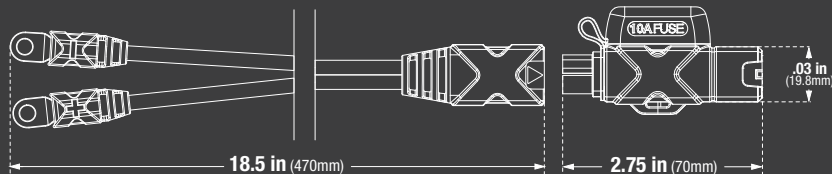

TECHNICAL SPECIFICATIONS

WIRE SIZE:	8 AWG
INPUT:	Boost Female Connector & X-Connect Connector
OUTPUT:	Heavy Duty Eyelets (1/4-Inch M6)
WEIGHT:	0.42 lbs (.19kg)
VOLUMETRICS:	Retail Packaging: Dimensions: 1.6"x5.1"x3.2" Weight: 0.50 lbs UPC: 0-46221-16017-8 Master Carton: Dimensions: 11.3"x11.9"x11.6" Weight: 20.48 lbs Quantity: 36 UCC: 10046221160175 Inner Carton: Dimensions: 1.8"x5.4"x3.5" Weight: 0.55 lbs Units Per Pallet: 3,456 Units

COMPATIBLE PRODUCTS

BOOST JUMP STARTERS:	GB20, GB40, GB50, GBX45
GENIUS CHARGERS:	GENIUS1, GENIUS2, GENIUS5, GENIUS10, GENIUS2X2, GENIUS2X4, G750, G1100, G3500, G7200

NOCO

30339 Diamond Parkway, #102
Glenwillow, OH 44139 | USA
1.800.456.6626

no.co