



Shown actual size: Maestro dimmer and 1-gang Claro wallplate in White (WH).

Product family features

- True multi-location dimming from every location
- Tap on to preset level; tap off; tap twice for full on; touch rocker to adjust light level
- LEDs indicate light level and glow softly in the dark
- Delayed off provides light as you exit the room
- Programming allows customized functions
- LED+, ELV, and PRO models available
- Coordinating Claro, Satin Colors, and Stainless Steel wallplates only available separately
- All models must be derated unless otherwise noted. Visit lutron.com/multigang for more information.

Direct load type compatibility

- Dimmable LED/CFL lighting (screw-base)
- Incandescent/halogen lighting
- Magnetic low-voltage lighting
- Electronic low-voltage lighting
- LED lighting
- Fluorescent lighting
- Switched lighting/motor

Load type requiring load interface

- Neon/cold cathode lighting
- Lighting load interfaces may be required for some load type, voltage, and capacity combinations. For additional information see "Lighting Load Interfaces."


Control types

- Single-pole (1 location)
- 3-way (2 locations)
- Multi-location (up to 10 locations)


Available finishes

Use **BOLD** color code in model number (Example: MA-600-**BR**)

Gloss

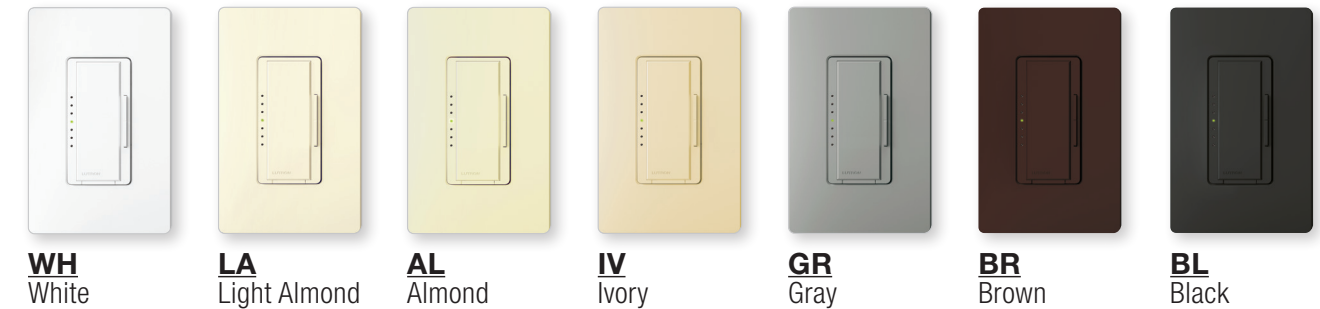

Satin Colors

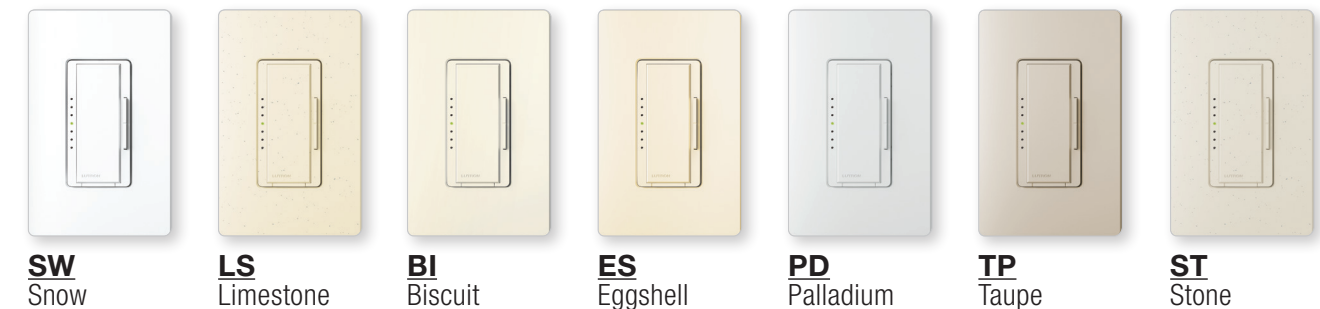

* Stainless Steel metal wallplate only available separately and includes black plastic trim/adaptor, visible from side. Match with separate Black (BL) or Midnight (MN) controls.

Dual digital-fade dimmer

(two loads)



Dimmers (top/bottom)

- Replacement for stacked switches
- Tap on to preset light level; tap off
- Tap twice for full on
- Single location only
- Dimmer advanced programming features available

Dual digital-fade dimmer/ electronic switch

(two loads)



Dimmer (top)

- Replacement for stacked switches
- Tap on to preset light level; tap off
- Tap twice for full on
- Dimmer advanced programming features available

Switch (bottom)

- Tap switch on/off
- Single location only

Dual digital fade dimmer/countdown timer control switch

(two loads)



Dimmer (top)

- Tap on to preset light level; tap off; tap twice for full on

Timer switch (bottom)

- Tap on to start timer; tap off; tap twice for untimed on
- Touch rocker to adjust countdown time from 5–60 minutes
- 1-minute warning before lights go off
- Top LED is full on with no timer action
- Single location only
- Timer advanced programming features available

Fan/light controls



- Tap on to preset light level/fan speed; tap off
- Four fan speeds plus off
- Indicator lights display light level and fan speed
- No canopy module required
- Requires separate wires for fan and light

Incandescent/halogen dimmer and incandescent/halogen dimmer

Dual digital fade dimmer (two loads)

Single-pole MA-L3L3-**XX**¹
120V 300W dimmer (top)
Incandescent/halogen
120V 300W dimmer (bottom)
Incandescent/halogen

Incandescent/halogen dimmer and switch

Dual digital fade dimmer/electronic switch
(two loads)

Single-pole MA-L3S25-**XX**¹
120V 300W dimmer (top)
Incandescent/halogen
2.5A light/fan switch (bottom)
Switch rated for: incandescent/halogen, magnetic
low-voltage, electronic low-voltage, CFLs,
fluorescents, and general purpose fans.

Incandescent/halogen dimmer and timer

Dual digital fade dimmer/countdown timer
control switch (two loads)

Single-pole MA-L3T251-**XX**¹
120V 300W dimmer (top)
Incandescent/halogen
2.5A light/fan timer switch (bottom)
Timer rated for: incandescent/halogen, magnetic
low-voltage, electronic low-voltage, CFLs,
fluorescents, and general purpose fans.

Fan/light controls

Fan/light controls—quiet 4-speed

Single-pole MACL-LFQ-**XX**¹
120V 1.5A fan
120V 75W LED/CFL
250W Incandescent/halogen
Visit lutron.com/LEDfinder for our online
compatibility tool.
Adjustable low-end trim.

XX¹: Gloss and Satin color codes
Wallplates not included. Order separately.

XX¹: Gloss and Satin color codes
Wallplates not included. Order separately.