



**MCR
SAFETY**

9674 UltraTech Dipped Specification Sheet

PRODUCT DESCRIPTION:

The next generation of gloves requires the next generation in manufacturing. MCR Safety's state-of-the-art manufacturing facility produces premium NXG® brand gloves with advanced coatings, utilizes 21st-century manufacturing efficiencies, and does so with environmentally friendly production methods. Our NXG® styles are well suited for Multi-Industrial applications that require high dexterity and comfort and are manufactured on seamless knit liners that are flat dipped to reproduce the natural curved shape of the hand. As a result, workers benefit from less hand fatigue and greater productivity while performing detailed tasks to heavy duty jobs. The 9674 features a seamless 15 gauge white nylon shell and a gray nitrile foam coated palm and fingertips that will enhance wet or dry gripping power. It can also be used as a touch screen glove. If you are looking for the best work gloves, be sure to check out MCR Safety's NXG® options! To learn more, [visit our NXG® landing page here.](#)



FEATURES:

- 15 gauge white nylon shell
- Gray nitrile foam coated palm and fingertips
- Excellent comfort, fit, and grip
- Greater dexterity
- Good abrasion resistance
- Touchscreen friendly
- Treated with ActiFresh®

APPLICATIONS:

First responder, Assembly Line Production, Carpentry, Construction, Landscaping, Material Handling, Warehousing

TECHNICAL DATA FOR: 9674

Series	UltraTech	EN 388: CE Score - Abrasion	3
Material Group	Strings	EN 388 : CE Score - Cut	1
Product Type	Dipped	EN 388 : CE Score - Tear	3

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2021 MCR Safety - All Rights Reserved



MCR
SAFETY


9674

UltraTech

Dipped

Specification Sheet

Glove Size	Large	EN 388 : CE Score - Puncture	1
Gauge	15 Gauge	ANSI Puncture	2
Material	Nylon	ANSI Abrasion	4
Made In	Pakistan		

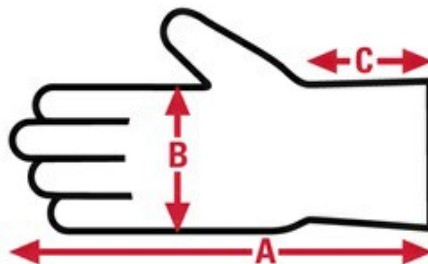

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
9674XS	X - Small	8.66	3.35	2.56	12.648 lb.	1.054
9674S	Small	9.06	3.54	2.76	14.112 lb.	1.176
9674M	Medium	9.45	3.54	2.48	15.444 lb.	1.287
9674L	Large	9.84	3.94	2.36	17.856 lb.	1.488
9674XL	X - Large	10.43	3.82	2.95	18.324 lb.	1.527

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2021 MCR Safety - All Rights Reserved