



KT-LED18PAR38-X-8XX

REPLACEMENT LAMP

DESCRIPTION

18W Commercial PAR38 Lamp | 3000–5000K | >80 CRI | Narrow Flood or Standard Flood



LAMP TYPE: Commercial PAR38
BASE TYPE: E26 (Medium)
WATTAGE: 18W
COLOR TEMPERATURE: 3000–5000K
COLOR RENDERING INDEX (CRI): > 80
WARRANTY: 5 Years



PRODUCT FEATURES

- Up to 75% energy saving compared to legacy equivalent lamps
- Can be used in base-up or base-down position
- Rated for open and recessed fixtures
- Large metal heatsink for optimal heat dissipation
- THD < 20%
- PF > 0.90
- Operating temperature range –4°F/–20°C to 113°F/45°C
- Ideal for recessed corridor and high-power flood lighting
- Suitable for dry and damp location
- UL 1993 and 1598C Rated

ELECTRICAL AND PERFORMANCE SPECIFICATIONS


Keystone Catalog Number	Description	Color Temp	Input Voltage	Rated Lamp Wattage	Legacy Equivalent Wattage	Base Type	Lumens	CRI	Light Distribution	Dimmable	Efficacy
KT-LED18PAR38-NF-830	Commercial PAR38 bulb. Universal input voltage, Narrow flood, Non-dimmable	3000K	120–277V	18W	100W halogen	E26	1950 L	>80	25	No	108 lm/W
KT-LED18PAR38-NF-840	Commercial PAR38 bulb. Universal input voltage, Narrow flood, Non-dimmable	4000K	120–277V	18W	100W halogen	E26	2060 L	>80	25	No	114 lm/W
KT-LED18PAR38-NF-850	Commercial PAR38 bulb. Universal input voltage, Narrow flood, Non-dimmable	5000K	120–277V	18W	100W halogen	E26	2100 L	>80	25	No	114 lm/W
KT-LED18PAR38-F-830	Commercial PAR38 bulb. Universal input voltage, Standard flood, Non-dimmable	3000K	120–277V	18W	100W halogen	E26	1950 L	>80	40	No	108 lm/W
KT-LED18PAR38-F-840	Commercial PAR38 bulb. Universal input voltage, Standard flood, Non-dimmable	4000K	120–277V	18W	120W halogen	E26	2060 L	>80	40	No	114 lm/W
KT-LED18PAR38-F-850	Commercial PAR38 bulb. Universal input voltage, Standard flood, Non-dimmable	5000K	120–277V	18W	120W halogen	E26	2100 L	>80	40	No	114 lm/W



KT-LED18PAR38-X-8XX

REPLACEMENT LAMP

PHYSICAL CHARACTERISTICS

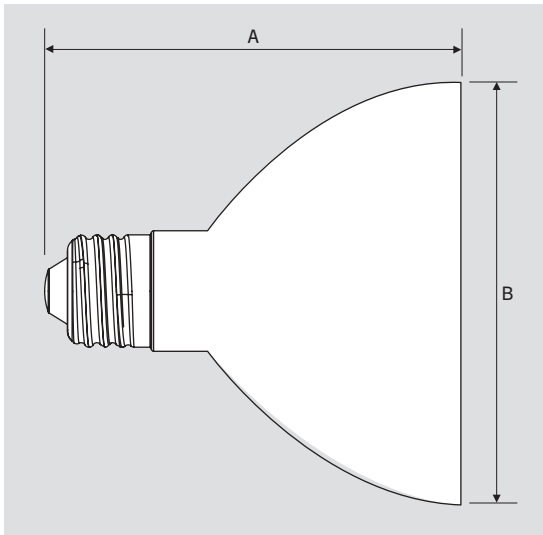

RATED LIFE

L70 (Hours)	50,000
-------------	--------

PACKAGING

Carton Quantity	12 pcs
Carton Dimensions	17.72" x 12" x 13"
Carton Weight	20.84 lbs

LAMP DIMENSIONS

A (Length)	5.03"
B (Diameter)	4.73"

BASE TYPE: E26 (Medium)

ORDERING INFORMATION

ORDER CODE	PACK QTY.	EASY CODE	UPC
KT-LED18PAR38-NF-830	TBD	AVN-59	843654122946
KT-LED18PAR38-NF-840	TBD	WMH-86	843654122953
KT-LED18PAR38-NF-850	TBD	LHR-73	843654122960
KT-LED18PAR38-F-830	TBD	YBY-12	843654122977
KT-LED18PAR38-F-840	TBD	UNW-29	843654122984
KT-LED18PAR38-F-850	TBD	EAR-65	843654122991

CATALOG NUMBER BREAKDOWN

KT-LED18PAR38-X-8XX

1 2 3 4 5 6 7 8

- 1 Keystone Technologies
- 2 LED Lamp
- 3 Wattage
- 4 Parabolic Aluminized Reflector
- 5 4.75" Diameter
- 6 Narrow Flood (NF) or Standard Flood (F)
- 7 800 Series
- 8 Color Temperature