

Bushings, nipples, locknuts and plugs

Chase® nipples



- Bush holes in metal boxes or enclosures
- 3/8" and 1/2" sizes in steel
- 3/4" to 6" sizes in malleable iron
- 1/2" to 4" sizes in copper-free aluminum

Options

- 1/2"–4" sizes in stainless steel 316 (add suffix SST)
- cULus listed

Stainless steel version coming soon




- Nylon insulator offers extra protection
- 3/8" and 1/2" sizes in steel
- 3/4" to 6" sizes in malleable iron
- 1/2" to 6" sizes also available in copper-free aluminum (add AL suffix to cat. no.)
- Look for the unique blue color ensuring the highest quality fitting

Chase nipples



Cat. no.	Size (in.)	Dimensions (in.)	
		A	B
Steel/malleable iron or stainless steel 316*			
841TB	3/8	15/16	7/16
842TB	1/2	1 5/32	11/32
843TB	3/4	1 7/16	17/32
844	1	1 25/32	21/32
845	1 1/4	2 1/32	3/4
846	1 1/2	2 3/8	13/16
847	2	2 15/16	31/32
848	2 1/2	3 9/16	1 1/16
849	3	4 3/8	1 3/16
850	3 1/2	5 1/8	1 5/16
851	4	5 7/8	1 5/16
853	5	6 13/32	1 5/16
854	6	7 3/8	1 3/8
Aluminum			
842AL†	1/2	1 3/16	7/16
843AL	3/4	1 13/32	17/32
844AL†	1	1 21/32	21/32
845AL†	1 1/4	2 1/32	3/4
846AL	1 1/2	2 3/8	13/16
847AL	2	2 15/16	31/32
848AL	2 1/2	3 9/16	1 1/16
849AL	3	4 3/8	1 3/16
850AL	3 1/2	5 1/8	1 5/16
851AL	4	5 7/8	1 5/16


Diagram

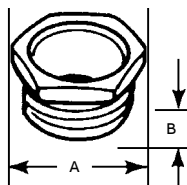

Chase nipples – Nylon-insulated

Cat. no.	Size (in.)	Dimensions (in.)		
		A	B	C
1942	1/2	1 9/64	7/16	19/32
1943	3/4	1 3/8	17/32	23/32
1944	1	1 11/16	21/32	7/8
1945	1 1/4	2 1/32	25/32	1 1/32
1946	1 1/2	2 3/8	13/16	1 3/32
1947	2	2 15/16	31/32	1 11/32
1948	2 1/2	3 9/16	1 1/16	1 7/16
1949	3	4 3/8	1 3/16	1 19/32
1950	3 1/2	5 1/8	1 5/16	1 25/32
1951	4	5 7/8	1 5/16	1 13/16
1953	5	6 3/8	1 5/16	1 13/16
1954	6	7 3/8	1 3/8	1 7/8

Diagram

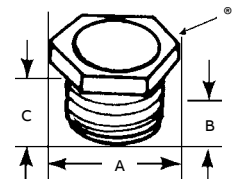

UL File No. E-23018
CSA File No. 2884

*Add suffix SST to catalog number to order stainless steel 316.

† Not UL listed

Available with DURA-PLATE® finish.

UL File No. E-23018

CSA File No. 2884

Stainless steel is cULus listed (file no. E23018)