



EAN: 4013288173881
Part number: 05004078001
Article number: 8100 SC 8

Size: 325x145x65 mm
Weight: 2880 g
Country of origin: CZ
Customs tariff number: 82041100

- Convenient direction change thanks to switchover lever
- Extremely slim ratchet with long lever
- Return angle of only 5°
- With Take it easy tool finder: colour coding by size

Incredibly compact set arrangement with many tools in a minimum of space. A completely new ratchet set feeling thanks to the unique textile boxes that are very robust and durable. They can be positioned upright for tidy storage on the workshop shelf. Additional surface protection due to textile outer material. Low weight and volume for simpler mobility. Take it easy Tool Finder with colour coding according to sizes.




Web link
<https://www.wera.de/en/05004078001>

Wera - 8100 SC 8
05004078001 - 4013288173881

Wera Werkzeuge GmbH
Korzerter Straße 21-25
D-42349 Wuppertal
Tel: +49 (0)2 02 / 40 45-0
E-Mail: info@wera.de

Zyklop Metal Switch

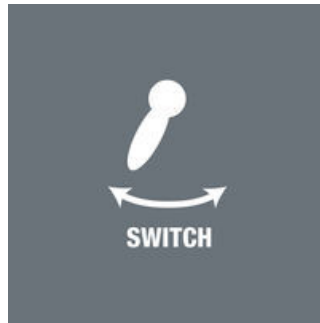

Due to the ever-more confined working environment, space is becoming more and more an issue for the application of ratchets. Our product developers therefore intensively occupied themselves with the issue of confined working spaces, and Wera has now solved this problem. The extremely slim and robust Zyklop Metal ratchet with a long lever was what emerged. When the change in direction needs to be quick, the Zyklop Metal Switch ratchet is the right tool. When the socket must not get lost and a coincidental change of direction has to be avoided at all cost, the Zyklop Metal Push is the correct choice.

The Zyklop Ratchet Metal Switch



Extremely slim. Long leverage. With switch lever.

Reversible



Switch lever for convenient change of direction.

Small return angle



Fine-pitched with 72 teeth for a return angle of only 5°

Take it easy tool finder system



Take it easy tool finder system - with profile and size colour-coding for quick and easy tool selection. Colour-coded system for hexagon drive screws (L-Keys, Zyklop bit sockets), external hex drive screws and nuts (Joker wrenches, Zyklop sockets and Zyklop bit sockets with holding function), and TORX® drive screws (L-Keys, Zyklop bit sockets).

Textile boxes



The textile boxes offer dramatically improved portability, and are space-saving to boot! This means you can now carry the same collection of tools, in a much more compact and comfortable package. The hassle of running back and forth for the right tools has now become a thing of the past. And the much lower weight of a set makes carrying more convenient than ever before. The textile box including the tool will even survive a fall undamaged.

Zyklop Metal Switch



Forged, full metal ratchet (chrome-molybdenum) that is extremely robust with a long service life; slim design to enable work in very confined spaces.

Web link

<https://www.wera.de/en/05004078001>

Wera - 8100 SC 8

05004078001 - 4013288173881

Wera Werkzeuge GmbH

Korzerter Straße 21-25

D-42349 Wuppertal

Tel: +49 (0)2 02 / 40 45-0

E-Mail: info@wera.de

Set contents:

8004 C Zyklop Metal Ratchet with switch lever and 1/2" drive, 1/2" x 281 mm

	05004064001	1x 1/2" x 281 mm
---	-------------	------------------

8790 HMC Zyklop socket with 1/2" drive, 10 x 37 mm

	05003601001	1x 10 x 37 mm
	05003602001	1x 11 x 37 mm
	05003603001	1x 12 x 37 mm
	05003604001	1x 13 x 37 mm
	05003605001	1x 14 x 37 mm
	05003606001	1x 15 x 37 mm
	05003607001	1x 16 x 37 mm
	05003608001	1x 17 x 37 mm
	05003609001	1x 18 x 37 mm
	05003610001	1x 19 x 37 mm

8794 LC Zyklop extension with free-turning sleeve, long, 1/2", 1/2" x 250 mm

	05003638001	1x 1/2" x 250 mm
---	-------------	------------------

8794 C Zyklop wobble extension, 1/2", 1/2" x 52 mm

	05003639001	1x 1/2" x 52 mm
--	-------------	-----------------

8784 C2 Zyklop bit adaptor, 1/2", 5/16", 5/16" x 1/2" x 50 mm

	05003641001	1x 5/16" x 1/2" x 50 mm
---	-------------	-------------------------

851/2 Z bits, PH 2 x 32 mm

	05057710001	1x PH 2 x 32 mm
	05057715001	1x PH 3 x 32 mm

867/2 Z TORX® bits, TX 20 x 35 mm

	05066901001	1x TX 20 x 35 mm
	05066900001	1x TX 25 x 35 mm
	05066905001	1x TX 30 x 35 mm
	05066910001	1x TX 40 x 35 mm
	05066915001	1x TX 45 x 35 mm
	05066920001	1x TX 50 x 35 mm
	05066902001	1x TX 27 x 35 mm
	05066925001	1x TX 55 x 35 mm

Web link

<https://www.wera.de/en/05004078001>

Wera - 8100 SC 8
05004078001 - 4013288173881

Wera Werkzeuge GmbH
Korzerter Straße 21-25
D-42349 Wuppertal
Tel: +49 (0)2 02 / 40 45-0
E-Mail: info@wera.de

Web link
<https://www.wera.de/en/05004078001>

Wera - 8100 SC 8
05004078001 - 4013288173881

Set contents:

8004 C Zyklop Metal Ratchet with switch lever and 1/2" drive, 1/2" x 281 mm



05004064001 1x 1/2" x 281 mm

8790 HMC Zyklop socket with 1/2" drive, 10 x 37 mm


05003601001 1x 10 x 37 mm
05003602001 1x 11 x 37 mm
05003603001 1x 12 x 37 mm
05003604001 1x 13 x 37 mm
05003605001 1x 14 x 37 mm
05003606001 1x 15 x 37 mm
05003607001 1x 16 x 37 mm
05003608001 1x 17 x 37 mm
05003609001 1x 18 x 37 mm
05003610001 1x 19 x 37 mm

8794 LC Zyklop extension with free-turning sleeve, long, 1/2", 1/2" x 250 mm



05003638001 1x 1/2" x 250 mm

8794 C Zyklop wobble extension, 1/2", 1/2" x 52 mm



05003639001 1x 1/2" x 52 mm

8784 C2 Zyklop bit adaptor, 1/2", 5/16", 5/16" x 1/2" x 50 mm



05003641001 1x 5/16" x 1/2" x 50 mm

851/2 Z bits, PH 2 x 32 mm


05057710001 1x PH 2 x 32 mm
05057715001 1x PH 3 x 32 mm

867/2 Z TORX® bits, TX 20 x 35 mm


05066901001 1x TX 20 x 35 mm
05066900001 1x TX 25 x 35 mm
05066905001 1x TX 30 x 35 mm
05066910001 1x TX 40 x 35 mm
05066915001 1x TX 45 x 35 mm
05066920001 1x TX 50 x 35 mm
05066902001 1x TX 27 x 35 mm
05066925001 1x TX 55 x 35 mm

840/2 Z Bits, 5 x 30 mm


05057515001 1x 5 x 30 mm
05057520001 1x 6 x 30 mm
05057525001 1x 8 x 30 mm
05057530001 1x 10 x 30 mm

Web link

<https://www.wera.de/en/05004078001>

Wera - 8100 SC 8
05004078001 - 4013288173881

Wera Werkzeuge GmbH
Körzter Straße 21-25
D-42349 Wuppertal
Tel: +49 (0)2 02 / 40 45-0
E-Mail: info@wera.de

Web link
<https://www.wera.de/en/05004078001>

Wera - 8100 SC 8
05004078001 - 4013288173881