

USB Charger Receptacles and Outlets



Weather Resistant Receptacle Features

- Meets Section 406.9 of NEC®
- 5 Amp, 5 Volt USB output
- Type A&C USB ports
- Power indicating green LED light



Weather Resistant USB Charger Duplex Receptacles

Description	Color	15A 125V	20A 125V
Type A&C USB Charger Receptacle, One Type A and one Type-C port configurations, high power 5 Amp, 5 Volt USB output, Tamper-Resistant USB ports rated 10,000 cycles; Commercial Grade	Black	USB15AC5BKWR	USB20AC5BKWR
	Brown	USB15AC5WR	USB20AC5WR
	Gray	USB15AC5GYWR	USB20AC5GYWR
	Ivory	USB15AC5IWR	USB20AC5IWR
	Light Almond	USB15AC5LAWR	USB20AC5LAWR
	White	USB15AC5WWR	USB20AC5WWR


Note: Outdoor circuits should be GFCI protected per national and local electric codes.




Commercial and Hospital Grade USB Charger Tamper-Resistant Duplex Receptacles

Description	Color	Commercial		Hospital Grade	
		15A 125V	20A 125V	15A 125V	20A 125V
Two Type-C port configurations, high power 5 Amp, 5 Volt USB output, Tamper-Resistant duplex receptacle, USB ports rated 10,000 cycles.	Black	USB15C5BK	USB20C5BK	USB8200C5BK	USB8300C5BK
	Brown	USB15C5	USB20C5	USB8200C5	USB8300C5
	Gray	USB15C5GY	USB20C5GY	USB8200C5GY	USB8300C5GY
	Ivory	USB15C5I	USB20C5I	USB8200C5I	USB8300C5I
	Lt. Almond	USB15C5LA	USB20C5LA	USB8200C5LA	USB8300C5LA
	Red	-	-	USB8200C5R	USB8300C5R
	White	USB15C5W	USB20C5W	USB8200C5W	USB8300C5W
One Type A and one Type-C port configurations, high power 5 Amp, 5 Volt USB output, Tamper-Resistant duplex receptacle, USB ports rated 10,000 cycles.	Black	USB15AC5BK	USB20AC5BK	USB8200AC5BK	USB8300AC5BK
	Brown	USB15AC5	USB20AC5	USB8200AC5	USB8300AC5
	Gray	USB15AC5GY	USB20AC5GY	USB8200AC5GY	USB8300AC5GY
	Ivory	USB15AC5I	USB20AC5I	USB8200AC5I	USB8300AC5I
	Lt. Almond	USB15AC5LA	USB20AC5LA	USB8200AC5LA	USB8300AC5LA
	Red	-	-	USB8200AC5R	USB8300AC5R
	White	USB15AC5W	USB20AC5W	USB8200AC5W	USB8300AC5W
Two Type A port configurations, high power 5 Amp, 5 Volt USB output, Tamper-Resistant duplex receptacle, USB ports rated 10,000 cycles.	Black	USB15A5BK	USB20A5BK	USB8200A5BK	USB8300A5BK
	Brown	USB15A5	USB20A5	USB8200A5	USB8300A5
	Gray	USB15A5GY	USB20A5GY	USB8200A5GY	USB8300A5GY
	Ivory	USB15A5I	USB20A5I	USB8200A5I	USB8300A5I
	Lt. Almond	USB15A5LA	USB20A5LA	USB8200A5LA	USB8300A5LA
	Red	-	-	USB8200A5R	USB8300A5R
	White	USB15A5W	USB20A5W	USB8200A5W	USB8300A5W

Note: See page Tech-10 for Tamper-Resistant description.

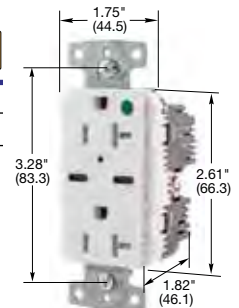

USB8300C5W

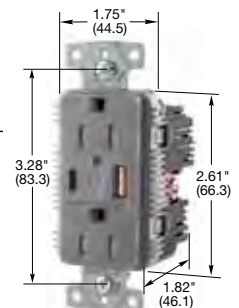

USB15AC5GY

4 Port USB Charger Outlets




Description	Color	Catalog Number
USB Charger Outlets, 4 USB ports, two Type A & two Type-C ports, 5 Amp up to 9 Volt DC, Style Line® decorator.	Black	USB4ACBK
	Brown	USB4AC
	Gray	USB4ACGY
	Ivory	USB4ACI
	Light Almond	USB4ACLA
	White	USB4ACW


Switch Combo Outlets



Description	Color	Catalog Number
Switch Combo Outlet, two USB type 2.0 ports, 2.1 Amp, 5 Volt DC, Style Line® decorator.	Black	USB102BK
	Brown	USB102
	Gray	USB102GY
	Ivory	USB102I
	Light Almond	USB102LA
	White	USB102W

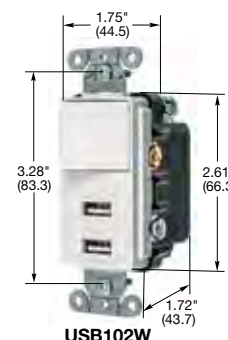

USB102W

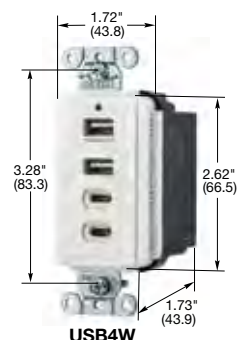

USB4W

NEC® is a registered trademark of the National Fire Protection Association (NFPA).

Dimensions in Inches (mm)

USB Charger Receptacles and Outlets



Weather Resistant Receptacle Features

- Meets Section 406.9 of NEC®
- 5 Amp, 5 Volt USB output
- Type A&C USB ports
- Power indicating green LED light



Weather Resistant USB Charger Duplex Receptacles

Description	Color	15A 125V	20A 125V
Type A&C USB Charger Receptacle, One Type A and one Type-C port configurations, high power 5 Amp, 5 Volt USB output, Tamper-Resistant USB ports rated 10,000 cycles; Commercial Grade	Black Brown Gray Ivory Light Almond White	USB15AC5BKWR USB15AC5WR USB15AC5GYWR USB15AC5IWR USB15AC5LAWR USB15AC5WWR	USB20AC5BKWR USB20AC5WR USB20AC5GYWR USB20AC5IWR USB20AC5LAWR USB20AC5WWR

Note: Outdoor circuits should be GFCI protected per national and local electric codes.



USB15AC5WWR



Standard USB Charger Tamper-Resistant Duplex Receptacles

Description	Color	15A 125V	20A 125V
Type-C USB Charger Receptacle, two Type-C port configurations, high power 5 Amp, 5 Volt USB output.	Black Brown Gray Ivory Light Almond White	USB15C5BK USB15C5 USB15C5GY USB15C5I USB15C5LA USB15C5W	USB20C5BK USB20C5 USB20C5GY USB20C5I USB20C5LA USB20C5W
Type A&C USB Charger Receptacle, one Type A and one Type-C port configuration, high power 5 Amp, 5 Volt USB output.	Black Brown Gray Ivory Light Almond White	USB15AC5BK USB15AC5 USB15AC5GY USB15AC5I USB15AC5LA USB15AC5W	USB20AC5BK USB20AC5 USB20AC5GY USB20AC5I USB20AC5LA USB20AC5W
Type A USB Charger Receptacle, two Type A port configurations, high power 5 Amp, 5 Volt USB output.	Black Brown Gray Ivory Light Almond White	USB15A5BK USB15A5 USB15A5GY USB15A5I USB15A5LA USB15A5W	USB20A5BK USB20A5 USB20A5GY USB20A5I USB20A5LA USB20A5W

Note: See page Tech-10 for Tamper-Resistant description.
See section M for Hospital grade series.



USB15C5W



USB15AC5W



USB20A5W

4 Port USB Charger Outlets

Description	Color	Catalog Number
USB Charger Outlets, 4 USB ports, two Type A & two Type-C ports, 5 Amp up to 9 Volt DC, Style Line® decorator.	Black Brown Gray Ivory Light Almond White	USB4ACBK USB4AC USB4ACGY USB4ACI USB4ACLA USB4ACW



Switch Combo Outlets

Description	Color	Catalog Number
Switch Combo Outlet, two USB type 2.0 ports, 2.1 Amp, 5 Volt DC, Style Line® decorator	Black Brown Gray Ivory Light Almond White	USB102BK USB102 USB102GY USB102I USB102LA USB102W



USB102W



USB4ACW

NEC® is a registered trademark of the National Fire Protection Association (NFPA).