



ESSENTIAL SERIES

GENERAL PURPOSE LED BULBS

KT-LED4.5FB11-E12-822-A

REPLACEMENT LAMP

DESCRIPTION

4.5W B11 Lamp | 2200K | ≥ 80 CRI | Straight-tip Amber Chandelier



Enclosed
Fixture Rated



RoHS
Compliant



LAMP TYPE: Filament B11

BASE TYPE: E12 (Candelabra)

WATTAGE: 4.5W

COLOR TEMPERATURE: 2200K

COLOR RENDERING INDEX (CRI): ≥ 80

WARRANTY: 3 Years

RATED LIFE: L70 (15,000 Hours)



TYPICAL APPLICATIONS

- Chandeliers
- Vanity Fixtures
- Decorative Accent Lighting
- Wall Sconces
- Pendant Lights

PRODUCT FEATURES

- Energy efficient, 80%+ energy savings over legacy equivalents
- Lower heat generation than legacy equivalents
- Smooth, uniform dimming to 10%
- Filament-style LED construction offers unique traditional appearance for decorative and mood-sensitive applications
- Long life minimizes replacement and maintenance costs
- Complies with Part 15 of FCC
- ANSI compliant construction ensures fitment for intended applications
- Suitable for use in wet locations
- Operating temperature range $-4^{\circ}\text{F}/-20^{\circ}\text{C}$ to $95^{\circ}\text{F}/35^{\circ}\text{C}$
- PF > 0.8
- Suitable for use in enclosed fixtures

PERFORMANCE SPECIFICATIONS


Keystone Catalog Number	Base Type	Rated Lamp Wattage	Legacy Equivalent Wattage	Color Temp	Lumens	Efficacy	Input Voltage	CRI	Beam Angle	Dimmable
KT-LED4.5FB11-E12-822-A	E12	4.5W	40W incandescent	2200K	300	67 lm/W	120V	≥ 80	360°	Yes

* Color Uniformity: CCT (Correlated Color Temperature) range as per guidelines outlined in ANSI C78.377-2017

KT-LED4.5FB11-E12-822-A

REPLACEMENT LAMP

PHYSICAL SPECIFICATIONS

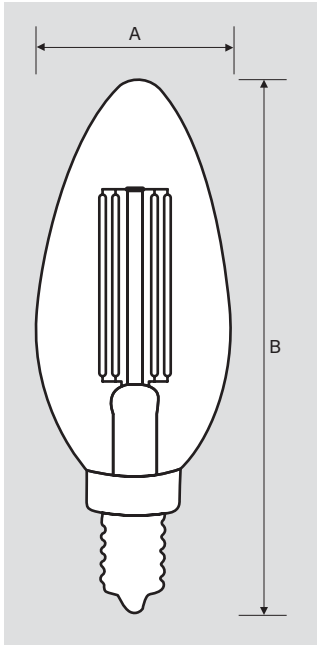

LAMP DIMENSIONS

A (Diameter)	1.38"
B (Length)	3.86"

BASE TYPE: E12 (Candelabra)

PACKAGING

Carton Quantity	24 pcs
Carton Dimensions	13.00" × 5.10" × 4.72"
Carton Weight	2.65 lbs

ORDERING INFORMATION

ORDER CODE	EASY CODE	UPC
KT-LED4.5FB11-E12-822-A	PDE-83	843654129778

CATALOG NUMBER BREAKDOWN

KT-LED4.5FB11-E12-822-A

1 2 3 4 5 6 7 8 9

- 1 Keystone Technologies
- 2 LED Lamp
- 3 Wattage
- 4 Filament Bulb
- 5 Lamp Shape
- 6 Base Type
- 7 80 CRI
- 8 CCT
- 9 Amber Bulb