

EAN:	4013288101488	Size:	105x65x25 mm
Part number:	05104634001	Weight:	27 g
Article number:	846 HSS	Country of origin:	CN
		Customs tariff number:	82075060

- Hex shaft for very good power transfer
- Finely-tuned material elasticity for great durability
- Very good centring properties
- Perfect chip removal
- Precise return movement

High quality 3-flute countersink bit for deburring, chamfering and countersinking. A finely-tuned material elasticity provides for great durability. Perfect chip removal and a low tilt risk ensure pleasant working. Cutting section as per DIN 335-C, 90° with 3 cutters. ¼" hexagon, suitable for holders with take-up as per DIN ISO 1173-D 6.3.

Web link

<https://www.wera.de/en/05104634001>

Wera - 846 HSS

05104634001 - 4013288101488

Wera Werkzeuge GmbH


Korzter Straße 21-25

D-42349 Wuppertal

Tel: +49 (0)2 02 / 40 45-0



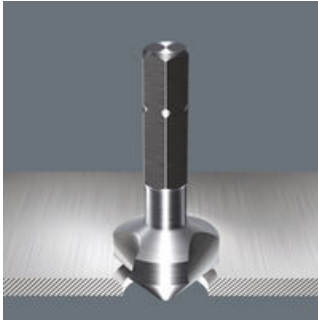

E-Mail: info@wera.de

3-flute countersink bits



3-flute countersink bits,
 90°Application:
 Deburring, chamfering and
 countersinking1/4" drive
 suitable for holders as per DIN
 3126-D 6.3 (ISO
 1173)Hexagon shaft for
 very high torque
 transferHSS = high
 speed steelFinely
 adjusted material elasticity for long
 service life3
 tipsExcellent centring
 propertiesStraightforward
 cuttingPerfect chip
 removalLow jamming
 riskPrecise return
 controlHigh corrosion
 protection

Further versions in this product family:

				
	mm	mm	mm	
05104630001	6.30	20.00	31.0	M 3
05104631001	8.30	20.00	31.0	M 4
05104632001	10.40	20.00	34.0	M 5
05104633001	12.40	20.00	35.0	M 6
05104634001	16.50	20.00	40.0	M 8
05104635001	20.50	20.00	41.0	M 10

Web link

<https://www.wera.de/en/05104634001>

Wera - 846 HSS
 05104634001 - 4013288101488

Wera Werkzeuge GmbH
 Korzter Straße 21-25
 D-42349 Wuppertal
 Tel: +49 (0)2 02 / 40 45-0
 E-Mail: info@wera.de