



MY6 EYESHIELD

ADAPTABILITY & PERFORMANCE

Experience unmatched performance with MY6, the ultimate ballistic eyeshield designed for mission-critical scenarios. Crafted with precision, it integrates advanced features to enhance your performance and ensure optimal visual clarity, comfort and style. Our exclusive PLATINUM technology guarantees a clear line of sight, even in challenging environments, while its superior ballistic impact resistance allows MY6 to withstand even the most extreme situations. Tailor your eyeshield to your preferences with our diverse range of CSP lens tint options, empowering you to make precise decisions with unwavering confidence. MY6 offers a secure and comfortable fit, enabling agile and assured movements during any operation. While your team relies on you to watch their backs, trust us to safeguard your eyes every step of the way.

SUPPLIED WITH : KIT (Box, case, microfiber pouch, user instruction)

 **1.305 OZ**

**+ HIGH-IMPACT BALLISTIC PROTECTION:
MIL & STANAG**

**+ PLATINUM COATING : ANTI-SCRATCH
& ANTI-FOG**

+ NON-SLIP ADJUSTABLE NOSE BRIDGE

**+ THIN AND COMFORTABLE TEMPLES
COMPATIBLE WITH COMMUNICATIONS
SYSTEMS AND BALLISTIC HELMETS**



TECHNOLOGIES

CSP
PLATINUM

VERSIONS



MY6EST10W

MY6EST00W



MY6EST20W

MY6EST02W



MY6EST30W

MY6EST01W



MY6EST31W

MY6EST03W



MY6EST32W

MY6EST04W



MY6EST70W

MY6EST72W



MY6EST71W

MY6EST05W



MY6 EYESHIELD

REFERENCE	VERSION	LENS MARKING	FRAME MARKING	BALLISTIC RESISTANCE V50 STANAG 2920	MIL-PRF	COATING
MY6EST10W	CLEAR	Z87+ U6 X	Z87+ CSA Z94.3	221,3 M/S	32432A	PLATINUM
MY6EST20W	SMOKE	Z87+ U6 L3 X	Z87+ CSA Z94.3	226,6 M/S	32432A	PLATINUM
MY6EST30W	MTO* COPPER	Z87+ U6L1.5 X	Z87+ CSA Z94.3	219,7 M/S	32432A	PLATINUM
MY6EST31W	MTO* AMBER	Z87+ U6 X	Z87+ CSA Z94.3	226,5 M/S	32432A	PLATINUM
MY6EST32W	MTO* VERMILLON	Z87+U6 S X	Z87+ CSA Z94.3	238,8 M/S	32432A	PLATINUM
MY6EST70W	MTO* CLEAR COPPER	CLEAR : Z87+ U6 X COPPER : Z87+ U6L1.5 X	Z87+ CSA Z94.3	CLEAR : 221,3 M/S COPPER : 219,7 M/S	32432A	PLATINUM
MY6EST71W	CLEAR SMOKE	CLEAR : Z87+ U6 X SMOKE : Z87+ U6 L3	Z87+ CSA Z94.3	CLEAR : 221,3 M/S SMOKE : 226,6 M/S	32432A	PLATINUM
MY6EST72W	CLEAR COPPER SMOKE	CLEAR : Z87+ U6 X COPPER : Z87+ U6L1.5 X SMOKE : Z87+ U6 L3 X	Z87+ CSA Z94.3	CLEAR : 221,3 M/S COPPER : 219,7 M/S SMOKE : 226,6 M/S	32432A	PLATINUM
MY6EST00W	MTO* CLEAR	Z87+ U6 X		221,3 M/S	32432A	PLATINUM
MY6EST01W	COPPER	Z87+ U6L1.5 X		219,7 M/S	32432A	PLATINUM
MY6EST02W	SMOKE	Z87+ U6 L3 X		226,6 M/S	32432A	PLATINUM
MY6EST03W	AMBER	Z87+ U6 X		226,5 M/S	32432A	PLATINUM
MY6EST04W	VERMILLON	Z87+U6 S X		238,8 M/S	32432A	PLATINUM

SPARE LENSES

▲ PROP65: WARNING: CANCER AND/OR REPRODUCTIVE HARM - WWW.P65WARNINGS.CA.GOV

* **MADE TO ORDER:** minimum order quantity applicable

PACKAGING & EAN13 CODE

SINGLE: Size: 7.283 x 2.874 x 2.874 in.	INNER BOX: Size: xx ft. Weight: 0 lb.	OUTER PACK: Size: 1.903 x 0.984 x 0.689 ft. Weight: 10.439 lb.
UPC: 840276705595 EAN: 3660740019068		UPC: 840276705601 EAN: 3660740219062
UPC: 840276705632 EAN: 3660740019082		UPC: 840276705649 EAN: 3660740219086
UPC: 840276705618 EAN: 3660740019075		UPC: 840276705625 EAN: 3660740219079
UPC: 840276705656 EAN: 3660740019099		UPC: 840276705663 EAN: 3660740219093
UPC: 840276705670 EAN: 3660740019105		UPC: 840276705687 EAN: 3660740219108
UPC: 840276705533 EAN: 3660740019037		UPC: 840276705540 EAN: 3660740219031
UPC: 840276705557 EAN: 3660740019044		UPC: 840276705564 EAN: 3660740219048
UPC: 840276705571 EAN: 3660740019051		UPC: 840276705588 EAN: 3660740219055
UPC: 840276705694 EAN: 3660740019112	UPC: 840276705700 EAN: 3660740119119	UPC: 840276705717 EAN: 3660740219116
UPC: 840276705724 EAN: 3660740019129	UPC: 840276705731 EAN: 3660740119126	UPC: 840276705748 EAN: 3660740219123
UPC: 840276705755 EAN: 3660740019136	UPC: 840276705762 EAN: 3660740119133	UPC: 840276705779 EAN: 3660740219130
UPC: 840276705786 EAN: 3660740019143	UPC: 840276705793 EAN: 3660740119140	UPC: 840276705809 EAN: 3660740219147
UPC: 840276705816 EAN: 3660740019150	UPC: 840276705823 EAN: 3660740119157	UPC: 840276705830 EAN: 3660740219154

CUSTOM CODE: 9004900010

BALLISTIC STANDARDS

STANAG 2920

MIL-PRF 32432A


GENERAL SPECIFICATIONS

LENS	POLYCARBONATE - 2.7MM - CURVE 7	CE	EN166
FRAME	NYLON/PC/TPR - HALF FRAME	ANSI	ANSI Z87.1-2020
STRAP		AS/NZS	AS/NZS 1337.1:2010

OPTIONAL ACCESSORIES

REFERENCE	DESCRIPTION	SINGLE	INNER BOX	OUTER PACK
MY6EST05W	BLACK SPARE NOSE PIECE	UPC: 840276705847 EAN: 3660740019167	UPC: 840276705922 EAN: 3660740119164	UPC: 840276705854 EAN: 3660740219161

KNOW MORE ABOUT MARKINGS:

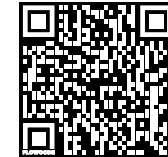

OR SCAN:

CLEANING & STORAGE

CLEANING: The lenses should be cleaned regularly. Bollé Safety recommends only using the B-clean lens cleaning system.

MAINTENANCE: Pitted, scratched or damaged lenses must be replaced by replacing the complete product. If the frame is damaged also replace the complete product. After each use it is recommended to keep the glasses or goggles in a microfiber pouch or rigid case.

STORAGE: All products must be stored in a dry and clean environment.



MADE IN: TW

DATASHEET: 12-18-2024

bolle-safety.com

Europe Headquarters
34 rue de la Soie
69100 Villeurbanne
France
Tél.: 00 33 (0) 4 78 85 23 64

U.K. & Ireland
Unit C83 - Barwell Business Park
Leatherhead Road - Chessington
Surrey - KT9 2NY - UK
Tél.: 00 44 (0)208 391 4700

USA Office
2810 Caribou Court, Suite 160
Carlsbad, CA 92010
United States of America
Tél.: 800 222 6553

Asia-Pacific Office
32-40 Fairchild Street
heatherton VIC 3202
Australia
Tél.: 1300 138 098

