

CRONUS

476-34-VPB

Like grapes on a vine, a cluster of glass orbs perch along the antique-inspired frame of Cronus. The ribbed, light bronze glass emits a warm glow, complemented by gleaming Vintage Polished Brass arches. Available as a 1-light wall sconce or 12 or 21-light chandelier, Cronus infuses a living or dining space with old Hollywood glamor.

FINISHES

VINTAGE POLISHED BRASS

Coastal Suitable Finish (EPM): No

DIMENSIONS

Height: 34.25"

Width/Diameter: 34"

Minimum Height: 41"

Maximum Height: 83"

Canopy/Backplate: 7"

Hanging Type: 1-6" / 2-12" / 1-18" Stems

Product Weight: 47.3lb

Canopy/Backplate Shape: Round

Sloped Ceiling Compatible: No

Living Finish: Yes

Uplight Only: No

Shade

Shade 1: Glass

Shade 1 Finish: Light Bronze

Shade 1 Top Width: 9.75"

Shade 1 Height: 9.25"

ELECTRICAL



Bulb 1

Bulb Included: No

Socket: E26 Medium Base

Bulb Type: G25

Max Wattage: 15

Bulb Quantity: 12

Bulb Included: No

Wire Length: 120"

Cord Type: B & W TEFLON W/ GROUND WIRE

Gem Box Required (2"x3"): No

Dark Sky: No


SHIPPING

Carton 1: 26" x 24" x 31"

Carton 1 Weight: 20lb

Shipping Method: Truck Only

Country of Origin: VN

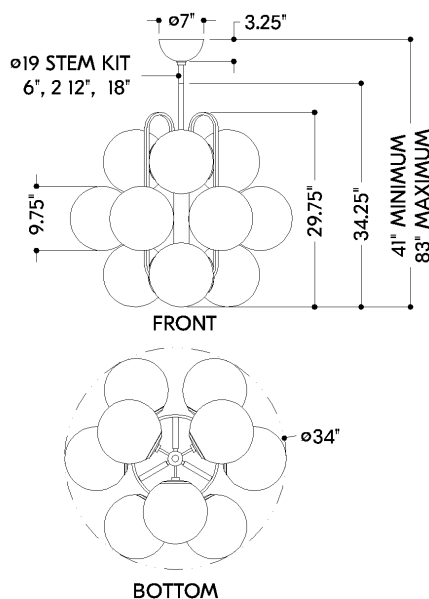

HUDSON VALLEY
LIGHTING GROUP

| hvlgroup.com | 1.800.814.3993

REVISED 3.11.2022