


Heavy-Duty Air Circulators

Component Parts / Accessories for Assembled Fan Heads

Motors

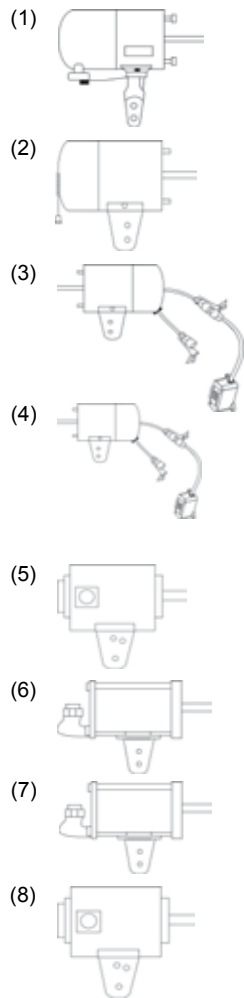

EDP No.	Catalog No.	F.L. Amps	Ship Wt.	Description
21021	967J	1.65	24	Single-phase, 3 Speed, 115 V, 1/5 HP, ball bearing, oscillating, 5/8" shaft (use only on standard 18" and 20" oscillating fans). Use BA-1A Propeller NOTE: Oscillating Motor NOT to be used UPSIDE-DOWN position (1)
21007	967-3 SP	2.7	23	Single-phase, 3 Speed, 115 V, 1/3 HP, ball bearing, oscillating, 5/8" shaft *use only on standard 24" and 30" oscillating fans). Use BA-1A Propeller NOTE: Oscillating Motor NOT to be used UPSIDE-DOWN position (1)
21777	Gear Box		18	Assembly 967J and 967-3SP
03915	End Dome			Assembly 967J and 967-3SP (with capacitor)
21022	642J	1.65	19	Single-phase, 3 Speed, 115 volt, 1/5 HP, ball bearing, non-oscillating, 5/8" shaft (use only on standard 18" and 20" non-oscillating fans). Use BA-1A Propeller (2)
21017	642-AC 3 SP	2.8	19	Single-phase, 3 Speed, 115 volt, 1/3 HP, ball bearing, non-oscillating, 5/8" shaft (use only on standard 24" and 30" non-oscillating fans). Use BA-1A Propeller (2)
06004	End Dome		2	Assembly for 642-AC-3SP (with capacitor)
21090	642-AC2SDC		19	Single phase, 2 Speed, 115 volt, 1/3 HP, ball bearing, non-oscillating motor with 2-speed drop cord switch. Use with BA-1A propeller (3)
12013	2-SPDCS-HD		2	Modular end dome with drop cord and 2 speed switch. For 642 Motor Only (4)
21025	1069 B	1.2 / 0.6	16	Three-phase, 1 Speed, 208 / 230 / 260V, 1/4 HP, ball bearing, non-oscillating fans only. Use BA-1A Propeller (5)
21035	1169 E	6.9 / 3.5	48	Single-phase, single-speed, 115/230V, 1/4 HP, ball bearing for Class I Group D and Class II, Groups E, F & G. (Use only on explosion-proof, non-oscillating fans with BA-1A Propeller) (6)
21040	1269	1.1 / 0.55	33	Three-speed, single-speed, 230/460V, 1/4 HP, ball bearing (use only on non-oscillating, explosion-proof fans) Use BA-1A Propeller (7)
21050	1369	4.5 / 2.0	36	1 HP, three-phase, single-speed 230/460 volt, ball bearing, totally enclosed (use only on high-velocity spot coolers). Use HH-1 Propeller (8)


NOTES: Explosion Proof and 3 Phase air circulator motors are not supplied with switches or power cords. Must be hard wired. See page 3 for further Explosion Proof Motor information.

Guards



EDP No.	Catalog No.	Ship Wt.	Description
71000	C-1820G	11	18" / 20" guard. Nickel chrome plated. (use on all 18" and 20" oscillating & non-oscillating fans)
21070	AC24-G	14	24" guard. Nickel chrome plated (use on all 24" oscillating & non-oscillating fans)
21080	AC30-G	20	30" guard (use on all 30" oscillating & non-oscillating fans)

Propellers

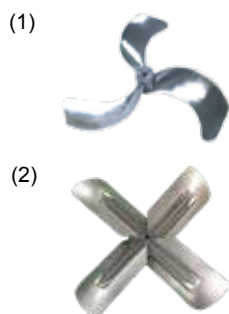

EDP No.	Catalog No.	Ship Wt.	Description
21101	18BA-1	4	18" Propeller - 5/8" bore. Cast Aluminum (1)
21102	20BA-1	5	20" Propeller - 5/8" bore. Cast Aluminum (1)
21095	24BA-1A	5	24" Propeller - 5/8" bore. Cast Aluminum (1)
21105	30BA-1A	6	30" Propeller - 5/8" bore. Cast Aluminum (1)
21120	24HH-1	8	24" Propeller, 5/8" bore (use only on 24" high velocity spot coolers) Galvanized (2)
21130	30HH-1	9	30" Propeller, 5/8" bore (use only on 30" high velocity spot coolers) Galvanized (2)



Warning: Cancer and Reproductive Harm www.P65Warnings.ca.gov
This warning is applicable to all products on this page, see page i2 for more information