



Spacity®
Hidden cord one-piece compact elongated toilet with skirted trapway, 1.28 gpf
K-28020-HC

Features

- Compact, streamlined one-piece toilet
- Compact elongated bowl offers added comfort while requiring less space
- Standard height
- 1.28 gpf (4.8 lpf)
- Left-hand Polished Chrome trip lever
- 1-15/16" (49 mm) fully glazed trapway
- Fully skirted trapway simplifies cleaning
- Hidden cord design conceals bidet seat cords (bidet seat sold separately)
- Coordinates with other products in the Spacity™ collection

Installation

- Standard 12" (305 mm) rough-in



Codes/Standards

ASME A112.19.2/CSA B45.1
DOE - Energy Policy Act 1992
EPA WaterSense®
California Energy Commission (CEC)


KOHLER® Toilets and Seats Limited Warranty


See website for detailed warranty information.

Available Colors/Finishes

Color tiles intended for reference only.

Color Code Description

	0	White
---	---	-------

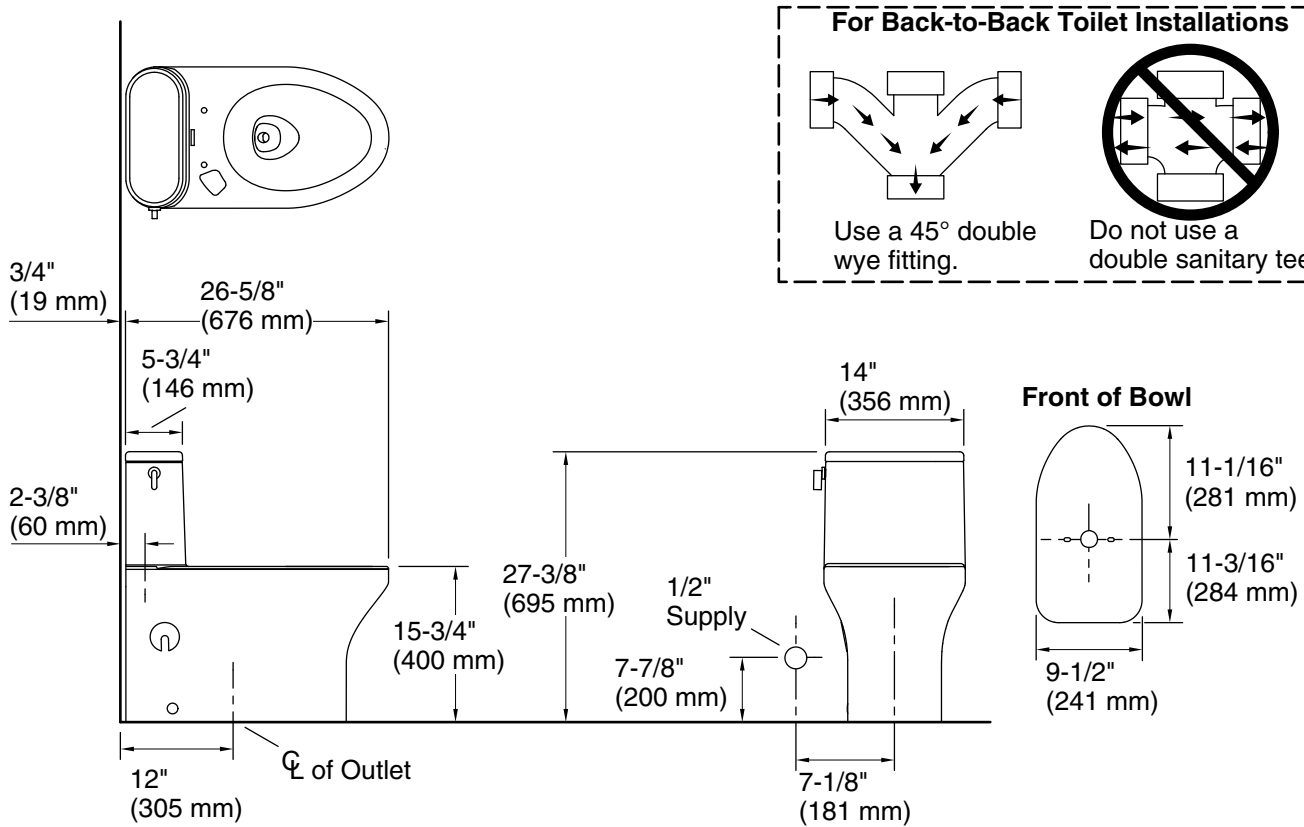

Technical Information

All product dimensions are nominal.

Toilet type:	Floor-mount
Waste Outlet:	Floor
Trap passageway:	1-15/16" (49 mm)
Rim to water surface:	6-3/8" (163 mm)
Rough-in:	12" (305 mm)

Notes

Install this product according to the installation instructions.

Product dimensions are nominal and may vary per ASME A112.19.2 tolerances.