


120-Degree Triple Low Profile Bullhorn Mounting Bracket Tenon Adapter



PRODUCT DESCRIPTION

The 120-degree bullhorn tenon adapter is engineered to support three light fixtures arranged at 120 degrees, featuring top tenons compatible with a 2-3/8 inch slip fit mount. The bottom section, constructed from heavy-duty steel, has a 3-inch outside diameter. It comes with all necessary mounting accessories for straightforward installation and replacement of existing post top mounts. Ideal for use with pole lights, parking lot lights, area lights, streetlights, and various other applications.

Dimensions

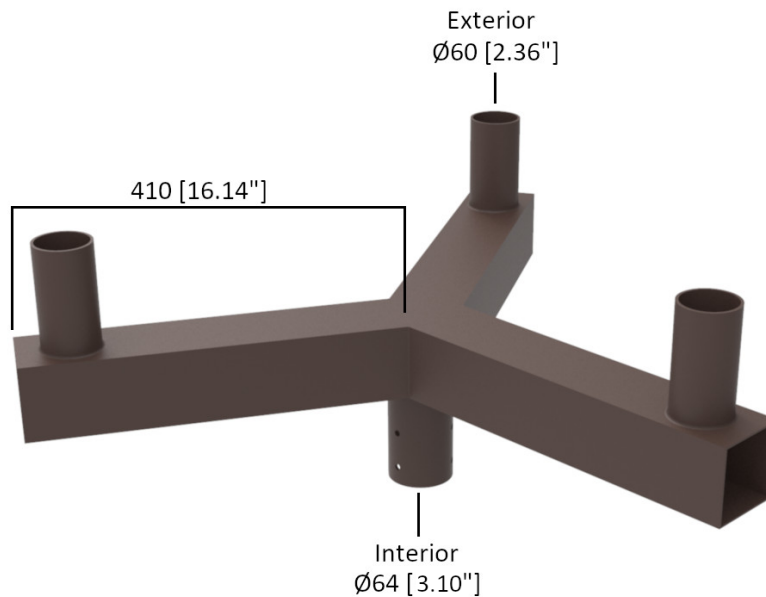

Specifications

Part Number	Weight (lbs.)	Capacity (lbs.)	Mount	Material	Warranty	Certificates
JH-1THTA120-54C	18	110/head	Round Poles	Steel	1 Year	ETL