

# DRYFT<sup>®</sup>

FROM NOW



# DRYFT®

## The world's first S-Motion Scrubber Dryer

Introducing DRYFT, a breakthrough in floor cleaning technology. With its patented ultra low profile head shape and groundbreaking 4200rpm Scrubbing Technology, DRYFT delivers 100% floor cleaning coverage in half the time.



## Now you can clean 100% of the floor surface.



### Low profile.

We designed our own compact, low profile digital motor which allowed us to create the world's lowest profile scrubber dryer for cleaning underneath partitions as low as 5cm/1.9".




### Hard-to-reach areas.

DRYFT's patented head shape is the key to its limitless cleaning ability, efficiently cleaning around toilets in seconds.



### Corner cleaning.

Don't cut corners, DRYFT them. DRYFT will scrub and dry deep into corners, thanks to the chamfered edges on the cleaning head.

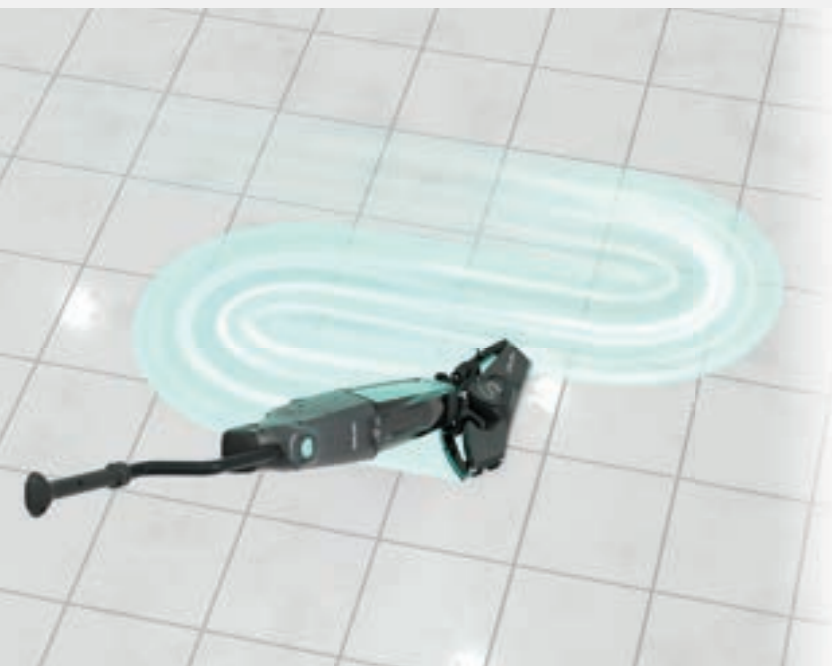

**s motion®**  
the way we clean

DRYFT is the world's first S-Motion Scrubber Dryer. DRYFT cleans in widths of 160cm/63" whilst you walk forward once, in comparison to other scrubbers, that require the user to walk four times up and down to cover this same cleaning width. The result is 75% less walking with DRYFT allowing the user to double their floor cleaning productivity.

DRYFT cleans 100m<sup>2</sup>/1076ft<sup>2</sup> in just 3.9 minutes.

**Spin Handle**  
Keeps your upper hand stationary allowing the machine to rotate effortlessly.

**Floor Tracking Technology**  
DRYFT tracks and adjusts automatically to uneven floors, thanks to the SPYDR Chassis, which enables the cleaning pad and squeegees to adjust independently.

**Aluminium Chassis**  
Robust aluminium construction designed for commercial use.

**S-Handle**  
The ergonomically designed S-Handle enables the user to effortlessly guide the machine in the super fast S-Motion.

**Simple Controls**  
Switch between smooth floor mode and rough floor mode at the press of a button.

**DRYFT CORE-ion**  
Clean 24/7 with DRYFT CORE-ion quick change battery technology, 1 hour 15 minute runtime, 1 hour charge time.

**Service Pods™**  
Anybody can service DRYFT with our smart self service pod design. Quickly and easily change all serviceable parts; suction motor, solenoid valve, PCB, squeegees and more.

**Magnetic Recovery Tank**  
Easy to clean and empty.

**Quick Fill Magnetic Tank**  
2.5 litre/0.55 gallon clean water tank delivers 20 minutes cleaning time.

**Ultimate Manoeuvrability**  
Forged aluminium torque transmitting ball joint.

### DRYFT specifications

Machine weight	7kg / 15.4lbs* (when empty) 9.5kg / 20.9lbs* (when full)
Cleaning width	s motion® 160cm / 63"
Scrubbing width	39cm / 15.4"
Scrubbing power	4200rpm

\* Specifications are subject to change.

### core-ion specifications

Battery run time	1 hour 15 mins
Battery charge time	1 hour
Battery spec	25.2v 5AH

**Efficient Water Release**  
High performance cleaning with just water, thanks to 4200rpm scrubbing action.

**Transportation Wheels**  
Flip the head onto the transport wheels for easy transportation between cleaning areas.

**MAGPlate**  
Colour coded magnetic pad holder.

**Wall Protection Glide Wheels**  
Non-marking soft rubber for precision edge cleaning.

**Quick Release Squeegee**  
Tool-free design for easy maintenance.



Patented technology

Clean at **DRYFT** speed

The future is NOW

