

PROJECT NAME: _____ CAT. #: _____
 NOTES: _____ FIXTURE SCHEDULE: _____

Value Canopy/Parking Fixture

CP Series



45-55W

Product Description

The Value Series Canopy/Parking fixture is an economical retrofit solution for 150-175W HID garage and canopy luminaires. Offered in multiple wattages, with different lens options for parking garage and canopy distributions, the CPL can address a variety of canopy lighting needs. The series is available with an internal motion sensor option that can be conveniently controlled with a remote control (sold separately).

Features

- Die cast aluminum housing with corrosion resistant polyester powder coat finish
- Shatter resistant UL stabilized polycarbonate lens
- Integral 4kV Surge Protection + 10kA stand alone surge protection standard
- Choice between Canopy and Parking Lens

Factory Installed Controls Options

- Multifunctional Occupancy + Photocell Motion Sensor
- Standard Photocell

Ordering Information

FAMILY ¹	WATTAGE (NOMINAL)	VOLTAGE	DISTRIBUTION	-	CCT	COLOR	OPTIONS
CP= Value Canopy/Parking	45= 45W 55= 55W	U= 120-277V	C= Canopy P= Parking	-	40= 4000K 50= 5000K	B= Dark Bronze <i>Contact Maxlite for additional finishes.</i>	MS= Motion Sensor* PC= Photocell

*Remote control available (RMRC-100) - sold separately

Accessories (Sold Separately)

ORDER CODE	MODEL NUMBER	DESCRIPTION	IMAGE
104799	RMRC-100	REMOTE CONTROL FOR MS OPTION, MINIMUM 1 PER PROJECT TO PROGRAM	
111294	EM2-REMOTE-MT	FIELD INSTALLABLE REMOTE MOUNT -20°C BATTERY BACKUP FOR 20-70W ONLY (NOT COMPATIBLE WITH 100W)	
109426	CPL-BPLATE-B	15 INCH X 15 INCH BEAUTY PLATE FOR 20-55W, BRONZE	
110763	CPL-BPLATE-W	15 INCH X 15 INCH BEAUTY PLATE FOR 20-55W, WHITE	

Value Canopy/Parking Fixture

CP Series

Stocked Items

ORDER CODE	MODEL NUMBER	WATTAGE
110645	CP45UP-50B	45W
110647	CP55UP-50B	55W
110692	CP55UP-50W	55W




Specifications

		CP45	CP55
Nominal Wattage (W)*		45W	55W
Lumens Delivered (lm)	Parking*	6,430 lm	6,900 lm
Lumens Delivered (lm)	Canopy*	6,170 lm	7,150 lm
Nominal Efficacy (lm/W)	Parking*	143 lm/W	125 lm/W
Nominal Efficacy (lm/W)	Canopy*	137 lm/W	130 lm/W
Battery Backup Min. Lumen Output	Parking	With EM2-REMOTE-MT - 1,000 lm	
	Canopy	With EM2-REMOTE-MT - 1,040 lm	
CRI			
Color Temperature (K)			
Input Voltage		120-277V AC	
Surge Protection		4kV integral + 10kA stand alone	
Dimming		0-10V dimming capability	
Controls		On/Off photocell or programmable motion sensor with photocell available as factory installed option	
Lumen Maintenance (L70) hrs		50,000 Hrs	
Housing		Die cast aluminum with corrosion resistant polyester powder coat	
Lens		Shatter resistant, UV stabilized polycarbonate	
Mounting		Metal plate with hinge to hold fixture for wiring	
Operating Temperature		-40°F to 122°F (-40°C to 50°C)	
Weight		5.5lbs/2.5kg	
Listings		ULus, FCC, RoHS	
Environment		IP65	
Warranty		5 Year warranty. Check maxlite.com/warranties for details.	

* Varies depending on CCT, consult IES files for exact measurements

† Fixture are set at highest wattage and 5000K

Dimensions

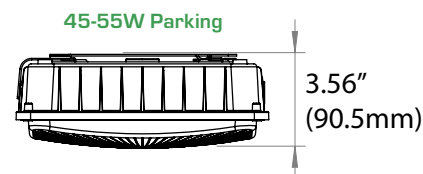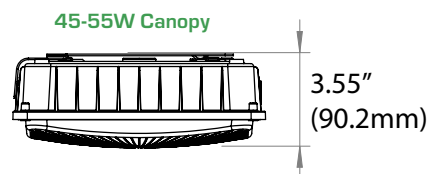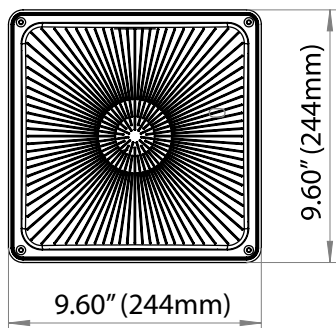

Value Canopy/Parking Fixture

CP Series

DLC 5.1 Chart

MODEL #	PRODUCT ID	GENERAL APPLICATION	PRIMARY USE DESIGNATION
CP45UC-40[ALL OPTIONS]	S-KYKVYC	Mid Output	Fuel Pump Canopy Luminaires
CP45UC-50[ALL OPTIONS]	S-5HCBMN	Mid Output	Fuel Pump Canopy Luminaires
CP55UC-40[ALL OPTIONS]	S-DFC0RZ	Mid Output	Fuel Pump Canopy Luminaires
CP55UC-50[ALL OPTIONS]	S-M3BV6M	Mid Output	Fuel Pump Canopy Luminaires
CP45UP-40[ALL OPTIONS]	S-V2FRN5	Mid Output	Parking Garage Luminaires
CP45UP-50[ALL OPTIONS]	S-WB42XG	Mid Output	Parking Garage Luminaires
CP55UP-40[ALL OPTIONS]	S-7CNXMC	Mid Output	Parking Garage Luminaires
CP55UP-50[ALL OPTIONS]	S-32F7DZ	Mid Output	Parking Garage Luminaires

Isofootcandle


Each gridline represents one mounting height.
For mounting heights other than noted multiply FC by the below factor.

$$\frac{(\text{Chart's Mtg Height})^2}{(\text{Actual Mtg Height})^2}$$

LEGEND

0.5 fc 1 fc 2 fc 5 fc 10 fc 20 fc

55W Canopy – 15 ft.

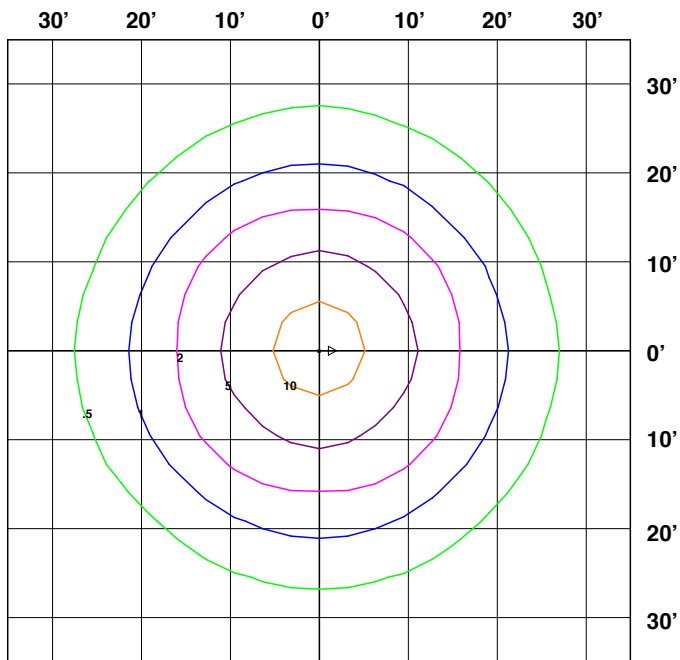

55W Parking – 15 ft.

