

Diva dimmers, switches, and fan controls



Shown actual size: Diva preset dimmer and 1-gang Claro wallplate in White (WH).

Product family features

- Large paddle switch with a captive linear slide dimmer for a standard Designer wallplate opening
- Preset dimmer
- LED+, reverse-phase, and 0-10V models available
- Coordinating Claro, Satin Colors, and Stainless Steel wallplates only available separately
- All models must be derated unless otherwise noted. Visit lutron.com/multigang for more information.

Control types

- Single-pole (1 location)
- 3-way or 4-way (2 or more locations)

Direct load type compatibility

- Dimmable LED/CFL lighting (screw-base)
- Incandescent/halogen lighting
- Magnetic low-voltage lighting
- Electronic low-voltage lighting
- LED lighting
- Fluorescent lighting
- Switched lighting/fan/motor
- Ceiling fans

Load type requiring load interface

- Neon/cold cathode lighting

Lighting load interfaces may be required for some additional load type, voltage, and capacity combinations. For additional information see "Lighting Load Interfaces."

Diva dimmers, switches, and fan controls

Available finishes


Use **BOLD** color code in model number (Example: DV-600P-**BR**)
Gloss



Satin Colors



Metal wallplate*

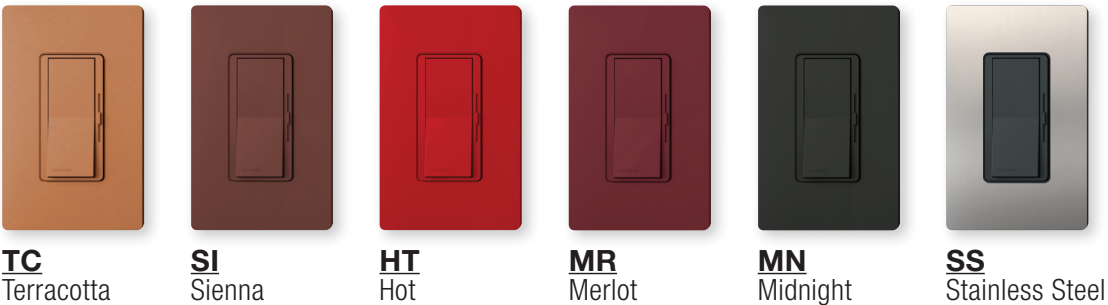

* Stainless Steel metal wallplate only available separately and includes black plastic trim/adaptor, visible from side. Match with separate Black (BL) or Midnight (MN) controls.

Mechanical switches



- Paddle turns on/off
- Use with any 15A load
- General purpose switching of all light sources and motor loads
- Available with locator light

 General purpose switches

Mechanical switches

Single-pole	CA-1PS- XX ¹
120/277V 15A	SC-1PS- XX ²
3-way	CA-3PS- XX ¹
120/277V 15A	SC-3PS- XX ²
4-way	CA-4PS- XX ¹
120/277V 15A	SC-4PS- XX ²

Mechanical switches with locator light

Single-pole	CA-1PSNL- XX ³
120V 15A	SC-1PSNL- XX ⁴
3-way	CA-3PSNL- XX ³
120V 15A	SC-3PSNL- XX ⁴
4-way	CA-4PSNL- XX ³
120V 15A	SC-4PSNL- XX ⁴

No derating required if ganged.

XX¹: Gloss color codes
XX²: Satin color codes
XX³: Available in Gloss White (WH), Ivory (IV), Almond (AL), and Light Almond (LA)
XX⁴: Available in Satin Colors Snow (SW), Biscuit (BI), Eggshell (ES), Goldstone (GS), Limestone (LS), and Sea Glass (SG)
Wallplates not included. Order separately.

Fan controls



- Paddle turns fan on/off
- Slide up to increase speed, down to decrease speed
- 3 quiet fan speeds for increased comfort
- For use with only one ceiling paddle fan
- Designed to prevent motor hum

 Fan controls

Fan controls—quiet 3-speed

3-way/single-pole	DVFSQ-F- XX ¹
120V 1.5A	DVSCFSQ-F- XX ²
3-way/single-pole	DVFSQ-F-HO- XX ¹
120V 2A	

DVFSQ-F-HO model for use with Hunter Original Series fans.

Does not include built-in locator light.
No derating required if ganged.

XX¹: Gloss color codes
XX²: Satin color codes
Wallplates not included. Order separately.

Fan/light controls



- Switch** (paddle)
 - Turns light on/off
- Fan Control** (slider)
 - Use slide to turn fan on/off and adjust fan speed
 - 3 quiet fan speeds for increased comfort
 - For use with only one ceiling paddle fan
 - Designed to prevent motor hum

 Fan/light controls

Fan/light controls—quiet 3-speed

Single-pole	DVFSQ-LF- XX ¹
120V 1.5A Fan, 120V 1A LED/CFL, 2A Incandescent/halogen	DVSCFSQ-LF- XX ²

No derating required if ganged.
Does not include built-in locator light.