


## WATER PIPE GROUND CLAMP

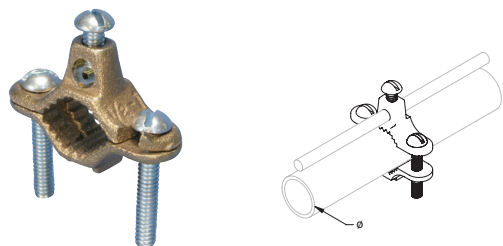

### FEATURED HIGHLIGHTS


- High-strength silicone bronze
- Used for connecting copper conductors to metallic water pipe or ground rods



| Part Number                     | Pipe Size, Nominal | Conductor Size                                                                    | Certifications |
|---------------------------------|--------------------|-----------------------------------------------------------------------------------|----------------|
| <b>Material: Silicon Bronze</b> |                    |                                                                                   |                |
| CWP1JJ                          | 1/2" – 1"          | #10 Solid - #4 Stranded, 6 mm <sup>2</sup> Stranded - 16 mm <sup>2</sup> Stranded |                |
| CWP1JU                          | 1/2" – 1"          | #10 Solid - #2 Stranded, 6 mm <sup>2</sup> Stranded - 25 mm <sup>2</sup> Stranded | CSA, cULus     |
| CWP2JU                          | 1 1/4" – 2"        | #10 Solid - #2 Stranded, 6 mm <sup>2</sup> Stranded - 25 mm <sup>2</sup> Stranded | CSA, cULus     |
| CWP4J                           | 2 1/2" – 4"        | #10 Solid - #4 Stranded, 6 mm <sup>2</sup> Stranded - 16 mm <sup>2</sup> Stranded | CSA, cULus     |
| CWP6J                           | 4 1/2" – 6"        | #10 Solid - #4 Stranded, 6 mm <sup>2</sup> Stranded - 16 mm <sup>2</sup> Stranded | CSA            |
| <b>Material: Zinc Alloy</b>     |                    |                                                                                   |                |
| ZWP1J                           | 1/2" – 1"          | #10 Solid - #6 Solid, 6 mm <sup>2</sup> Stranded - 10 mm <sup>2</sup> Stranded    | cULus          |

Optional copper screw for use in direct burial applications.

## WATER/GAS PIPE GROUND CLAMP

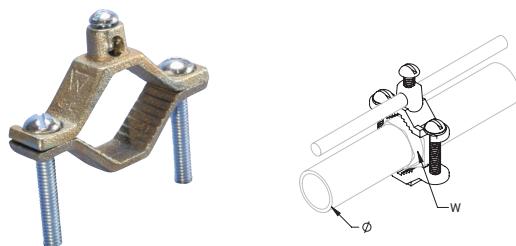

### FEATURED HIGHLIGHTS

- High-strength silicone bronze
- Used for connecting copper conductors to metallic water pipe, ground rods, or flexible gas pipe (CSST) with brass hex fittings
- Conform to the requirements of the 2009 edition of NFPA® 54, NFGC® (National Fuel Gas Code) and NEC® (National Electric Code) for bonding corrugated stainless steel tubing (CSST) gas piping systems to the grounding conductor of the building's electrical system
- SH version for outdoor applications



Material: Silicon Bronze

| Part Number                 | Pipe Size, Nominal | Hex Width       | Conductor Size                                                                    | Certifications |
|-----------------------------|--------------------|-----------------|-----------------------------------------------------------------------------------|----------------|
| <b>For Outdoor Use: No</b>  |                    |                 |                                                                                   |                |
| CWP1J                       | 1/2" – 1"          | 1" – 1 1/4"     | #10 Solid - #2 Solid, 6 mm <sup>2</sup> Solid - 25 mm <sup>2</sup> Stranded       | CSA, cULus     |
| CWP2J                       | 1 1/4" – 2"        | 1 1/2" – 2 1/8" | #10 Solid - #2 Stranded, 6 mm <sup>2</sup> Stranded - 25 mm <sup>2</sup> Stranded | CSA, cULus     |
| CWP3J                       | 2 1/2" – 4"        | 2 1/2" – 3 1/8" | #10 Solid - #4 Stranded, 6 mm <sup>2</sup> Stranded - 16 mm <sup>2</sup> Stranded | cULus          |
| <b>For Outdoor Use: Yes</b> |                    |                 |                                                                                   |                |
| CWP1JSH                     | 1/2" – 1"          | 1" – 1 1/4"     | #10 Solid - #2 Stranded, 6 mm <sup>2</sup> Stranded - 25 mm <sup>2</sup> Stranded | cULus          |
| CWP2JSH                     | 1 1/4" – 2"        | 1 1/2" – 2 1/8" | #10 Solid - #2 Stranded, 6 mm <sup>2</sup> Solid - 25 mm <sup>2</sup> Stranded    | cULus          |
| CWP3JSH                     | 2 1/2" – 4"        | 2 1/2" – 3 1/8" | #10 Solid - #4 Stranded, 6 mm <sup>2</sup> Stranded - 16 mm <sup>2</sup> Stranded | cULus          |