




Sink Drain with or without Overflow Installation Instructions

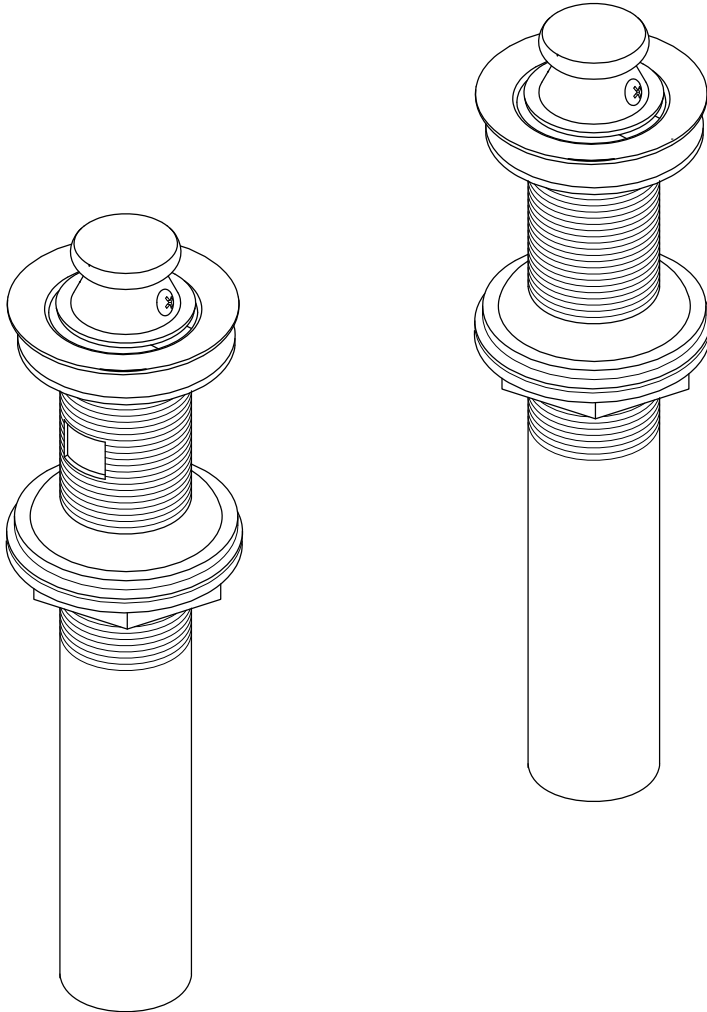

 
NOTICE

Failure to follow all directions may cause leaks
which may result in water damage

www.kingstonbrass.com

TOLL-FREE CUSTOMER SERVICE: 1-877-2-KBRASS
TECHNICAL SUPPORT E-mail: service@kingstonbrass.com
12775 Reservoir Street, Chino, CA 91710

Tools Required




Basin Wrench




Adjustable Wrench



 Teflon Tape



Silicone Sealant

 

Screwdriver

Installation Steps:

1. Remove the flange (2), stopper (1) and rubber (3) from the drain body (7).
2. Turn the lock nut (6) downward to the lower position of drain body (7), also push plastic washer(5) and rubber gasket (4) downward.
3. Insert drain body (7) upwardly with (4)/(5)/(6) parts through the drain opening from the underside of the sink.
4. Put the rubber washer (3) back onto the flange (2), then slowly thread the flange (2) on to the top of the drain body (7). Make sure the flange (2) is completely threaded in the drain body(7) and firmly fixed on the bottom of sink without any gap between the flange and sink's bottom.
5. Move rubber gasket (4), plastic washer (5) upwardly and tighten up the lock nut (6) with a wrench until the rubber gasket (4) can completely and tightly seal the drain opening beneath the sink.
6. Install stopper (1) back to the flange (2) and tighten up the set screw by a screwdriver.
7. Lift and turn the stopper (1) to the closed position of the drain body (3), then turn on the faucet to fully fill the sink with water. Examine and ensure that no water is leaking from the tailpiece (8).
8. Lift and turn the stopper (1) to the open position to drain water, examine to make sure no water leakage around the rubber gasket(4) or lock nut(6). If leakage found, adjust the rubber gasket (4) and re-tighten up the lock nut (6) until no more leakage found.

