

NEPHELE

473-09-VPB

Echoing the artistry of bespoke installations and the graceful allure of fine jewelry, Nephele floats elegantly in space, resembling a string of luminous pearls suspended in perfect harmony. Each softly glowing cloud glass orb is held in place by intricately detailed Vintage Polished Brass links, creating a striking interplay of light and form.

Available in 8, 12, or 16-light LED-lit chandeliers, as well as a 1-light wall sconce, Nephele captivates the senses with its fluid silhouette and exquisite craftsmanship. This artful statement piece offers a refined elegance that elevates interiors with its sculptural presence.

FINISHES

VINTAGE POLISHED BRASS

Coastal Suitable Finish (EPM): No

DIMENSIONS

Height: 29.75"

Width/Diameter: 10"

Length: 98.5"

Minimum Height: 29"

Maximum Height: 45.25"

Canopy/Backplate: 7.75"

Hanging Type: 72" Chain

Product Weight: 33.5lb

Canopy/Backplate Shape: Round

Sloped Ceiling Compatible: No

Living Finish: No

Uplight Only: No

Shade

Shade 1: Glass

Shade 1 Finish: Cloud

Shade 1 Top Width: 10"

Shade 1 Height: 6.25"

ELECTRICAL



Bulb 1

Bulb Included: N/A

Socket: Integrated LED

Max Wattage: 56

Bulb Quantity: 8

Bulb Included: Yes

Wire Length: 120"

Cord Type: SPT-1 SILVER W/ TINNED GROUND WIRE

Dimmer Type: ELV, TRIAC, 0-10 VOLT

Gem Box Required (2"x3"): No

Dark Sky: No

CRI: 90

Color Temp.: 2700k

Lumens: 1950

Title 24: No

Field Serviceable: No


SHIPPING

Carton 1: 49" x 37" x 10"


Carton 1 Weight: 45lb

Shipping Method: Truck Only

Country of Origin: VN

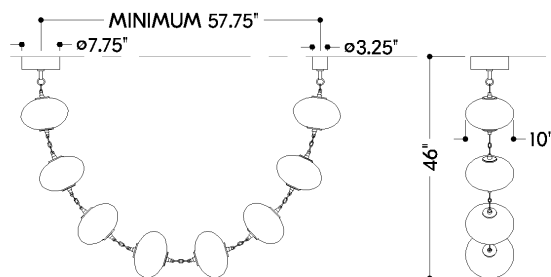

8 LT MIN

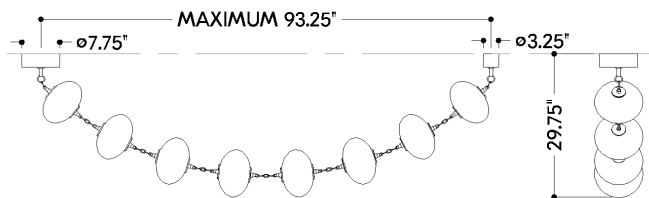

8 LT MAX

FRONT

SIDE

HUDSON VALLEY
LIGHTING GROUP

| hvlgroup.com | 1.800.814.3993

REVISED 3.11.2022