



**MCR
SAFETY**

6100

**Supported / Dipped gloves
Specification Sheet**

PRODUCT DESCRIPTION:

Even the dirtiest, harshest jobs won't destroy the will of these tough gloves. Single dipped PVC coated gloves provide basic protection in light chemical applications. Glove lengths range from knit wrist to 18 inches to provide different levels of protection. The 6100 is an industry standard black single dipped glove with a smooth finish, interlock lining and a knit wrist. Looking for the best PVC coated gloves? Look no further than MCR Safety!

FEATURES:

- Single dipped PVC coated gloves
- Black color hides dirt and grime
- Comfortable knit wrist
- Soft interlock lining

APPLICATIONS:

Agriculture, Farming, Janitorial , Landscaping, Material Handling, Sanitation



TECHNICAL DATA FOR: 6100

Material Group	Supported	Overall Length	10 in.
Product Type	Supported / Dipped gloves	EN 388: CE Score - Abrasion	4
Glove Size	Large	EN 388 : CE Score - Cut	1
Material	PVC	EN 388 : CE Score - Tear	1
Grade	Industrial Grade	EN 388 : CE Score - Puncture	1
Lining	Interlock		
Thumb Style	Wing		
Made In	Bangladesh		

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com


©2021 MCR Safety - All Rights Reserved



MCR
SAFETY

6100

Supported / Dipped gloves
Specification Sheet

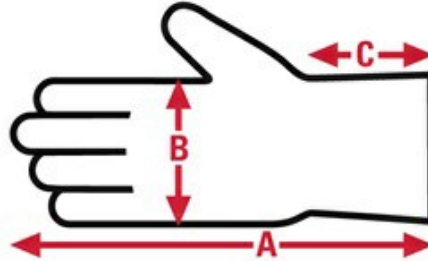

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
6100	Large	10.500	5	3.000	33.910 lb.	3.391

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2021 MCR Safety - All Rights Reserved