

AIR COMPRESSOR
12V | 22A

BOOST-X JUMP STARTER
12V | 2000A

AX65



ALL IN ONE LITHIUM POWERED. AIR COMPRESSOR + JUMPSTARTER.

START DEAD BATTERIES.

Extreme jump starting power - 2000 amps - for fast and powerful engine starts for up to 8.0-liter gasoline and 6.0-liter diesel engines.

INFLATE FLAT TIRES.

Inflate 205-265 R16 tires astonishingly fast in 2 minutes. A pressure sensor and smart tech pause inflation at the set pressure and shut it off for precise accuracy.

DESIGNED TOUGH.

Designed for rugged environments with rubberized port covers and anti-vibration feet for uncompromising operation - zero movement.



NOCO

30339 Diamond Parkway, #102
Glenwillow, OH 44139 | USA
1.800.456.6626

no.co

AIR COMPRESSOR + JUMP STARTER

22A MOTOR 2000A BOOSTX

Introducing the next generation of air compressors — an all new design that offers ultrafast, automatic inflation — combined with the extreme jump starting power of BoostX.

*Do not use both features simultaneously.

INFLATE FLAT TIRES | START DEAD BATTERIES

INTUITIVE INTERFACE



CHARGE PORT

BOOST PORT

PRESTA/NEEDLE ADAPTER

INFLATABLE TOY ADAPTER


TOTAL VERSATILITY.

With its rugged portable design, integrated cord management, dedicated slots for accessories, and ultra-compact size, it can easily be stored - and ready to take on anything.

TECHNICAL SPECIFICATIONS

MAX AIRFLOW AT 0 PSI:	67 SLPM
MAX PRESSURE:	100 psi
MOTOR RATING:	280W
MOTOR MAX CURRENT DRAW:	22A
DUTY CYCLE:	7 min @ 30 PSI "ON" time/53 min "OFF" time
MANUAL MODE DUTY CYCLE:	5 min "ON" time/55 min "OFF" time
POWER TYPE:	12V Plug
IP RATING:	IP55
OPERATING TEMPERATURE:	-4° to 122° F (-20° to +50° C)
STORAGE TEMPERATURE:	-4° to 122° F (-20° to +50° C)
GAS ENGINE SIZES:	Up to 8.0L
DIESEL ENGINE SIZES:	Up to 6.0L
PEAK CURRENT:	2000A
BATTERY TYPES:	12V Lead-Acid Only (Wet, Gel, MF, EFB, AGM)
WEIGHT:	7.01 lbs (3.18 kg)
WARRANTY:	1-Year Limited Warranty
VOLUMETRICS:	Retail Packaging: Dimensions: 10.63" x 6.42" x 7.24" Weight: 9.79 lbs UPC: 0-46221-24025-2
	Master Carton: Dimensions: 16.73" x 14.57" x 11.81" Weight: 43.48 lbs Quantity: 4 ITF-14: 10046221240259
	Inner Carton: Dimensions: 10.83" x 6.69" x 6.81" Weight: 10.21 lbs
	Units Per Pallet: US: 108 units

WHAT'S IN THE BOX

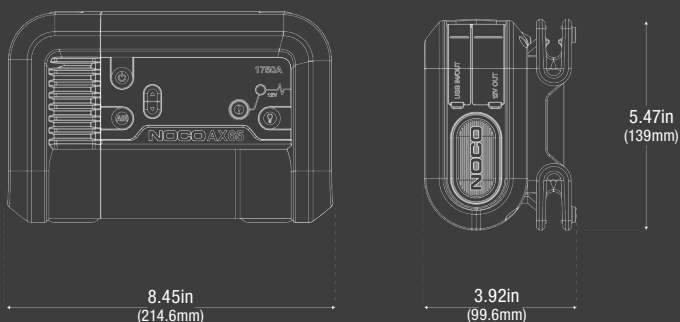


*Accessories not to scale with AX65

AX65 Air Compressor + BoostX



HD Precision Battery Clamps

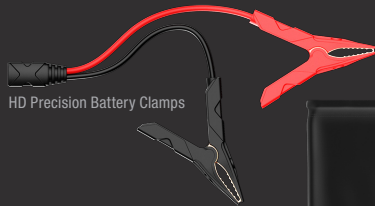

USB-C to USB-C Cable 24"



User Guide



Microfiber storage bag

NOCO

30339 Diamond Parkway, #102
Glenwillow, OH 44139 | USA
1.800.456.6626

no.co

