






3596BTRM  
Tub/Hand Shower/Shower Trim  
**Specification Submittal**

Location:

<p><b>Model Numbers</b></p> <p><input type="checkbox"/> <b>3596BTRM</b> Tub/Hand Shower/Shower Trim</p> <p><b>Valve Options</b> -261 Series Temptrol® Shower Valve with TRM modifier -161 Series Temptrol Shower Valve requires TC modifiers -3DIVBODYSRT</p>	<p><b>Modifications</b></p> <ul style="list-style-type: none"> <li><input type="checkbox"/> <b>15</b>  1.5 gpm (5.7 L/min) flow restrictor</li> <li><input type="checkbox"/> <b>175</b> 1.75 gpm (6.6 L/min) flow restrictor</li> <li><input type="checkbox"/> <b>Delete suffix B</b> Chrome plastic escutcheon on valve with color graphics/indicators in place of standard brass escutcheon</li> <li><input type="checkbox"/> <b>TC</b> Test Cap Trim (includes TA-10™ &amp; T-12A) <i>used with 161 Series Temptrol Valve.</i></li> <li><input type="checkbox"/> <b>L1</b> Less showerhead</li> <li><input type="checkbox"/> <b>L2</b> Less hand shower (wand only)</li> <li><input type="checkbox"/> <b>L3</b> Less showerhead and hand shower (head and wand only)</li> <li><input type="checkbox"/> <b>L4</b> Less showerhead, shower arm, and flange</li> <li><input type="checkbox"/> <b>L5</b> Less hand shower system (less bar/cradle, hose, wand, and elbow.</li> <li><input type="checkbox"/> <b>L7</b> Less handle</li> <li><input type="checkbox"/> <b>BBZ</b> Brushed Bronze finish</li> <li><input type="checkbox"/> <b>MB</b> Matte Black finish</li> <li><input type="checkbox"/> <b>STN</b> Satin Nickel finish</li> <li><input type="checkbox"/> <b>1L</b> 1-Inch Spindle Extension</li> </ul>
<p><b>Feature Highlights</b></p> <ul style="list-style-type: none"> <li>• Dia Tub/Shower/Hand Shower Trim.</li> <li>• Requires Temptrol Pressure-Balancing Shower Valve.</li> <li>• 30" slide bar.</li> <li>• Separate three-function diverter body.</li> <li>• 7" tub spout.</li> <li>• 60" flexible metal hose.</li> <li>• 7-mode HydroMersion™ hand shower with Non-Positive Shutoff (NPSO).</li> <li>• 7-mode HydroMersion showerhead with Non-Positive Shutoff (NPSO).</li> <li>• Dual check valves for backflow protection.</li> <li>• Standard 2.0 gpm (7.6 L/min) flow restrictors.</li> <li>• Components made from metal and nonmetal materials plated in standard Polished Chrome finish.</li> </ul>	<p><b>Warranty</b></p> <p><b>Limited Lifetime</b> - for residential installations. <b>10 Years</b> - for commercial/industrial installations. Refer to <a href="http://www.symmons.com/warranty">www.symmons.com/warranty</a> for complete warranty information.</p> 
<p><b>Compliance</b></p> <ul style="list-style-type: none"> <li>• ASME A112.18.1/CSA B125.1</li> <li>• WaterSense 1.5 gpm (5.7 L/min) 1.75 gpm (6.6 L/min) 2.0 gpm (7.6 L/min)</li> <li>• Lever handle meets ADA requirements for operation</li> </ul>   	

**SKU Builder**


Series	Finish	Modifier	Flow Rate	Trim (required)	Test Cap	1L	Final SKU
3596	STN		15	TRM			3596STN15TRM
3596B	MB	L3		TRM	TC	1L	3596BMBL3TRMTC1L

**Notes:** No more than two modifiers (L1-L7) permitted when ordering. Modifiers will list in numerical order.

**Architectural/Engineering Specification**

Symmons Dia Tub and Shower and Hand Shower System \_\_\_\_\_ Includes Dia Tub/Shower/Hand Shower Trim for the Temptrol® Pressure-Balancing Shower Valve. Features 30" slide bar, 7" tub spout, 60" flexible metal hose, 7-mode HydroMersion hand shower with NPSO, 7-mode HydroMersion showerhead with NPSO, dual check valves for backflow protection and standard 2.0 gpm (7.6 L/min) flow restrictors. Components made from metal and nonmetal materials plated in standard Polished Chrome finish. 10-Year Commercial Warranty. Lever handle meets ADA requirements for operation. ASME A112.18.1/CSA B125.1, WaterSense 1.5 gpm (5.7 L/min), 1.75 gpm (6.6 L/min), and 2.0 gpm (7.6 L/min) compliant. Available options: 15 = 1.5 gpm (5.7 L/min) flow restrictor, 175 = 1.75 gpm (6.6 L/min) flow restrictor, Delete Suffix B = Chrome plastic escutcheon, L1 - Less showerhead, L2 = Less hand shower (wand only), L3 = Less showerhead and hand shower (head and wand only), L4 = Less shower arm and flange, L5 = Less hand shower system, L7 = Less handle, BBZ = Brushed Bronze finish, MB = Matte Black finish, STN = Satin Nickel finish, 1L = 1-Inch Spindle Extension, and TC = Test Cap Trim.

## Dimensions

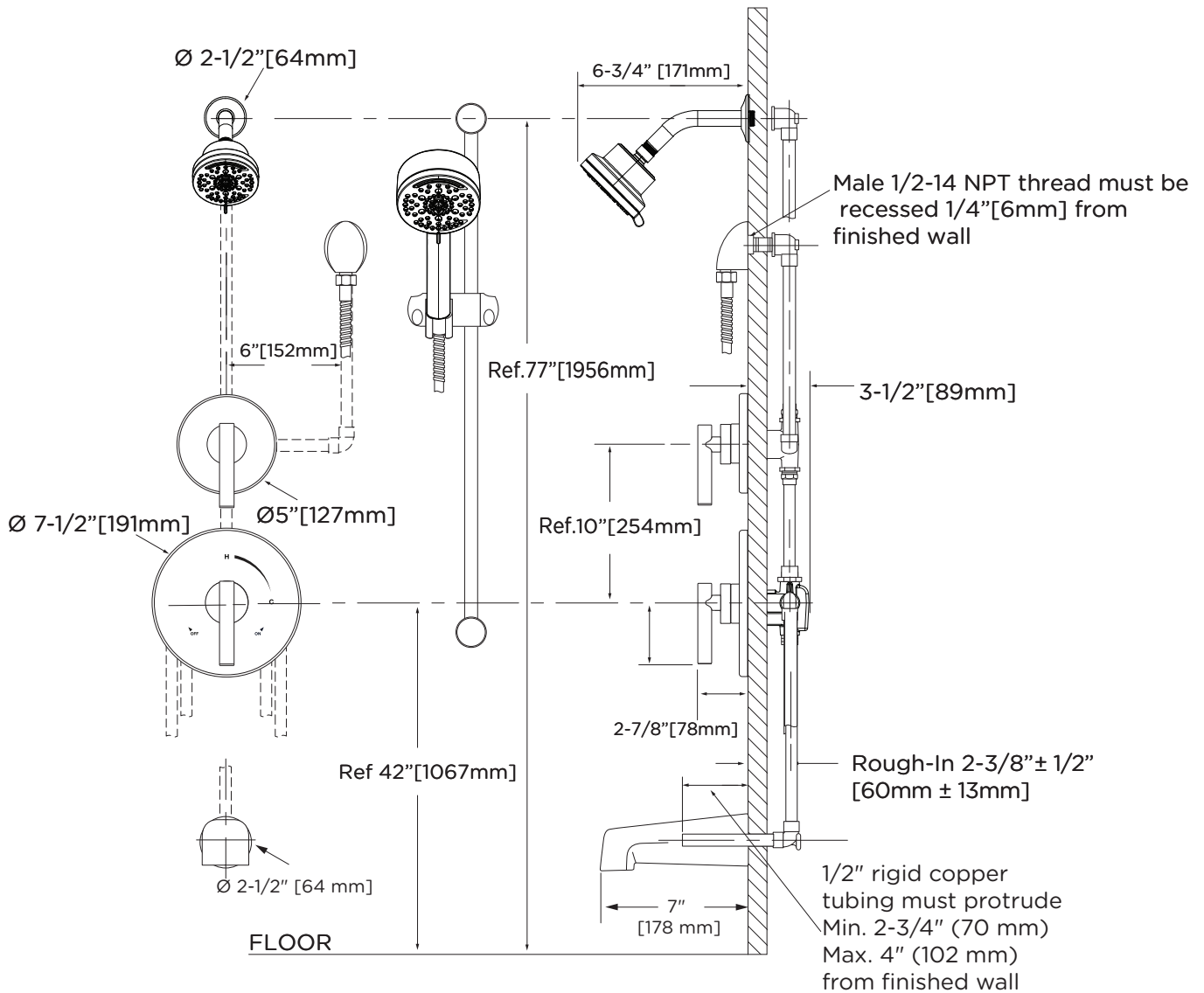

### Notes:

- 1) Valve body and piping not included and shown as reference only.
- 2) Plaster shield (p/n T-176) from drywall, plaster, or other type walls 1/2" or greater.
- 3) All dimensions measured from nominal rough-in.
- 4) Dimensions are subject to change without notice.