

Popular for good reason.

Halogen lamps come in more sizes, shapes, and base variations than most other technologies, and with good reason – brilliant white light, great color temperature, and color rendering properties, long life, and superior lumen maintenance combine to make them very popular. Satco stocks virtually every variation there is. Our wide inventory allows you to get the types you need, whether a specialty size or an incandescent A19 replacement, that meets government regulations. When it comes to Halogen lamps, we can confidently say “Yes, we have that.”

Halogen lamp features:


- Available from 5 to 1500 Watts
- From 6 to 240 Volt variations
- All industry standard sizes and bases
- Fully dimmable
- Environmentally friendly – Mercury free
- Energy efficient
- Our Halogen Excel line saves up to 30% in energy costs over traditional incandescent lamps
- Halogen/Xenon technology for enhanced performance in our Halogen Excel™ line
- Excellent color rendering
- High lumen output



Nuvo Lighting's Lynne five light vanity in Polished Nickel with Frosted Glass. Nuvo item number 60-5178. See the www.nuvolighting.com website.



HALOGEN

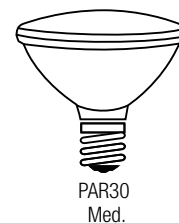

PAR30 Short Neck

Watts	Bulb Type	Base	Satco Prod. #	Lamp Code	Beam Pattern	Volts	Finish	CBCP	M.O.L. Inches	Filament	Initial Lumens	Avg. Rated Hours	Pkg. Type	Carton	Notes	
39	PAR30	Med.	S2233	39PAR30/HAL/XEN/NSP/120V	NSP 9	120	Clear	6500	3 5/8	CC-8	530	1500	Box	15		
			Y16117 ▲	39PAR30/HAL/SP10/120V	SP 10	120	Clear	6100	3 5/8	CC-8	550	1500	Box	10		
			Y16121 ▲	39PAR30/HAL/SP10/130V	SP 10	130	Clear	6100	3 5/8	CC-8	550	1500	Box	10		
			S2234	39PAR30/HAL/XEN/NFL/120V	NFL 34	120	Clear	1350	3 5/8	CC-8	530	1500	Box	15		
			Y16118 ▲	39PAR30/HAL/NFL25/120V	NFL 25	120	Clear	1700	3 5/8	CC-8	550	1500	Box	10		
			S2330	39PAR30/HAL/XEN/NFL/130V	NFL 34	130	Clear	1350	3 5/8	CC-8	530	2000	Box	15		
			Y16122 ▲	39PAR30/HAL/NFL25/130V	NFL 25	130	Clear	1700	3 5/8	CC-8	550	1500	Box	10		
			S2335	39PAR30/HAL/XEN/WFL/130V	WFL 50	130	Clear	750	3 5/8	CC-8	530	2000	Box	15		
			Y16119 ▲	39PAR30/HAL/WFL50/120V	WFL 50	120	Clear	600	3 5/8	CC-8	550	1500	Box	10		
			Y16123 ▲	39PAR30/HAL/WFL50/130V	WFL 50	130	Clear	600	3 5/8	CC-8	550	1500	Box	10		
			<i>SOFT RAY</i>	S4131	39PAR30/HAL/XEN/FL/FR/120V	FL 42	120	Frost	550	3 5/8	CC-8	500	1500	Box	15	5
			<i>SOFT RAY</i>	S4209	39PAR30/HAL/XEN/FL/FR/130V	FL 42	130	Frost	550	3 5/8	CC-8	500	2000	Box	15	5
				S2235	39PAR30/HAL/XEN/WFL/120V	WFL 50	120	Clear	750	3 5/8	CC-8	530	1500	Box	15	
60	PAR30	Med.	S2236	60PAR30/HAL/XEN/NSP/120V	NSP 9	120	Clear	10500	3 5/8	CC-8	1090	1500	Box	15		
			Y16127 ▲	60PAR30/HAL/S/SP10/120V	SP 10	120	Clear	12000	3 5/8	CC-8	1070	1500	Box	10		
			S2237	60PAR30/HAL/XEN/NFL/120V	NFL 34	120	Clear	2300	3 5/8	CC-8	1090	1500	Box	15		
			Y16128 ▲	60PAR30/HAL/S/NFL25/120V	NFL 25	120	Clear	3300	3 5/8	CC-8	1070	1500	Box	10		
			S2268	60PAR30/HAL/XEN/NFL/120V 2PK	NFL 34	120	Clear	2300	3 5/8	CC-8	1090	1500	Box	8-2pks		
			S2238	60PAR30/HAL/XEN/WFL/120V	WFL 50	120	Clear	950	3 5/8	CC-8	1090	1500	Box	15		
	Y16129 ▲	60PAR30/HAL/S/WFL50/120V	WFL 50	120	Clear	1300	3 5/8	CC-8	1070	1500	Box	10				