




60-Gallon Manual Closing Doors

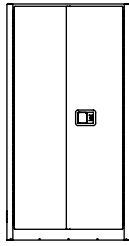

Model No.	SC60-MC-Y,-R,-B,-G,-PL
Color	Yellow (-Y), Red (-R), Green (-G), Blue (-B), Platinum (-PL)
Material Specifications	18-Gauge Steel with Reinforced Double-Wall Construction
Verification	Factory-Verified to UL 1275 Flammable Liquid Storage Performance Criteria
OSHA	Yes
NFPA 30	Yes
Door Style	Double Door Manual Close
UPC	033983097248 (Y) 033983097293 (B) 033983097330 (PL) 033983097279 (R) 033983097316 (G)
Dimensions, Exterior	34" W x 34" D x 65" H
Dimensions, Interior	30.52" W x 30.837" D x 60.277" H
Number of Doors	2
Number of Shelves	2
Lock	Keyed Cam Lock
Gallon Capacity	60
Liter Capacity	227 L
Replacement Shelf Model No.	X410185
Shelf Depth	30.154"
Net Weight, lbs.	346
Net Weight, kgs.	157
Adjustable Shelves	Yes
Warranty	10 Yr. Structural- Free After Fire Replacement Guarantee