




LED WALL PACK FIXTURE

Tunable Wattage & CCT

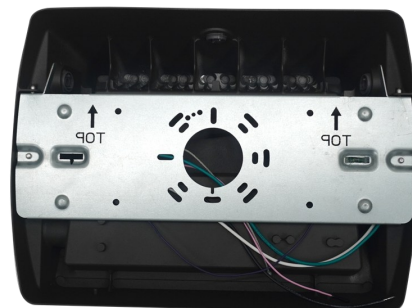

PRODUCT FEATURES

- **Tunable Power**
- **Tunable CCT - 3000K / 4000K / 5000K**
- Die-Cast Aluminum Alloy Housing
- Bronze Finish
- 120-277 Voltage Rating, PF > 0.9
- CRI > 70
- 135 Lm/W
- 0-10V Dimming
- Photocell Included (Off/On Switch)
- Glass Lens
- Beam Angle - 70 x 110°
- IP65 Rating - Suitable for Wet Locations
- DLC Listed
- ETL Certified
- 50,000 Hour Lifetime Rating
- 5-Year Limited Warranty
- Operating Temperature Range: -40°F to 104°F (-40°C to 40°C)

PRODUCT SPECIFICATIONS

MODEL	ITEM #	POWER (W)	LUMENS (LM)	INPUT VOLTAGE (V)	DIMENSIONS (IN) (L x W x H)
CLW12-120W-H-TCP	L120WTUNWMCL12	80W/100W/120W	10,800-16,200	120-277	13.35 x 9.84 x 5.79

