



Product Specifications

MODEL NUMBER	MOTOR SPECIFICATIONS	RPM	MAX VAC		MAX PRESS		HP	kW	NET WT.	
			"H ₂ O	mbar	"H ₂ O	mbar			lbs.	kg
R3305A-1	190-220/380-415-50-3	2850	28	70	31	77	1/3	0,25	29	13,2
	208-230/460-60-3	3450	40	100	43	107	1/2	0,37		

SOUND LEVEL	68/63 dB(A) MAX. @ 60/50 Hz
NORMAL AMBIENT	-29°C TO 40°C
RELATIVE HUMIDITY	0% - 100% NON CONDENSING
ENVIRONMENT	CLEAN DUST FREE

**TECHNICAL DATA SUBJECT TO
CHANGE WITHOUT NOTICE.**

Product Performance (Metric U.S. Imperial)

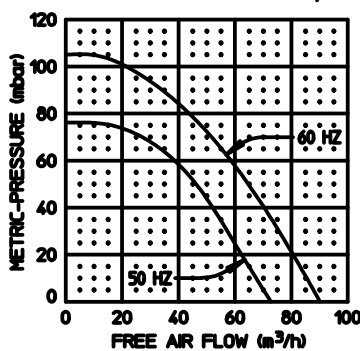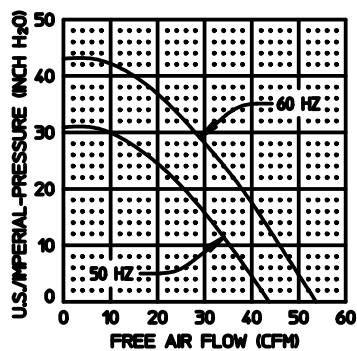

PERFORMANCE DATA

THE PERFORMANCE DATA SHOWN WAS DETERMINED UNDER THE FOLLOWING CONDITIONS:

**LINE VOLTAGE @ 60 Hz. 230V OR 460V FOR 3 PHASE
UNITS. 115V OR 230V FOR 1 PHASE UNITS.**

LINE VOLTAGE @ 50 Hz. 220V FOR 3 PHASE OR 1 PHASE UNITS.



UNITS IN A TEMPERATURE STABLE CONDITION.

DELIVERY MEASUREMENTS MADE WITH OUTPUT PORT THROTTLED.

SUCTION MEASUREMENTS MADE WITH INPUT PORT THROTTLED.

TEST CONDITIONS: INLET AIR DENSITY @ 0.075 lbs. per cu. ft. [20°C (68°F), 29.92" Hg (14.7 PSIA)].

NORMAL PERFORMANCE VARIATIONS ON THE RESISTANCE CURVE WITHIN $\pm 10\%$ OF SUPPLIED DATA CAN BE EXPECTED.

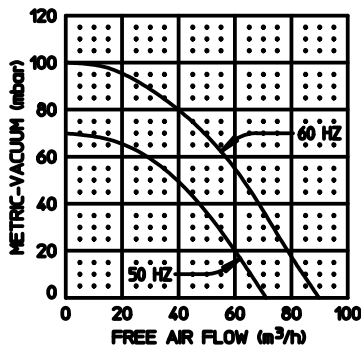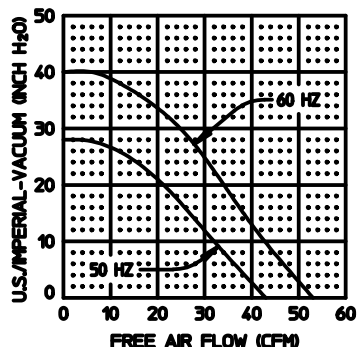

Product	Dimensions	Metric (mm) / U.S. Imperial (inches)
---------	------------	--------------------------------------

