

PRODUCT SPECIFICATIONS

ITEM NUMBER	MODEL DESCRIPTION	MAX. PRESSURE		VOLTAGE	FREQUENCY	HP	kW	NET WT.		AMPS	TANK SIZE
		PSI	BAR					lbs.	kg		
1069738	106R-25MQ2	116	8	120 VAC	60Hz	.75	.56	186	84	7.2	25L

NOTES:

1. TECHNICAL DATA SUBJECT TO CHANGE WITHOUT NOTICE
2. ALL DIMENSIONS ARE FOR REFERENCE ONLY.


MAX. SOUND: 58 dB(A), 13 SONES

AMBIENT: 5/40 °C


RELATIVE HUMIDITY: 20-80% NON CONDENSING

ENVIRONMENT: CLEAN DUST FREE

REGULATORY: cULus

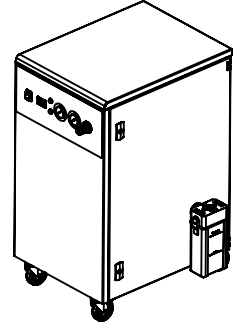

PRODUCT PERFORMANCE: FLOW LOSS OF 18% - 20% DURING DRYER PURGE CYCLE.

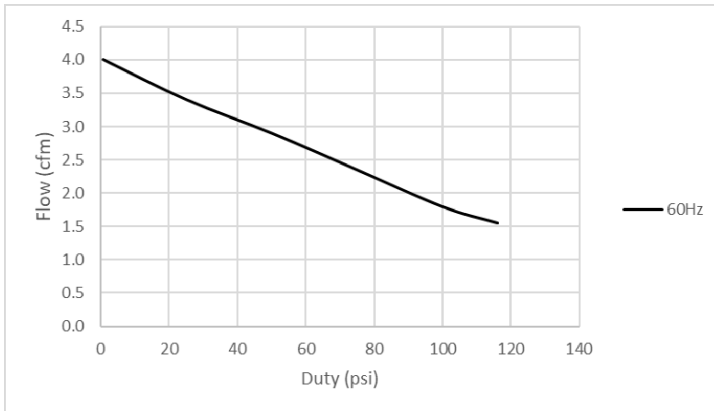

PRODUCT DIMENSIONS:

