

# Steel square covers

## COVERS FOR 4" SQUARE BOXES – CUBIC INCH CAPACITY (SEE BELOW)

UL LISTED

#8-32 screw used on covers



TP472

TP474

TP478  
TP487

TP473, TP475, TP476,  
TP477, TP479, TP483

TP850<sup>ⓑ</sup>

TP854<sup>ⓑ</sup>

AMR0

Cat. #	Description	Unit qty.	Wt. lbs. per 100	Capacity cu. in.
TP472 <sup>ⓓ</sup> <sup>ⓑ</sup>	Flat blank	50	31	-
TP474 <sup>ⓓ</sup>	Flat, open with ears 2 <sup>3</sup> / <sub>4</sub> "	50	21	-
TP478 <sup>ⓓ</sup> <sup>ⓑ</sup>	Flat, with 1/2" KO	50	31	-
TP487 <sup>ⓓ</sup>	Flat, with 3/4" KO	50	29	-
TP473 <sup>ⓓ</sup>	Raised 1/4", open with ears 2 <sup>3</sup> / <sub>4</sub> "	50	23	1.3
TP476 <sup>ⓓ</sup>	Raised 1/2", open with ears 2 <sup>3</sup> / <sub>4</sub> "	50	26	4.0
TP477 <sup>ⓓ</sup> <sup>ⓑ</sup>	Raised 5/8", open with ears 2 <sup>3</sup> / <sub>4</sub> "	50	27	5.0
TP475 <sup>ⓓ</sup>	Raised 3/4", open with ears 2 <sup>3</sup> / <sub>4</sub> "	25	31	6.0
TP479 <sup>ⓓ</sup>	Raised 1", open with ears 2 <sup>3</sup> / <sub>4</sub> "	25	34	7.0
TP483 <sup>ⓓ</sup> <sup>ⓑ</sup>	Raised 1 1/4", open with ears 2 <sup>3</sup> / <sub>4</sub> "	25	31	9.5
AMR0 <sup>ⓓ</sup>	3/4" - 1 1/2" round adjustable mud ring	25	44	6.1

### Air Plenum

TP850 <sup>ⓑ</sup>	Flat blank gasketed with captive screws	25	31	-
TP854 <sup>ⓑ</sup>	Flat ring double gasketed	25	12	-

<sup>ⓑ</sup> For air plenum (no mounting holes) - not UL Listed.

<sup>ⓐ</sup> cUL Listed.


<sup>ⓓ</sup> ETL listed.

<sup>ⓓ</sup> CSA certified.

<sup>ⓑ</sup> Available in painted options.

## MUD RINGS FOR 4" SQUARE STEEL OUTLET BOXES

UL LISTED

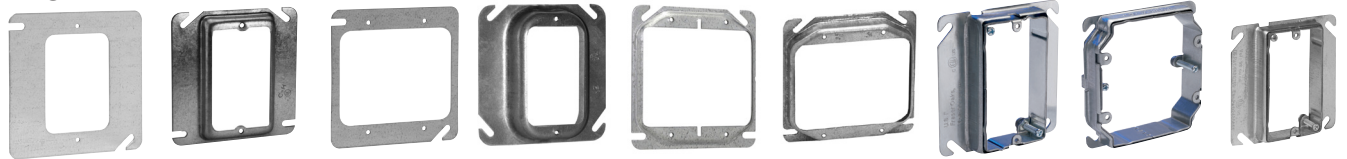

TP480

TP482, TP484,  
TP486, TP489

TP494

TP488, TP490

TP496

TP501, TP502

AMR1

AMR2

AMR158

Cat. #	Description	Unit qty.	Wt. lbs. per 100	Capacity cu. in.
<b>One Device</b>				
TP480 <sup>ⓓ</sup>	Flat	50	20	-
TP482 <sup>ⓓ</sup>	1/4" raised	50	21	1.8
TP484 <sup>ⓓ</sup> <sup>ⓑ</sup>	1/2" raised	50	23	3.8
TP489 <sup>ⓓ</sup> <sup>ⓑ</sup>	5/8" raised	50	26	4.3
TP486 <sup>ⓓ</sup> <sup>ⓑ</sup>	3/4" raised	50	30	5.5
TP488 <sup>ⓓ</sup>	1" raised	50	34	6.8
TP490 <sup>ⓓ</sup>	1 1/4" raised	25	39	8.5
AMR1 <sup>ⓐ</sup>	3/4" - 1 1/2" raised adjustable	25	47	-
AMR158 <sup>ⓐ</sup>	5/8" - 1 1/4" raised adjustable	25	44	6.0
<b>Two Device</b>				
TP494 <sup>ⓓ</sup>	Flat	50	12	-
TP496 <sup>ⓓ</sup> <sup>ⓐ</sup>	1/4" raised	50	13	3.0
TP498 <sup>ⓓ</sup> <sup>ⓐ</sup>	1/2" raised	50	18	6.0
TP499 <sup>ⓓ</sup> <sup>ⓐ</sup>	5/8" raised	50	22	8.0
TP500 <sup>ⓓ</sup> <sup>ⓐ</sup>	3/4" raised	50	24	9.0
TP501 <sup>ⓓ</sup>	1 1/4" raised	25	31	14.0
TP502 <sup>ⓓ</sup>	1" raised	25	30	11.7
AMR2 <sup>ⓐ</sup>	5/8" - 1 1/2" raised adjustable	25	50	11.3

<sup>ⓐ</sup> cUL Listed.

<sup>ⓓ</sup> CSA certified.

<sup>ⓐ</sup> Slotted design for use with 4" square box partitions.

<sup>ⓑ</sup> Available in painted options.