

Liquid Tight Straight Fitting

Size Range: 3/8" - 4"

Product Series: STR Seal Tight Fitting Reuseable

Material: Solid Alloy Steel Construction AL and SS Options

Zinc Plated with a Chromate Finish **

Made in the USA

Features:

Precision Machined Cut Threads NPT

Furnished with Steel Locknut and Sealing Washer





Extra Long Ferrule Engages Conduit Provides Exceptional Retention & Bend Radius

UL Rated Concrete Tight Suitable for Direct Burial

Twice the Strength and Durability of ALL Die Cast and Malleable Products

Full FLAT HEX Surface with
EZ Torque Steel Compression Nuts
Torques Tight & Right

Industrial SPEC-grade

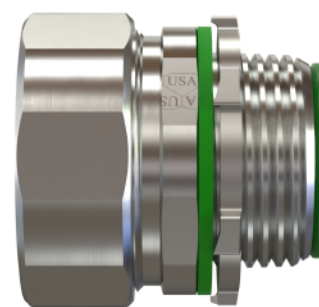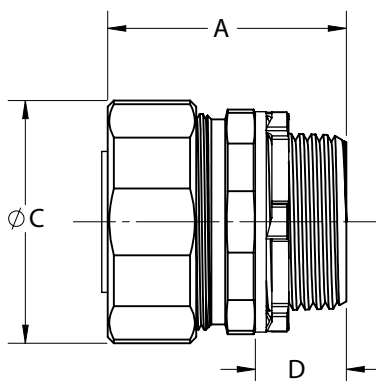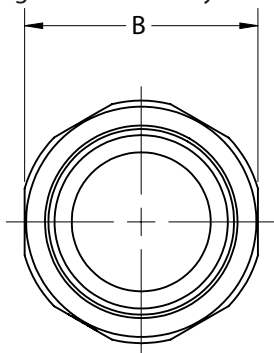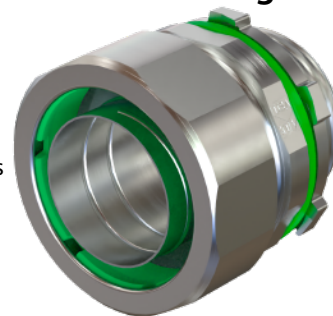

Shown with Optional Bushing

Cat # *	Trade Size	A Length	B Hex	C Diameter	D Thread Length	Wt. Per/C
STR38	3/8"	1-3/8"	1-1/16"	1-1/8"	5/8"	12
STR50	1/2"	1-3/16"	1-1/8"	1-3/16"	5/8"	13
STR75	3/4"	1-7/16"	1-3/8"	1-7/16"	5/8"	17
STR100	1"	1-3/4"	1-11/16"	1-3/4"	11/16"	26
STR125	1-1/4"	2-3/16"	2-1/16"	2-3/16"	11/16"	46
STR150	1-1/2"	2-3/8"	2-5/16"	2-3/8"	3/4"	59
STR200	2"	2-7/8"	2-3/4"	2-7/8"	3/4"	84
STR250	2-1/2"	3-7/16"	3-1/4"	3-7/16"	1-1/8"	147
STR300	3"	4"	3-15/16"	4"	1-1/8"	174
STR350	3-1/2"	4-9/16"	4-7/16"	4-9/16"	1-1/8"	219
STR400	4"	5-1/8"	4-15/16"	5-1/8"	1-1/8"	256

** Add suffix "B" for insulated throat

Compliances:

UL 514 B, 467

NEMA Standard FB1

Rated NEMA Types 2, 3, 3R, 3, 4X, 5, 12, 13

NEC: Class I, Division 2

Class II, Divisions 1 and 2

Class III, Divisions 1 and 2

Federal Standard A-A-50553

UL Rated for Wet Locations Guaranteed to Seal Out Liquids,
Contaminants & Ingress of Other Fluids Suitable for Direct Burial

CSA Standard: C22.2 No. 18F

RoHS Compliant

REACH Compliant

CA Prop 65 Compliant

UNSPSC 39123033



Available Options:

** Material Options: ALUMINUM - Copper Free

Add Suffix "AL" to Cat #; Stainless Steel Consult Factory

** Insulated Throat Bushing 105° UL Rating

Factory Installed Bushing - Add Suffix "B" to Above Cat #

Configurations: 90° and 45°

Transition Fittings - Adapters to Convert

EMT to Liquid Tight, Right Conduit to Liquid Tight

Options of:

Grounding Lugs AL and CU

Wire Mesh Strain Relief

** Galvanized Plating Option Available

STR Series is NOT Rated nor Recommended for Type B Conduit
See our NMLT Series