

Rigid Conduit/IMC Fittings

Threadless Compression Connectors

- Malleable iron/zinc plated



CAT. NO.	CONDUIT SIZE (IN.)	STD. CTN.
Die-Cast Zinc Flexible Metal Conduit to EMT		
HC-401	½	300
HC-402	¾	150
HC-403	1	90
HC-404	1¼	60
HC-405	1½	30
HC-406	2	12
HC-407	2½	12
HC-408	3	6
HC-409	3½	6
HC-410	4	6

Suggested use — rigid conduit only.

UL File No. E-23018 ½"–1¼".



Threadless Compression Couplings


- Malleable iron/zinc plated



CAT. NO.	CONDUIT SIZE (IN.)	STD. CTN.
HK-401	½	300
HK-402	¾	150
HK-403	1	90
HK-404	1¼	60
HK-405	1½	30
HK-406	2	6
HK-407	2½	6
HK-408	3	4
HK-409	3½	4
HK-410	4	4

Suggested use — rigid conduit only.

UL File No. E-23018 ½"–1¼".

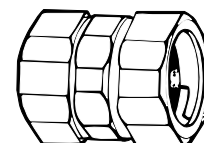

Set-Screw Connectors

- Steel
- Zinc plated



CAT. NO.	CONDUIT SIZE (IN.)	DIMENSIONS (IN.)		STD. CTN.
		A	B	
<i>Die-Cast Zinc Flexible Metal Conduit to EMT</i>				
HC-101	½	1⅞	1⅞	100
HC-102	¾	1⅞	1½	50
HC-103	1	⅞	1⅞	50
HC-104	1¼	2	2	25
HC-105	1½	2½	2⅞	25
HC-106	2	2¾	2⅞	20
HC-107	2½	3⅝	3⅞	10
HC-108	3	4⅝	3⅞	5
HC-109	3½	4⅞	3⅞	5
HC-110	4	5⅝	4⅝	5

One set screw or two. Two set screws starting at 2" trade size.

Suggested use — rigid conduit only.

UL File No. E-23018 ½"–1¼".

Insulated




CAT. NO.	CONDUIT SIZE (IN.)	DIMENSIONS (IN.)		STD. CTN.
		A	B	
		<i>Die-Cast Zinc Flexible Metal Conduit to EMT</i>		
HC-701	½	1⅞	1⅞	100
HC-702	¾	1⅞	1½	50
HC-703	1	⅞	1⅜	25
HC-704	1¼	2	2	25
HC-705	1½	2½	2⅞	25
HC-706	2	2¾	2⅞	20
HC-707	2½	3⅜	3⅞	10
HC-708	3	4⅜	3⅞	5
HC-709	3½	4¾	4⅞	5
HC-710	4	4¾	4⅞	5

One set screw or two. Two set screws starting at 2" trade size.

Suggested use — rigid conduit only.

UL File No. E-23018 ½"–1¼".

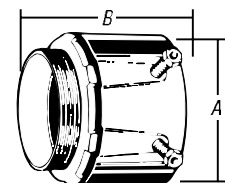

Set-Screw Couplings

- Steel (concrete tight) when taped
- Zinc plated



CAT. NO.	CONDUIT SIZE (IN.)	DIMENSIONS (IN.)		STD. CTN.
		A	B	
HK-101	½	1⅞	2⅜	100
HK-102	¾	1⅞	2⅜	50
HK-103	1	1⅞	2⅜	25
HK-104	1¼	2	2⅜	25
HK-105	1½	2¼	3⅜	25


Two set screws starting at 2".

UL File No. E-23018.

CAT. NO.	CONDUIT SIZE (IN.)	DIMENSIONS (IN.)		STD. CTN.
		A	B	
HK-106	2	2¾	3⅜	20
HK-107	2½	3⅞	3⅜	10
HK-108	3	4⅞	4⅞	5
HK-109	3½	4⅞	4⅞	5
HK-110	4	5⅞	5⅞	5


Two set screws starting at 2".

UL File No. E-23018.

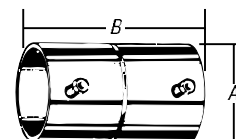

Rigid Connectors — Set-Screw Type — Die-Cast Zinc

CAT. NO.	TRADE SIZE (IN.)	DIMENSIONS (IN.)		STD. CTN.
		A	B	
HC-203	1	1.54	.49	100
HC-802	¾	1.44	.45	250
HC-803	1	1.54	.49	100

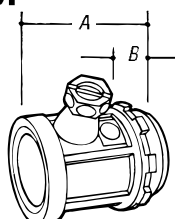

Rigid Connectors — Set-Screw Type — Die-Cast Zinc

CAT. NO.	TRADE SIZE (IN.)	DIMENSIONS (IN.)		STD. CTN.
		A	B	
HK-201	½	1.77	1.09	250
HK-203	1	2.29	1.61	100

