

Compression Lug Splices

Long Barrel

Features

- Seamless, high conductivity copper tubing, suitable for heavy duty applications
- Tin-plated to provide corrosion resistance
- Color coded

Applications


- Suitable for use at voltages up to 35 KV provided connector is properly taped
- 5 KV is the maximum voltage in all bare splice applications

Standard Material

- Copper


Standard Finish

- Tin plated

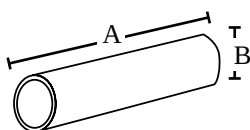

Catalog Number	UPC	Wire Size	Color Code	Unit Carton	Ship Case	Weight/Case	A	B
3101	41080	#8	Red	100	1000	22	1.75	.20
3102	41081	#6	Blue	100	1000	22	1.75	.20
3103	41082	#4	Gray	100	1000	26	1.75	.25
3105	41084	#2	Brown	50	500	21	1.90	.31
3106	41085	1/0	Pink	25	250	19	2.20	.39
3107	41086	2/0	Black	25	250	20	2.25	.44
3108	41087	3/0	Orange	25	250	23	2.25	.49
3109	41088	4/0	Purple	25	250	32	2.75	.55
3109A	41089	250 MCM	Yellow	10	100	20	3.25	.59
3109B	41090	300 MCM	White	10	100	23	3.50	.66
3110	41091	350 MCM	Red	10	100	28	3.75	.70
3110A	41092	400 MCM	Blue	10	100	32	3.75	.76
3111	41093	500 MCM	Brown	5	50	25	4.25	.83
3111A	81810	600 MCM	Green	5	50	34	4.50	.93
3112	81811	750 MCM	Black	5	50	41	4.75	1.03

Short Barrel

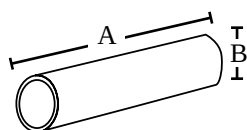

Catalog Number	UPC	Wire Size	Color Code	Unit Carton	Ship Case	Weight/Case	A	B
3301	81599	#8	Red	100	1000	12	.90	.17
3302	81600	#6	Blue	100	1000	14	1	.20
3303	81601	#4	Gray	100	1000	16	1	.25
3305	81602	#2	Brown	100	1000	27	1.25	.31
3305A	81603	#1	Green	50	500	23	1.60	.39
3306	81604	1/0	Pink	50	500	26	1.75	.44
3307	81605	2/0	Black	50	500	29	1.75	.49
3308	81606	3/0	Orange	50	500	34	1.90	.55
3309	81607	4/0	Purple	25	250	23	2	.59
3309A	81608	250 MCM	Yellow	25	250	29	2.10	.66
3310	81609	350 MCM	Red	20	200	31	2.10	.70
3310A	81610	400 MCM	Blue	10	100	21	2.30	.76
3311	81611	500 MCM	Brown	10	100	29	2.50	.83
3311A	81612	600 MCM	Green	5	50	20	2.50	.93
3312	81613	750 MCM	Black	5	50	29	3.21	1.03