

LOW VOLTAGE PRODUCTS

PRODUCT FEATURES

► Install LVSB series between studs on SSB bracket, visit page P7 for more information

Cat. No.	Description	Std. Pkg.
LVSB1 NEW	1-Gang Low Voltage Stud Mounting Bracket	50
LVSB2 NEW	2-Gang Low Voltage Stud Mounting Bracket	25
LVWP1 NEW	1-Gang Low Voltage Wall Mounting Plate	50
LVWP2 NEW	2-Gang Low Voltage Wall Mounting Plate	25




FIXED BAR HANGERS



PRODUCT FEATURES

► For Stud and T-Bar

Cat. No.	Description	Std. Pkg.
BHT-1	24" T-Bar bracket for use with boxes 1-1/2" or 2-1/8" Deep, with BHT-C Box Clip	50
BHT-1A	24" T-Bar bracket - 8" height adjustable, with BHT-C Box Clip	50
BH-1	24" Straight bar hanger for mounting ceiling boxes, Slotted, Includes 2 Stove Bolts per Unit	50
BH-1C	24" Straight bar hanger for mounting ceiling boxes, with BH-C Box Clip	50
BH-1S	20" Straight bar hanger for mounting ceiling boxes, Slotted, Includes 2 Stove Bolts per Unit	50
BH-1SC	20" Straight bar hanger for mounting ceiling boxes, With BH-C Box Clip	50
BH-2NC	21" Offset (1-1/2") bar hanger for mounting boxes with ring, Slotted, Includes 2 Stove Bolts/Unit	50
BH-C	Additional box clip & screw set for use with BH-1, BH-1S & BH-2NC	100
BH-3	Straight bracket for mounting architectural recess lights 25-1/4" long with notches 24" apart for use on T-Bar	50
BHT-C	Additional box clip & screw set for use with BHT-1 & BHT-1A	100


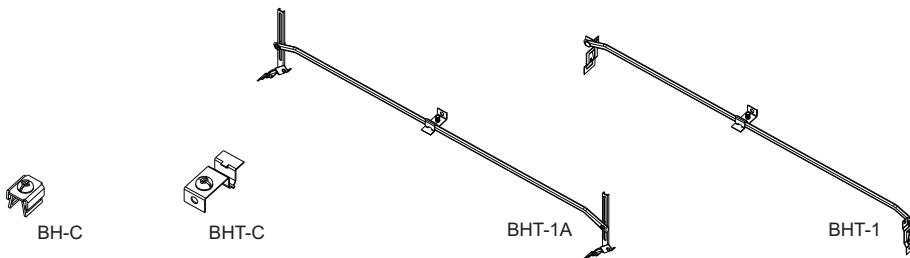


BHT-1 INSTALLATION VIEW

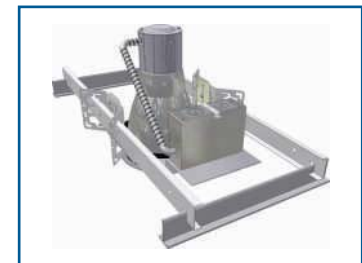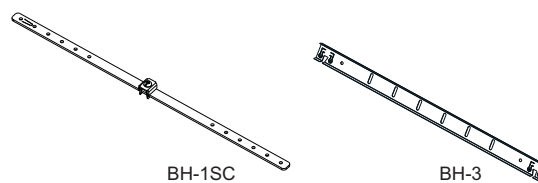

BH-3 INSTALLATION VIEW

Visit Page P15 for more BH-3 Installation Photos

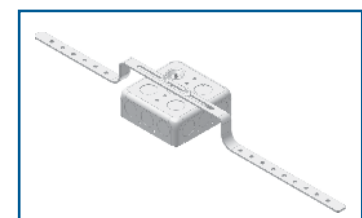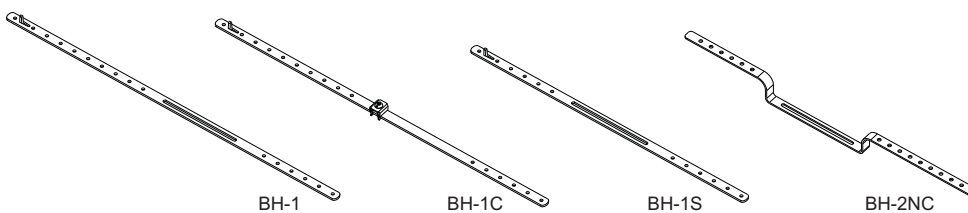

BH-2NC INSTALLATION VIEW



ULTIMATE SUPPORT BRACKETS AND ACCESSORIES


PRODUCT FEATURES

- ▶ Can be floor or wall mounted on wooden or metal studs
- ▶ Infinite height and width combinations
- ▶ Provides flexibility at job site
- ▶ Works great with Orbit's Adjustable Rings
- ▶ Markings on bracket allow for quick and consistent adjustability.

NOTE

USB must be accompanied with either US4SB, UMA, UMA-LVBS, WBAR1G or WBAR2G mounting brackets to attach a steel box

Cat. No.	Description	Std. Pkg.
USB	Ultimate Support Bracket, Adj. 8"-24" as a floor brkt or 14"-24" as a wall brkt between studs	12
US4SB	Mounting Bracket for 4" Square Box, snaps to USB	24
UMA	Universal Mounting Adapter for 4" and 4-11/16" Boxes to mount to USB, and directly to stud	25
USDBM	For use with USB to create a double box in floor mount assembly with built-in back support	50
USTBM	For use with USB to create a triple box in floor mount assembly with built-in back support	50
USTS	USB floor mount stud-to-stud top support	50
USB-4SDB-50/75-PT	Complete Pre-Assembled Floor Bracket with a 4" Square 2-1/8" Deep Box, Includes installed Far-Side Back Support and Ground Pigtail	12
USB-5SDB-50/75-PT	Complete Pre-Assembled Floor Bracket with a 4-11/16" Square 2-1/8" Deep Box, Includes installed Far-Side Back Support and Ground Pigtail	12
LVSB1	Low Voltage Stud Mounting Bracket 1-Gang	50
LVSB2	Low Voltage Stud Mounting Bracket 2-Gang	25

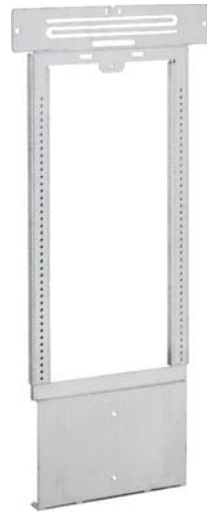

USB



US4SB



UMA



LVSB1



LVSB2



USDBM



USTBM



USTS

Adjustable
8" to 24"



USB-4SDB-50/75-PT

Complete
Prefabricated
Assembly



USB-5SDB-50/75-PT