


JOB NAME:

DATE:

TYPE:

COMMENTS:

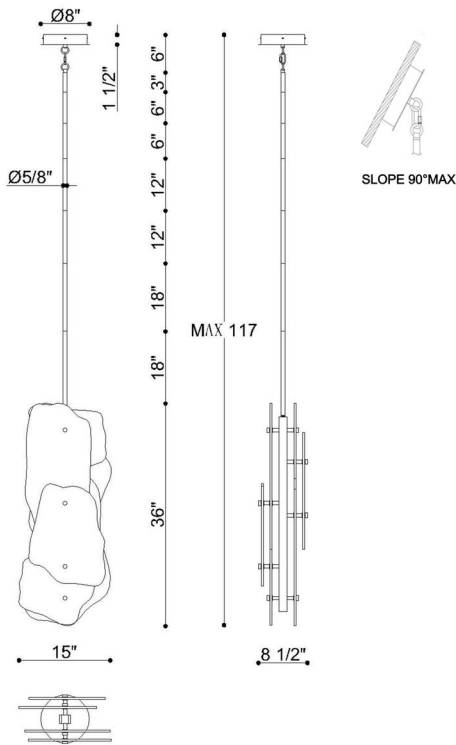

LIGHT INFORMATION

Light Type	Integrated LED
CRI	90
Delivered Lumens	1052
Color Temperature	3000K
LED Lifespan (L70)	50000
Light Direction	Ambient
Dimming Method	Triac/Elv
Current Type	DC
Input Voltage	120
Total Wattage	39

DIMENSIONS & WEIGHT

Length (In)	15
Width (In)	8.5
Max Height (In)	117
Weight (Lbs)	48.4

INSTALLATION

Mounting Type	J-Box
Rating	Dry
Hanging Support Type	Rod
Slope Compatible	Yes

PRODUCT FINISH

Antique Brass

SHADE FINISH

Geometric Mixed Glass

PRODUCT FEATURES

Each glass piece is handcrafted by artisans. Subtle variations in shape, size, or color are to be expected.

CERTIFICATIONS & COMPLIANCE

