



MUSTEE
Preferred by the "Pros"

10 Utility Sink



Design features:

- Molded using matched metal molds with premium fiberglass blended with special resins for extra strength and durability
- 17 gallon capacity, extra deep bowl — self-rimming
- Includes 1-1/2" drain assembly with stopper
- Connects to standard 1-1/2" P or S trap
- Accommodate single or dual-handle faucet with 4" or 8" center
- Available in white and bone
- Stain resistant, semi-gloss, colorfast finish
- Easy to clean

Code Accepted

Mustee utility sinks meet or exceed performance requirements:

- International Association of Plumbing and Mechanical Officials (IAPMO)® Listed
- Warnock Hersey® (Canada) Listed—CSA #B45.0 and #B45.5
- American National Standards Institute (ANSI)—Specification Z 124-2011




Specifications

Model No.	Color	UPC
10	White	6 71031 00001 9
10BN	Bone	6 71031 00006 4

Dimension	Length	Width	Depth
Overall	22"	25"	13-3/4"
Inside Bowl	15-3/4"	21-3/8"	13-1/4"
Countertop Cutout	21"	24"	—

General: Furnish and install as shown on plans a Countertop Sink Model 10 as manufactured by E.L. Mustee & Sons, Inc. Material composition shall be molded fiberglass, using matched metal dies under heat and pressure. One-piece, seamless construction with self-rimming edge and complete 1-1/2" drain assembly. Shall meet ANSI Z 124-2011. Overall size 22" length x 25" width x 13-3/4" depth, weight 14 lbs., Color: ____ (White, Bone).

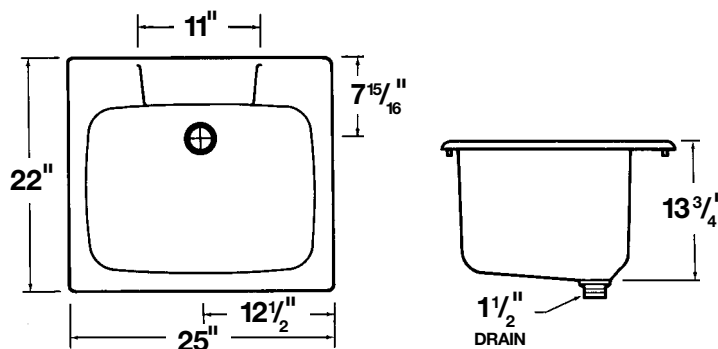

MUSTEE

E.L. Mustee & Sons, Inc. • 5431 West 164th Street • Brook Park, OH 44142 • Phone: 216.267.3100 • Fax: 216.267.9997
E-mail: info@mustee.com • Web: www.mustee.com • Proudly made in the USA

Notice: Our continuous commitment to product improvement may result in changes to product specifications without notice.
Patents pending. Made and Printed in U.S.A.