

ART VERSION #: 2

ART REVISION DATE: 09/13/2016

FINAL ART DATE: 09/00/2016

SPEC #: A01-1116-1630 A


PART #: 3235 829538 01

510.5

PHILIPS LIGHTING USA	
Brand	PHILIPS
Product Family	LED
Shape	Prof PAR38 Glass
Wattage	13.5W
Master Brand Template Ref.	New
SGS number	XXXXXXX
6NC #	468199
PKG PART #	3235 829538 01
DIE #	3241 648 04431
CRC #	CRC_XXXUS
Barcode No.	046677468194
Operator(s)	donna.raia@philips.com
VERSION No.	v1
Date	Aug 29, 2016
Cyan	<input type="checkbox"/>
Magenta	<input type="checkbox"/>
Yellow	<input type="checkbox"/>
Black	<input type="checkbox"/>
Die	<input type="checkbox"/>
Date Check	
<input type="checkbox"/> Check briefing Traffic	
Artwork document	
<input type="checkbox"/> Legend	<input type="checkbox"/> Number of colors
<input type="checkbox"/> 12NC	<input type="checkbox"/> Trapping/Bleed
<input type="checkbox"/> Barcode	<input type="checkbox"/> Images hires
<input type="checkbox"/> Diecut	<input type="checkbox"/> Jobsizes
Approval	
<input type="checkbox"/> QC Lithographer	
<input type="checkbox"/> Product Manager	
<input type="checkbox"/> Traffic Manager	

365.5

136

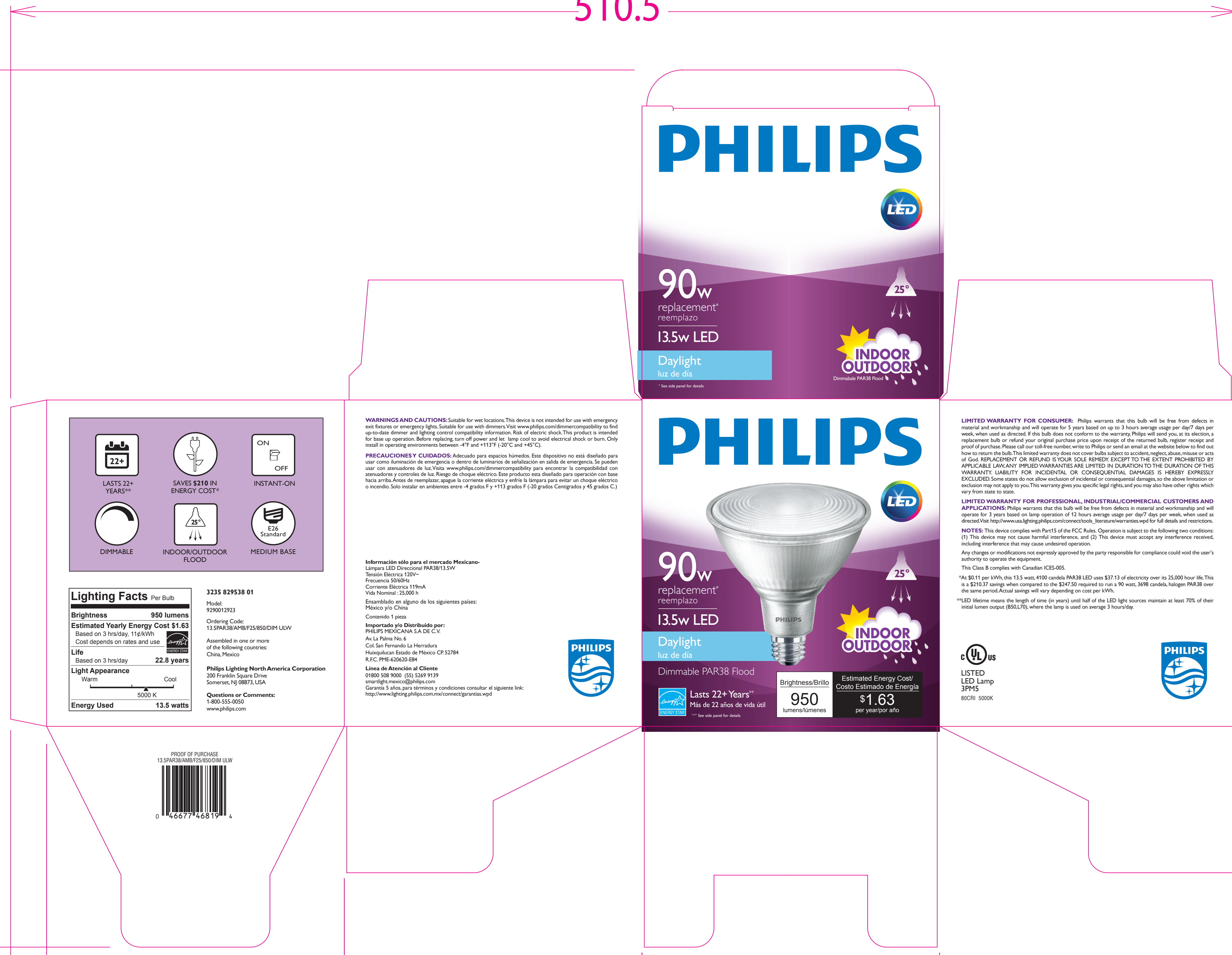

LASTS 22+ YEARS**	SAVES \$210 IN ENERGY COST*	INSTANT-ON
DIMMABLE	INDOOR/OUTDOOR FLOOD	MEDIUM BASE

WARNINGS AND CAUTIONS: Suitable for wet locations. This device is not intended for use with emergency exit fixtures or emergency lights. Suitable for use with dimmers. Visit www.philips.com/dimmercompatibility to find up-to-date dimmer and lighting control compatibility information. Risk of electric shock. This product is intended for base up operation. Before replacing, turn off power and let lamp cool to avoid electrical shock or burn. Only install in operating environments between -4°F and +113°F (-20°C and +45°C).

PRECAUCIONES Y CUIDADOS: Adecuado para espacios húmedos. Este dispositivo no está diseñado para usar como iluminación de emergencia o dentro de luminarios de señalización en salida de emergencia. Se pueden usar con atenuadores de luz. Visita www.philips.com/dimmercompatibility para encontrar la compatibilidad con atenuadores y controles de luz. Riesgo de choque eléctrico. Este producto está diseñado para operación con base hacia arriba. Antes de reemplazar, apague la corriente eléctrica y enfríe la lámpara para evitar un choque eléctrico o incendio. Solo instalar en ambientes entre -4 grados F y +113 grados F (-20 grados Centígrados y 45 grados C.)

Información sólo para el mercado Mexicano-
Lámpara LED Direccional PAR38/13.5W
Tensión Eléctrica 120V~
Frecuencia 50/60Hz
Corriente Eléctrica 119mA
Vida Nominal: 25,000 h
Ensamblado en alguno de los siguientes países: México y/o China
Contenido: 1 pieza
Importado y/o Distribuido por:
PHILIPS MEXICANA S.A DE C.V.
Av. La Palma No. 6
Col. San Fernando La Herradura
Huaquepán Estado de México CP 52784
R.F.C. PME-620620-E84
Línea de Atención al Cliente
01800 508 9000 (35) 5269 9139
smartlight.mexico@philips.com
Garantía 5 años, para términos y condiciones consultar el siguiente link:
<http://www.lighting.philips.com.mx/connect/garantias.wpd>

Lighting Facts Per Bulb	
Brightness	950 lumens
Estimated Yearly Energy Cost \$1.63	
Based on 3 hrs/day, 11¢/kWh	
Cost depends on rates and use	
Life	22.8 years
Based on 3 hrs/day	
Light Appearance	5000 K
Warm ————— Cool	
Energy Used	13.5 watts

3235 829538 01
Model: 9290012923
Ordering Code: 13.5PAR38/AMB/F25/850/DIM/ULW
Assembled in one or more of the following countries: China, Mexico
Philips Lighting North America Corporation
200 Franklin Square Drive
Somerset, NJ 08873, USA
Questions or Comments:
1-800-555-0050
www.philips.com



15 124 124 124 123.5

250g Duplex(CCNB)+F flute 67g