




Submersible Sewage Pump Specifications

Part No.	MA0387X-6	MA0387X-8	MA0387X-8A	MA0387X-9	MA0387X-9A
HP	1/2	3/4	3/4	1	1
Volt/HZ	115/60	115/60	230/60	115/60	230/60
F.L Amp	4.9	9.2	4.5	14.2	7.1
Max Flow	3200 GPH	5600 GPH	5600 GPH	7250 GPH	7250 GPH
Max Head	26 feet	38 feet	38 feet	49 feet	49 feet
Housing Material	Stainless Steel	Stainless Steel	Stainless Steel	Stainless Steel	Stainless Steel
Discharge	1-1/2" NPT	2" NPT	2" NPT	2" NPT	2" NPT
Switch type	Tethered	Tethered	Tethered	Tethered	Tethered
Thermal Protected	Yes	Yes	Yes	Yes	Yes
Cable Length	20' with plug	20' with plug	20' with plug	20' with plug	20' with plug
Impeller material	Cast iron	Cast iron	Cast iron	Cast iron	Cast iron
Weight	19	38	38	45	45

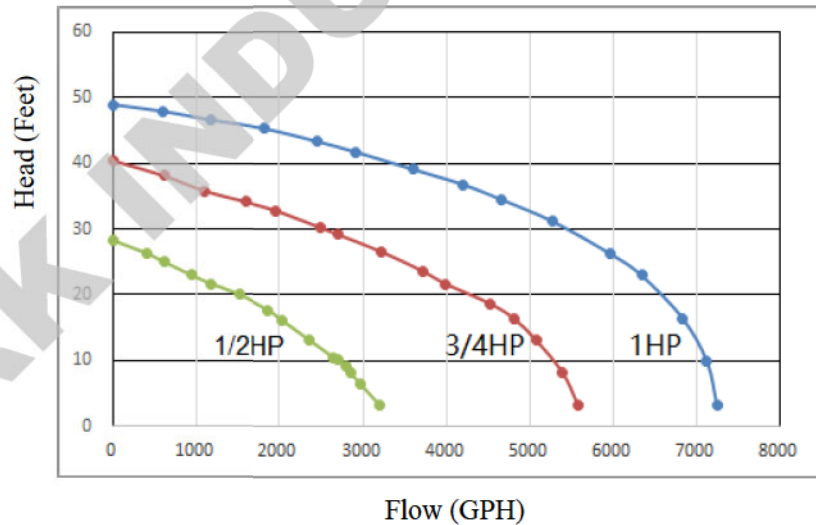

HALLMARK INDUSTRIES, INC.