


# ASSEMBLY AND INSTALLATION INSTRUCTIONS

P0452 / P0453 / P0459

**WARNING:** TO AVOID RISK OF ELECTRICAL SHOCK, BE SURE TO SHUT OFF POWER WHILE INSTALLING OR SERVICING THIS FIXTURE.

**NOTES:** 1. Before installing, consult local electrical codes for wiring and grounding requirements.  
2. Read and save this instruction.

## Hardware Package (included):

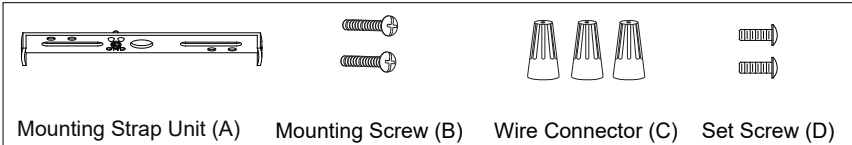

## Installation Steps

Turn off the power at fuse or circuit box.

1. Rod Connections:
  - a. Thread the fixture wire from the fixture through the lower rod, then secure the lower rod onto fixture using the threaded pipe.
  - b. Thread the fixture wire through the middle rods, and then secure the middle rods onto the lower rod using the threaded pipe.
  - c. Thread the fixture wire through the upper rod, and then secure the upper rod onto the middle rod using the threaded pipe.

**Note:** Length adjustable from 18-3/4" to 48-3/4". Use fewer rods if shorter length is desired.
2. Thread the fixture wire through the canopy kit, then secure the rod assembly to the set threaded pipe of the canopy kit.
3. Unscrew the two set screws (D) and separate the mounting strap unit (A) from the fixture.
4. Attach the mounting strap unit (A) to outlet box by using two mounting screws (B).
5. Pull out the source wires from the outlet box. Make wire connections using wire connectors (C) as follows:
  - Connect the smooth-coated wire (marked) from the fixture to the black wire from the power source.
  - Connect the ribbed-coated wire (unmarked) from the fixture to the white wire from the power source.
  - Attach the fixture ground wire to the mounting strap unit (A) with the green ground screw, then connect it to the house ground wire with a wire connector (C).Carefully put the wires back into the outlet box.
6. Attach the fixture to the mounting strap unit (A), and then secure it with two set screws (D).
7. Install 1 X 60W Max. medium base bulb (not included).

**See relamping label at socket area or packaging for maximum wattage allowed.**
8. Attach the glass shade to the fixture, and then secure it with three fixture screws.


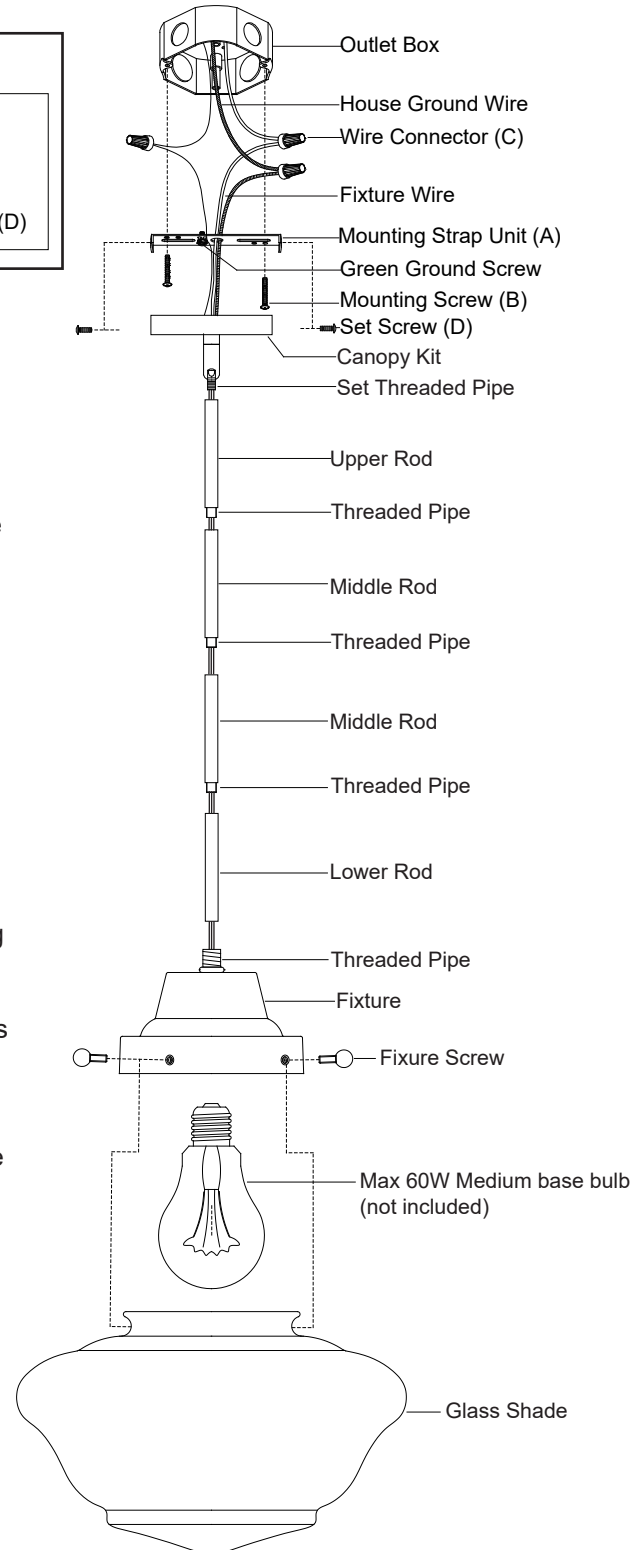


Fig. 1

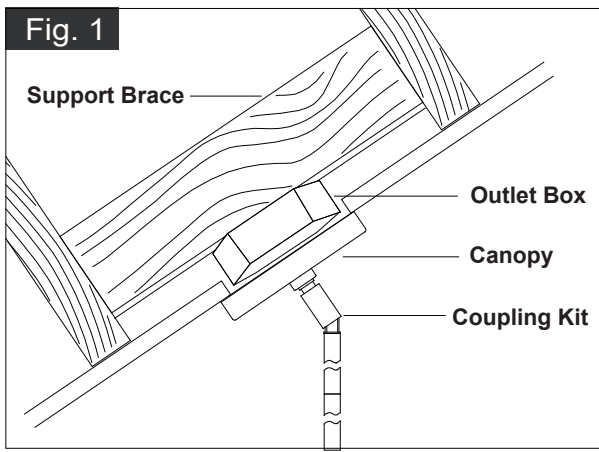


9. Angled mounting recommended for a vaulted or angled ceiling.  
(See Fig.1)

Turn on the power at fuse or circuit box.

The following parts are available for re-order if damaged or missing.

### Spare Parts List:

|                                                                                                       |                    |                    |               |                                                                     |                                                                    |                        |
|-------------------------------------------------------------------------------------------------------|--------------------|--------------------|---------------|---------------------------------------------------------------------|--------------------------------------------------------------------|------------------------|
|                                                                                                       |                    |                    |               |                                                                     |                                                                    |                        |
| Mounting Strap Unit (A)                                                                               | Mounting Screw (B) | Wire Connector (C) | Set Screw (D) | 12" Rod<br>3440RD for P0452<br>3442RD for P0453<br>3448RD for P0459 | 6" Rod<br>3441RD for P0452<br>3443RD for P0453<br>3449RD for P0459 | Glass Shade<br>10547OP |
|                                                                                                       |                    |                    |               |                                                                     |                                                                    |                        |
| Mounting Hardware<br>7128MM (1 SET) for P0452<br>7129MM (1 SET) for P0453<br>7174MM (1 SET) for P0459 |                    |                    |               |                                                                     |                                                                    |                        |

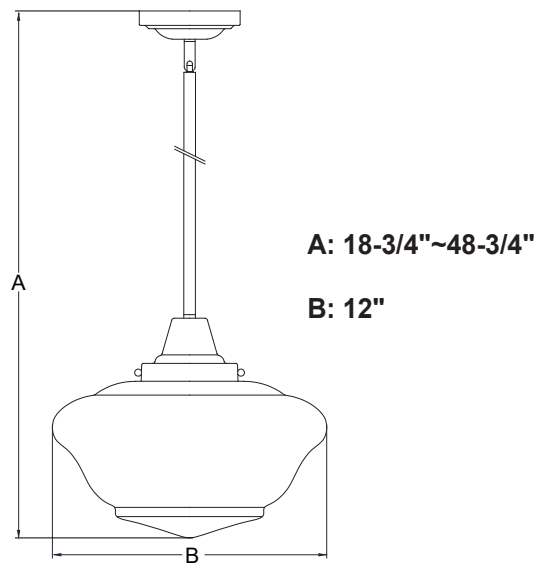

### 1 Year Warranty

Vaxcel warrants all of our products against defects in workmanship and finishes for one year following the date of shipment.

*Exclusions: This warranty does not include the failure of products from extreme acts of nature; environmental conditions not suited for the products intended use; operation in temperatures outside of the range specified in the instruction manual; usage with improper power supply, power surges or dips. For coastal locations, some corrosion is considered normal for the environment.*

*Vaxcel reserves the right to repair, replace or issue a credit for any properly installed product, provided it is returned per RMA instruction. This warranty is limited to the cost of the product only and does not extend to transportation, installation or replacement costs.*

How can warranty service be obtained?

info@vaxcel.com  
1-800-482-9235