



LOCATION		DATE
PREPARED BY		QUANTITY
COMMENTS		FIXTURE TYPE
CATALOG NUMBER		

Emma LED Ceiling EMAF Series

Features

Decorative ceiling fixture features low profile decorative metal canopy with a solid glass diffuser. Ideal use in hallways, entrances or anywhere general lighting is needed. Provides lighting in residential, commercial and hospitality applications. Fixture mounts to standard junction box (not included).

Construction

Steel frame. The canopy fits over a standard junction box. Power supply connections must be made inside a junction box (not included).

Finish

Black, Light Antique Brass, Satin Brass or Satin Nickel finish.

Diffuser

Solid acrylic diffuser.

Electrical

Input 120 VAC 60 HZ.
Compatible with TRIAC and ELV dimmers.

LED

Integrated LED modules capable of producing:
15W = 850 delivered lumens
Selectable 2700K, 3000K, 3500K, 4000K, 5000K (CCT).
Rated for 50,000 Hrs., 90 CRI.


Certification

All fixtures are cETLus listed for indoor damp locations.
Title 24/JA8 Compliant

Warranty

Limited warranty: This fixture is free from defects in materials and workmanship for a period of 5 year from date of purchase.

Specifications and dimensions
subject to change without notice.

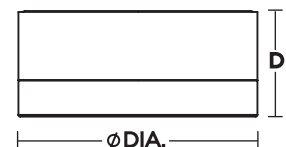

Ordering Information:

Black	Light Antique Brass	Satin Brass	Satin Nickel	LED	Delivered Lumens	Adjustable CCT	DIA.	D
EMAF06LAJD1BK	EMAF06LAJD1LB	EMAF06LAJD1SB	EMAF06LAJD1SN	15W	850	2700K/3000K/3500K/4000K/5000K	5-3/4"	2-1/2"