



Features

- 3000K color temperature and 93+ CRI
- Diffused lens eliminates dotting
- Efficacies up to 70 lumens per watt
- Linkable up to 400W
- Low profile design - less than 1" high
- Plug-in or direct wire capable
- Dimmable with most CL and ELV dimmers
- cETLus Listed for indoor dry locations
- 35,000 hours rated life
- ENERGY STAR certified

Available Sizes

8" / 12" / 18" / 24" / 32" / 40"

Available Finishes



White



Dark Bronze

Dimming Options

- CL (5-100%)
- ELV (5-100%)

Listing / Ratings

 



LED Complete 2 - 120V

Choose from six energy efficient fixture lengths in two finishes. Easy installation with captive mounting screws, quick access door to wiring compartment, and handy accessories such as hardwire box and linking cables. Multiple fixtures can also be linked directly with an inline connector (included). Long life, high CRI and convenient dimming are additional benefits.

Technical Information

Series	ALC2
Input Voltage	120V AC, 60Hz
CCT	3000K
CRI	93+
Wattage	Up to 14W (see individual product)
Lumens	Up to 955Lm (see individual product)
Beam Angle	120°
Max Run	400W
Dimmable	5-100%
Mounting	Surface mount
Rating	cETLus Listed (dry location)
Rated Life	35,000 hrs

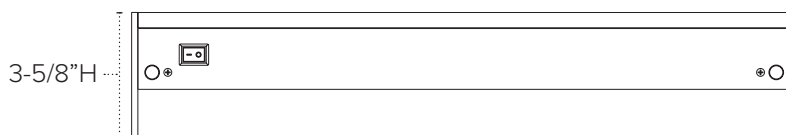

LED Complete 2



LED Complete 2 - White

ALC2-8-WH (8" / 3W / 180Lm)
ALC2-12-WH (12" / 4W / 270Lm)
ALC2-18-WH (18" / 6W / 415Lm)
ALC2-24-WH (24" / 8W / 515Lm)
ALC2-32-WH (32" / 11W / 770Lm)
ALC2-40-WH (40" / 14W / 955Lm)

LED Complete 2 - Dark Bronze

ALC2-8-DB (8" / 3W / 175Lm)
ALC2-12-DB (12" / 4W / 250Lm)
ALC2-18-DB (18" / 6W / 375Lm)
ALC2-24-DB (24" / 8W / 475Lm)
ALC2-32-DB (32" / 11W / 650Lm)
ALC2-40-DB (40" / 14W / 800Lm)

ALC2 fixtures include: (1) 3/8" cable connector / (1) End-to-end linking connector / Captive mounting screws

LED Complete 2 Accessories



Hardwire Junction Box
ALC-BOX-WH (White)
ALC-BOX-DB (Dark Bronze)



120V AC Power Cord (6ft)
ALC-PC6-WH (White)
ALC-PC6-BK (Black)



Linking Cables
ALC-EX6-WH (6" / White)
ALC-EX12-WH (12" / White)
ALC-EX6-BK (6" / Black)
ALC-EX12-BK (12" / Black)